




# SERIES 28 HiPer-D Connectors

## High-performance M24308 intermateable


The HiPer-D connector is a M24308-type D-Subminiature connector with superior design features. Unlike standard M24308 connectors with stamped steel shells, the HiPer-D connector features a one-piece machined shell, and is rated for 200°C continuous operating temperature. Aerospace grade fluorosilicone grommets and face seals provide environmental protection. The HiPer-D is intermateable, intermountable and interchangeable with standard M24308 D-Sub connectors. A ground spring offers enhanced EMI/RFI protection. New Combo-D insert arrangements for Coax, QuadraX, fiber and El Ochito® contacts now available.

- Advanced temperature, vibration and EMC/ electrical performance
- 11 standard and 20 combo insert arrangements
- High temperature epoxy insulators
- Watertight sealing
- Rugged machined one-piece shell

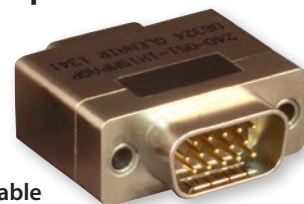

Available EMI/EMP filters

### STANDARD AND HIGH DENSITY CONTACT ARRANGEMENTS (face view of pin connector)

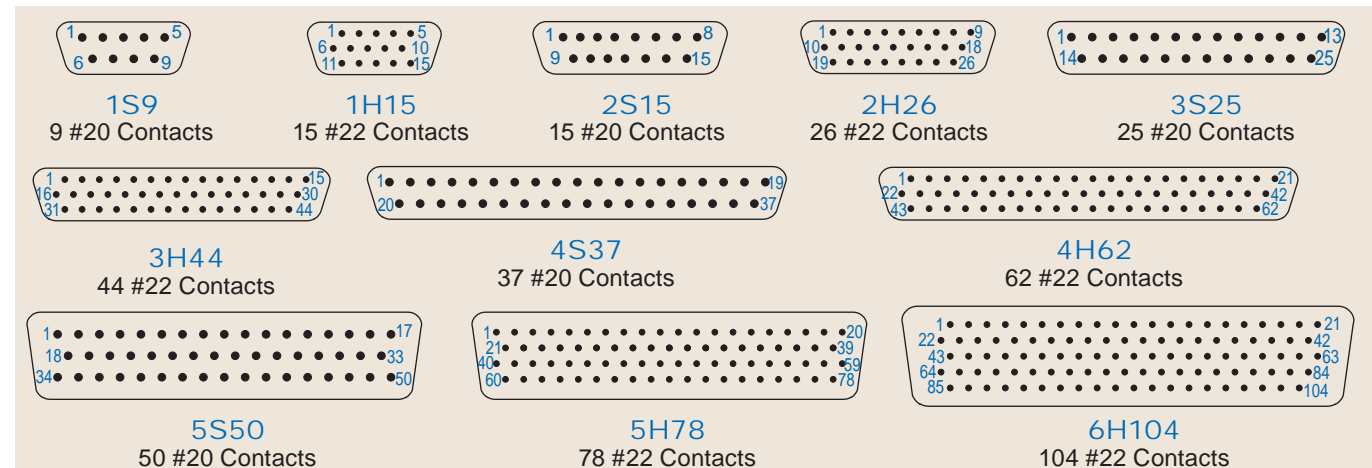

## SERIES 28 M24308 INTERMATEABLE HiPer-D® Connectors



### COMBO-D CONTACT ARRANGEMENTS (face view of pin connector)

