


Reference Guides

Band Straps and Tools for Shield Termination

Band-Master ATS®



Terminate cable braid shield to adapter with stainless steel **Band-Master ATS®** bands. Install band with hand tool or bench-mounted pneumatic tool. Bands are available in three widths: **Standard** (.24 inch), **Micro** (.12 inch) and **Nano** (.075 inch). **Slim Standard** and **Micro Slim** bands have reduced thickness for weight reduction. Available flat or pre-coiled, bands are 304 series stainless steel, passivated.

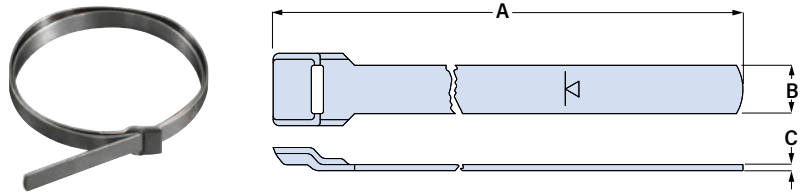

For more information on the Band-Master ATS EMI shield termination system, including instruction manuals and calibration details:

<https://www.glenair.com/bandmaster/>

Band Part Numbers

Size	A		Fits up to		B		C		Part Number		Hand Tool Part Number
	Length in	mm	in	mm	Width in	mm	Thickness in	mm	Flat	Pre-coiled	
Standard	9	228	1.00	25.4	.24	6.1	.02	0.5	601-005	601-006	601-100
	14	355	1.80	45.7	.24	6.1	.02	0.5	601-040	601-041	
	18	457	2.50	63.5	.24	6.1	.02	0.5	601-049	601-050	
Slim Standard	9	228	.94	23.9	.24	6.1	.01	0.3	601-570	601-571	601-109
	14	355	1.80	45.7	.24	6.1	.01	0.3	604-572	601-573	
Micro	5	127	.50	12.7	.12	3.0	.015	0.4	601-024	601-025	601-101
	8	203	.88	22.4	.12	3.0	.015	0.4	601-060	601-061	
	14	356	1.88	47.7	.12	3.0	.015	0.4	601-064	601-065	
Micro Slim	8	203	.88	22.4	.12	3.0	.01	0.3	601-600	601-601	601-122
	14	356	1.88	47.7	.12	3.0	.01	0.3	601-602	601-603	
Nano	6	152	.60	15.2	.075	1.9	.009	0.9	601-500	601-501	601-108
	9	229	.94	23.9	.075	1.9	.009	0.9	601-504	601-505	
	14	356	1.80	45.7	.075	1.9	.009	0.9	601-508	601-509	



Hand Tool for Band Installation



High Volume Pneumatic Tool