

Series 31 Shrink Boot Adapters

for MIL-DTL-38999 Series III and IV Connectors

310HS034 Shrink Boot Adapter, Direct Coupling




Adapter Code **H**

This accessory fits these connectors:
MIL-DTL-38999 Series III and Series IV

SHRINK BOOT

Optional heatshrink boot provides cable strain relief and environmental protection. Type 1 high-performance semi-rigid elastomer resists fuels and oils and withstands temperature extremes.

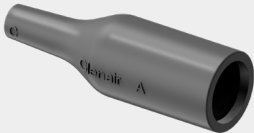


Shell Size	Shrink Boot P/N
9 (A)	770-001S103
11 (B)	770-001S103
13 (C)	770-001S104
15 (D)	770-001S106
17 (E)	770-001S106
19 (F)	770-001S107
21 (G)	770-001S107
23 (H)	770-001S108
25 (J)	770-001S108

Direct coupling. Low profile. 310HS034 shrink boot adapter fits MIL-DTL-38999 Series III and IV connectors. Adapter has groove for lipped shrink boot. Supplied as adapter only or as kit with shrink boot. Aluminum or stainless steel, silicone O-ring.

PART NUMBER

310HS034 NF 17 T

Base P/N	310HS034										
Material/Finish	M	Alum/ Electroless Nickel									
	MT	Alum/ Nickel-PTFE									
	NF	Alum/ Olive Drab Cadmium									
	ZR	Alum/ Black Zinc-Nickel									
	TZ	Alum/ Tin-Zinc									
	ZI	SST/ Passivated									
Shell Size	Shell Size	9	11	13	15	17	19	21	23	25	
	Size Code	09	11	13	15	17	19	21	23	25	
Shrink Boot	<i>Omit if not required</i>										
	T	Shrink Boot included									

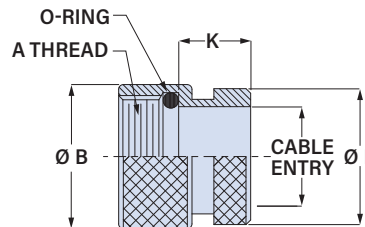

Shell Size	A Thread	Ø B Max		K Max		Ø L Max		Cable Entry Min	
		in	mm	in	mm	in	mm	in	mm
9 (A)	M12X1.0-6H	.65	16.5	.500	12.7	.688	17.5	.250	6.4
11 (B)	M15X1.0-6H	.77	19.6	.500	12.7	.803	20.4	.355	9.0
13 (C)	M18X1.0-6H	.89	22.6	.500	12.7	.938	23.8	.491	12.5
15 (D)	M22X1.0-6H	1.03	26.2	.500	12.7	1.063	27.0	.565	14.4
17 (E)	M25X1.0-6H	1.15	29.2	.500	12.7	1.238	31.4	.690	17.5
19 (F)	M28X1.0-6H	1.28	32.5	.500	12.7	1.310	33.3	.769	19.5
21 (G)	M31X1.0-6H	1.41	35.8	.500	12.7	1.436	36.5	.844	21.4
23 (H)	M34X1.0-6H	1.53	38.9	.500	12.7	1.560	39.6	1.019	25.9
25 (J)	M37X1.0-6H	1.66	42.2	.500	12.7	1.686	42.8	1.134	28.8