


750-190 Flexible Metal-Core EMI/RFI Conduit



Superior EMI protection and crush-proof strength for static applications




How To Order

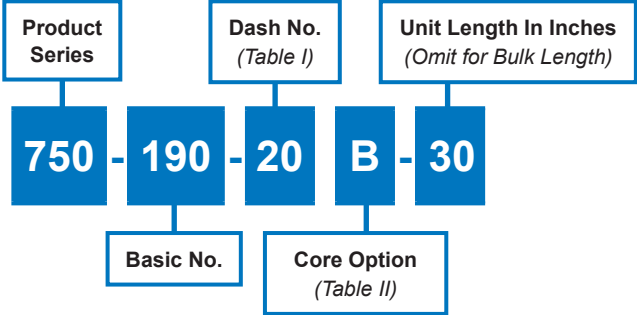

Dash No.	"B" Glenair Brass			"C" SST, "N" Nickel/Iron		
	A I.D.	B O.D.		A I.D.	B O.D.	
	Min	Min	Max	Min	Min	Max
06	.175 (4.45)	.260 (6.60)	.270 (6.86)	.175 (4.45)	.260 (6.60)	.270 (6.86)
08	.260 (6.60)	.360 (9.14)	.370 (9.40)	.245 (6.22)	.354 (9.00)	.374 (9.50)
09	.294 (7.47)	.390 (9.91)	.398 (10.1)	.294 (7.47)	.390 (9.91)	.398 (10.1)
10	.308 (7.82)	.408 (10.4)	.425 (10.8)	.308 (7.82)	.408 (10.4)	.425 (10.8)
12	.380 (9.65)	.484 (12.3)	.490 (12.4)	.370 (9.40)	.478 (12.1)	.498 (12.6)
16	.505 (12.8)	.610 (15.5)	.620 (15.7)	.495 (12.6)	.627 (15.9)	.647 (16.4)
20	.630 (16.0)	.730 (18.5)	.740 (18.8)	.620 (15.7)	.750 (19.1)	.770 (19.6)
24	.760 (19.3)	.860 (21.8)	.875 (22.2)	.745 (18.9)	.870 (22.1)	.890 (22.6)
32	1.012 (25.7)	1.115 (28.3)	1.125 (28.6)	.995 (25.3)	1.182 (30.0)	1.202 (30.5)
40	1.265 (32.1)	1.475 (37.5)	1.485 (37.7)	1.245 (31.6)	1.444 (36.7)	1.464 (37.2)
48	1.510 (38.4)	1.730 (43.9)	1.740 (44.2)	1.495 (38.0)	1.694 (43.0)	1.714 (43.5)
56	1.760 (44.7)	1.970 (50.0)	1.985 (50.4)	1.760 (44.7)	1.970 (50.0)	1.985 (50.4)
64	2.010 (51.1)	2.240 (56.9)	2.250 (57.2)	1.995 (50.7)	2.204 (56.0)	2.224 (56.5)
80	2.515 (63.9)	2.735 (69.5)	2.745 (69.7)	2.495 (63.4)	2.704 (68.7)	2.724 (69.2)
96	2.995 (76.1)	3.194 (81.1)	3.214 (81.6)	2.995 (76.1)	3.194 (81.1)	3.214 (81.6)

SYM	Core Material
B	Brass, Per A-A-52440 Type I, Grade B
C	Stainless Steel
N	80% Nickel, 20% Iron

Length (Inches)	Tolerance (Inches)
Up To 18	± .50
19 - 36	± 1.0
37 - 72	± 1.5
73 - 144	± 2.0
145 - 300	± 3.0
301 - 600	± 4.0
601 - 1200	± 5.0
1201 - Up	± 6.0

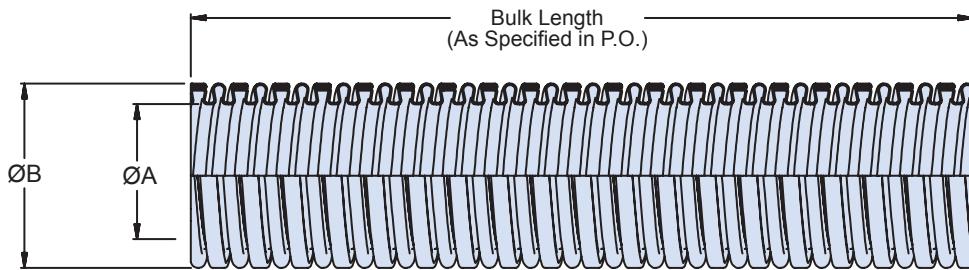

Packaging

Long-length orders of 750-190 conduit are subject to carrier weight and box size restrictions. For example, UPS air shipments are currently limited to 50 lbs. per box. Unless otherwise specified, Glenair standard practice is to ship optimal lengths of product based on weight, size, and individual carrier specifications. Consult factory for additional information or to specify packaging requirements.

