

El Ochito® Heat Shrink Boots and Sealing Boots

HEAT SHRINK BOOTS AND SEALING BOOTS



Heat Shrink Boot (Type II Only)



770-074 non-lipped, zero halogen heat shrink boot without eyelet. Shrink boot is adhesive lined for use with Type 2 El Ochito contacts. Provides environmental sealing and strain relief support. Pre-coated with W1 zero halogen/hot melt adhesive rated for use up to 125°C. To be used in place of a grommet follower for Type II assemblies.

How-to-Order

770	-	074	S	1	01	W1
Series		Basic Part No.	Angular Function	Material	Boot Size	Adhesive
		Non-Lipped Boot Without Eyelet	S Straight	1 Compound 2025: High Performance Elastomer		W1 125° C Zero Halogen/ Hot Melt

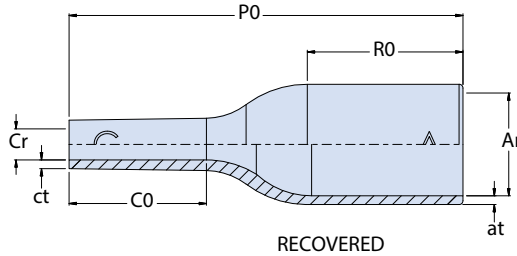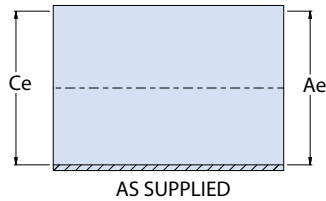


770-074 Shrink Boot Dimensions

Boot Size	Ae Dia Min	Ce Dia Min	Ar Dia Max	at ±30%	Cr Dia Max	ct ±20%	C0 Ref	P0 ±10%	R0 Ref
-01	.354 (8.99)	.354 (8.99)	.265 (6.73)	.023 (0.58)	.080 (2.03)	.023 (0.58)	.354 (8.99)	1.015 (25.78)	.401 (10.19)

Grommet Follower (Type I)

An "F" suffix in the contact part number indicates the contact is supplied with a grommet follower. To order these contacts without grommet follower, delete the "F" suffix from the part number. Grommet followers are not compatible with Type II Ochito contacts.

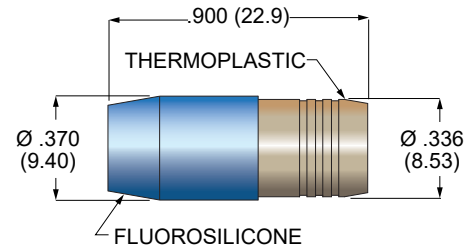

GROMMET FOLLOWER FOR OCHITO CONTACTS

- 687-754-8-4**
FOR .177 (4.5) DIAMETER CABLES
- 687-754-8-8**
FOR .220 (5.56) DIAMETER CABLES
- 687-754-8-9**
FOR .236 (6.0) DIAMETER CABLES