

Selection Guide

**THE ARMORLITE
ADVANTAGE**

Lightweight
microfilament braided
ground straps



107-105 100% ArmorLite, our lightest weight braid configuration


107-106 75% ArmorLite 25% Nickel Copper weight-saving conductive blend

107-107 50% ArmorLite 50% Nickel Copper weight-saving conductive blend

107-108 ArmorLite CF High-performance corrosion-free lightweight braid

**STANDARD-DUTY
GROUND STRAPS**

A-A-59569
soft-drawn braided
ground straps

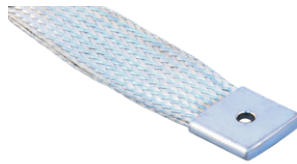

107-101 Tin copper material ground straps

107-102 Silver copper material ground straps

107-103 Nickel copper material ground straps

107-104 Stainless steel material ground straps


**MIL-SPEC
GROUND STRAPS**

with "better than
QPL" configuration
options



107-500 M24749-IV equivalent with configuration options beyond the mil-spec

VARIABLE LUG / HOLE / STRAP CONFIGURATION OPTIONS AVAILABLE ON ALL STYLES

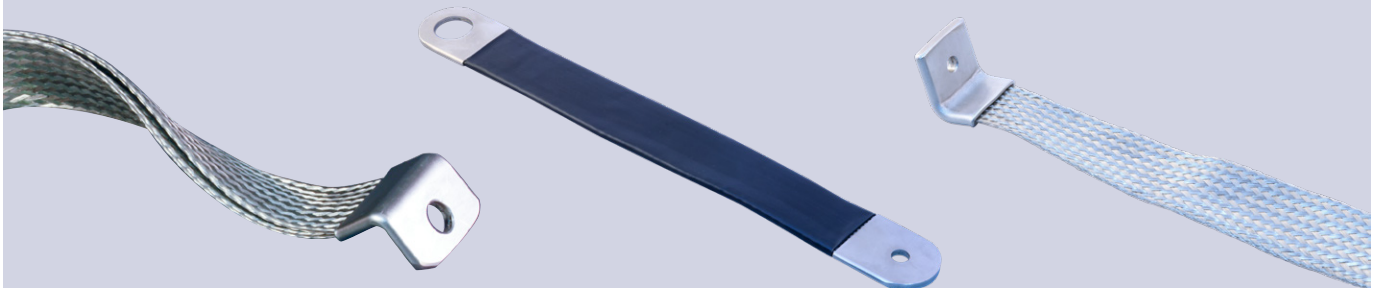

Choose single-layer straps or dual-layer for strength and electrical performance

Available black or clear sleeving over strap. Square or radiused lugs and variable hole sizes

Straight, single right-angle, and dual right-angle configurable lugs