

SERIES 80

Mighty Mouse Connectors and Cables




Standard Contact Layouts and Specifications

Contact Size and Quantity					Specifications			Contact Arrangement						
#23	#20HD	#16	#12	#8	Max Current Rating (Amps)	AWG Accepted	VAC DWV	Series 800	Series 801	Series 802	Series 803	Series 804	Series 805	
3					5	#22-#28	750	5-3	5-3	5-3	5-3	5-3	N/A	
4					5	#22-#28	750	6-4	6-4	6-4	6-4	6-4	8-4	
6					5	#22-#28	750	6-6	6-6	6-6	6-6	6-6	8-6	
7					5	#22-#28	750	6-7	6-7	6-7	6-7	6-7	8-7	
10					5	#22-#28	750	7-10	7-10	7-10	7-10	7-10	9-10	
13					5	#22-#28	750	8-13	8-13	8-13	8-13	8-13	10-13	
19					5	#22-#28	750	9-19	9-19	9-19	9-19	9-19	11-19	
26					5	#22-#28	750	10-26	10-26	10-26	10-26	10-26	12-26	
31					5	#22-#28	750	N/A	11-31	N/A	11-31	11-31	13-31	
37					5	#22-#28	750	12-37	13-37	12-37	12-37	12-37	15-37	
55					5	#22-#28	750	N/A	16-55	14-55	14-55	14-55	18-55	
85					5	#22-#28	750	N/A	17-85	15-85	N/A	N/A	19-85	
100					5	#22-#28	750	N/A	19-100	19-100	N/A	N/A	21-100	
130					5	#22-#28	750	N/A	21-130	21-130	N/A	N/A	23-130	
	3				7.5	#20-#24	1000	6-23	6-23	6-23	6-23	6-23	8-23	
	5				7.5	#20-#24	1000	7-25	7-25	7-25	7-25	7-25	9-25	
	8				7.5	#20-#24	1000	8-28	8-28	8-28	8-28	8-28	10-28	
	10				7.5	#20-#24	1000	9-210	9-210	9-210	9-210	9-210	11-210	
	20				7.5	#20-#24	1000	12-220	13-220	12-220	12-220	12-220	15-220	
	35				7.5	#20-#24	1000	N/A	16-235	14-235	14-235	14-235	18-235	
	41				7.5	#20-#24	1000	N/A	17-241	15-241	N/A	N/A	19-241	
	55				7.5	#20-#24	1000	N/A	19-255	19-255	N/A	N/A	21-255	
	69				7.5	#20-#24	1000	N/A	21-269	21-269	N/A	N/A	23-269	
		1			13	#16-#20	1800	6-1	6-1	6-1	6-1	6-1	8-1	
		2			13	#16-#20	1800	8-2	8-2	8-2	8-2	8-2	10-2	
		4			13	#16-#20	1800	9-4	9-4	9-4	9-4	9-4	11-4	
		5			13	#16-#20	1800	10-5	10-5	10-5	10-5	10-5	12-5	
		7			13	#16-#20	1800	12-7	13-7	12-7	12-7	12-7	15-7	
		12			13	#16-#20	1800	N/A	16-12	14-12	14-12	14-12	18-12	
		14			13	#16-#20	1800	N/A	17-14	15-14	N/A	N/A	19-14	
		19			13	#16-#20	1800	N/A	19-19	19-19	N/A	N/A	21-19	
		22			13	#16-#20	1800	N/A	21-22	21-22	N/A	N/A	23-22	
			1		23	#12-#14	1800	7-1	7-1	7-1	7-1	7-1	9-1	
			2		23	#12-#14	1800	10-2	10-2	10-2	10-2	10-2	12-2	
			2		23	#12-#14	1800	12-2	13-2	12-2	12-2	12-2	15-2	
			3		23	#12-#14	1800	12-3	13-3	12-3	12-3	12-3	15-3	
			4		23	#12-#14	1800	N/A	16-4	14-4	14-4	14-4	18-4	
			5		23	#12-#14	1800	N/A	16-5	14-5	14-5	14-5	18-5	
			7		23	#12-#14	1800	N/A	17-7	15-7	N/A	N/A	19-7	
			12		23	#12-#14	1800	N/A	21-12	21-12	N/A	N/A	23-12	
				1	46	#8	1800	N/A	8-1	8-1	N/A	N/A	10-1	
				2	46	#8	1800	N/A	16-2	14-2	N/A	N/A	18-2	
				3	46	#8	1800	N/A	17-3	15-3	N/A	N/A	19-3	
				4	46	#8	1800	N/A	19-4	19-4	N/A	N/A	21-4	
				5	46	#8	1800	N/A	21-5	21-5	N/A	N/A	23-5	

General Information and Reference

* DWV rating is applicable to contact arrangements shown

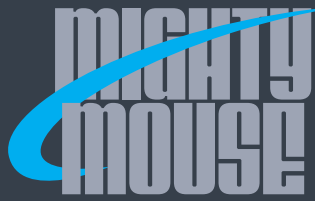

SERIES 80

Mighty Mouse Connectors and Cables



Combo Contact Layouts and Specifications

Contact Size and Quantity					Specifications		Contact Arrangement					
#23	20	#16	#12	#8	Test Vac	AWG Accepted	Series 800	Series 801	Series 802	Series 803	Series 804	Series 805
12			1		750	#22-#28	10-200	10-200	10-200	10-200	10-200	12-200
4			2		750	#22-#28	10-201	10-201	10-201	10-201	10-201	12-201
6			2		750	#22-#28	12-200	13-200	12-200	12-200	12-200	15-200
10			2		750	#22-#28	12-201	13-201	12-201	12-201	12-201	15-201
4		2			750	#22-#28	9-200	9-200	9-200	9-200	9-200	11-200
8		2			750	#22-#28	10-202	10-202	10-202	10-202	10-202	12-202
4	2				750	#22-#28	8-200	8-200	8-200	8-200	8-200	10-200
8	2				750	#22-#28	9-201	9-201	9-201	9-201	9-201	11-201
20		2			1300	#22-#28	12-202	13-202	12-202	12-202	12-202	15-202
12		4			1300	#22-#28	12-203	13-203	12-203	12-203	12-203	15-203
40		2			1300	#22-#28	N/A	16-204	14-204	14-204	14-204	18-204
32		4			1300	#22-#28	N/A	16-205	14-205	14-205	14-205	18-205
40		4			1300	#22-#28	N/A	17-203	15-203	N/A	N/A	19-203
58		4			1300	#22-#28	N/A	17-206	15-206	N/A	N/A	19-206
12			2		1300	#22-#28	12-204	13-204	12-204	12-204	12-204	15-204
4			4		1300	#22-#28	12-205	13-205	12-205	12-205	12-205	15-205
34			2		1300	#22-#28	N/A	16-206	14-206	14-206	14-206	18-206
20			4		1300	#22-#28	N/A	16-207	14-207	14-207	14-207	18-207
28			4		1300	#22-#28	N/A	17-204	15-204	N/A	N/A	19-204
18				1	1300	#22-#28	N/A	11-201	11-201	N/A	11-201	13-201
32				1	1300	#22-#28	N/A	16-208	14-208	N/A	14-208	18-208
40				1	1300	#22-#28	N/A	17-205	15-205	N/A	N/A	19-205
44				2	1300	#22-#28	N/A	19-201	19-201	N/A	N/A	21-201
12				4	1300	#22-#28	N/A	19-202	19-202	N/A	N/A	21-202
28				4	1300	#22-#28	N/A	21-200	21-200	N/A	N/A	23-200