

CONNETTORE SERIE "PLAF"

CONFIGURAZIONI :

- Maschio volante
- Femmina pannello
- Femmina volante
- Maschio pannello

Le configurazioni volanti sono fornite di raccordo e serracavo plastico PGI3.5 oppure con predisposizione per l'utilizzo di guaina termorestringente .

CARATTERISTICHE :

Contatti :


- Terminale a saldare
- Terminale a pinzare
- Terminale con vite x capocorda ad occhiello
- Portata max. 4IA a 20° C

Corpo :

- Gomma cloroprenica o tipo "Fire Resistant"
- Nylon UL94-V0

Tenuta ambientale : IP67

Connettore dotato di polarizzazione meccanica

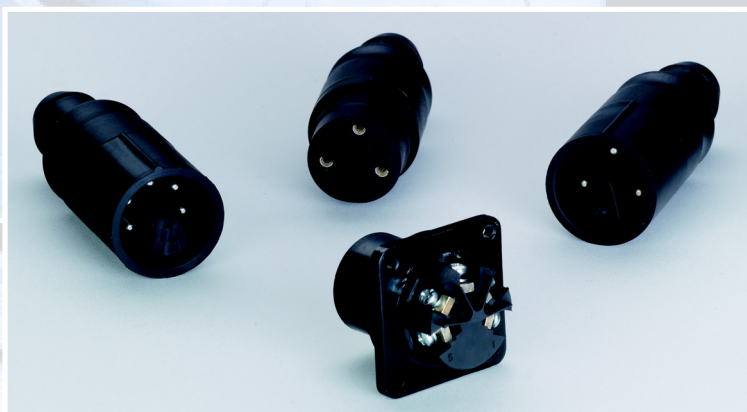

"PLAF" SERIES CONNECTORS

CONFIGURATIONS :

- Male plug
- Female receptacle
- Female plug
- Male receptacle

Plug connectors are available with an adapter and plastic PGI3.5 cable gland or arranged for the use on an heat shrink tubing .

CHARACTERISTICS :

Contacts :

- Solder ending
- Crimp ending
- Threaded ending for 0 terminals
- Max. current : 4IA at 20° C

Shells :

- Neoprene rubber or "Fire Resistant" rubber
- Nylon UL94-V0

Protection index : IP67

The connector is provided with mechanical polarization