



OCTOBYTE

The faster 4/8 pole industrial Ethernet interconnect system

COAX contacts



How To Order						
Sample Part Number	Q	0	CX	P	-RG58	B1
Product Series	Q = OctoByte contacts					
Contact Size	0 = Contact size 0					
Contact Type	CX = COAX					
Contact Gender	P = Pin contacts (male) S = Socket contacts (female)					
Cables	-RG58 - 50 Ohm -RG59U - 75 Ohm					
Plating	B1 = Gold plating					

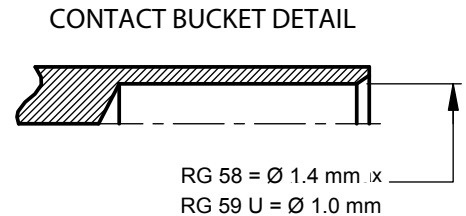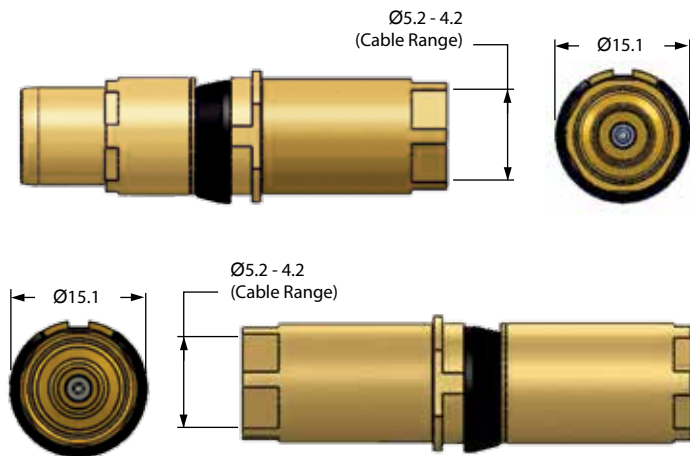

Data Transmission Contacts for	RG58
Featuring	Internal crimpable contacts
	Inspectable contact
	Integrated cable clamp
	Low mating force
Technical Characteristics	Current rating 5A max
	Voltage drop (at 5A and 25°C) 70 mV max
Materials and Finish	Copper alloy and gold plating
Inserts	PTFE - UL94V0

NOTES

Crimp Tools and Die

- Crimper: M.112017
- Die: Y197 for RG58 cable and Y143 for RG59 cable