
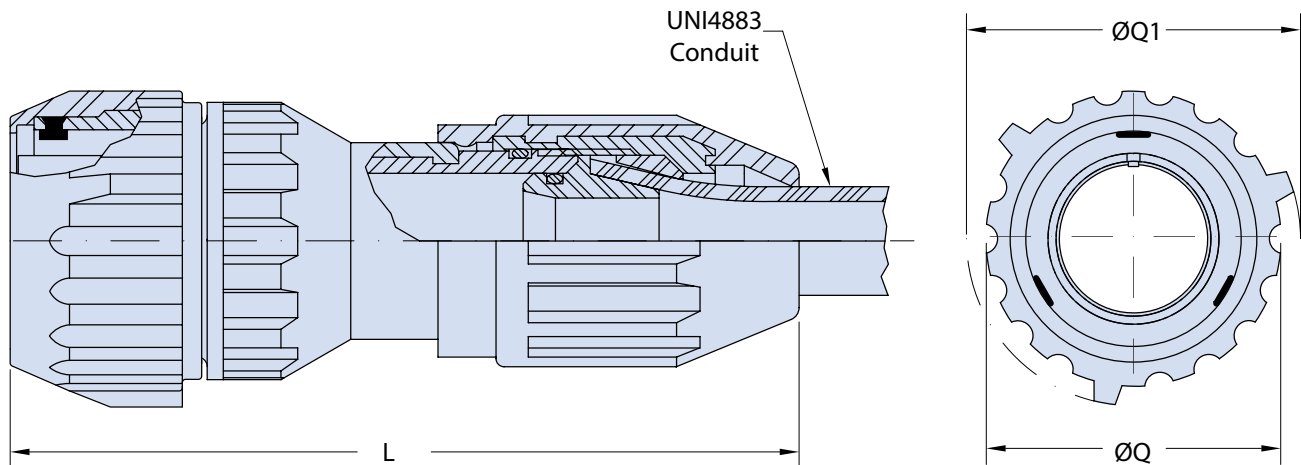


ITS 4106 RGBF and ITS 4106 RRGBF Straight Cylindrical Plug Connector with Rubber-Coated Threaded Adapter for Use with UNI4883 Conduit

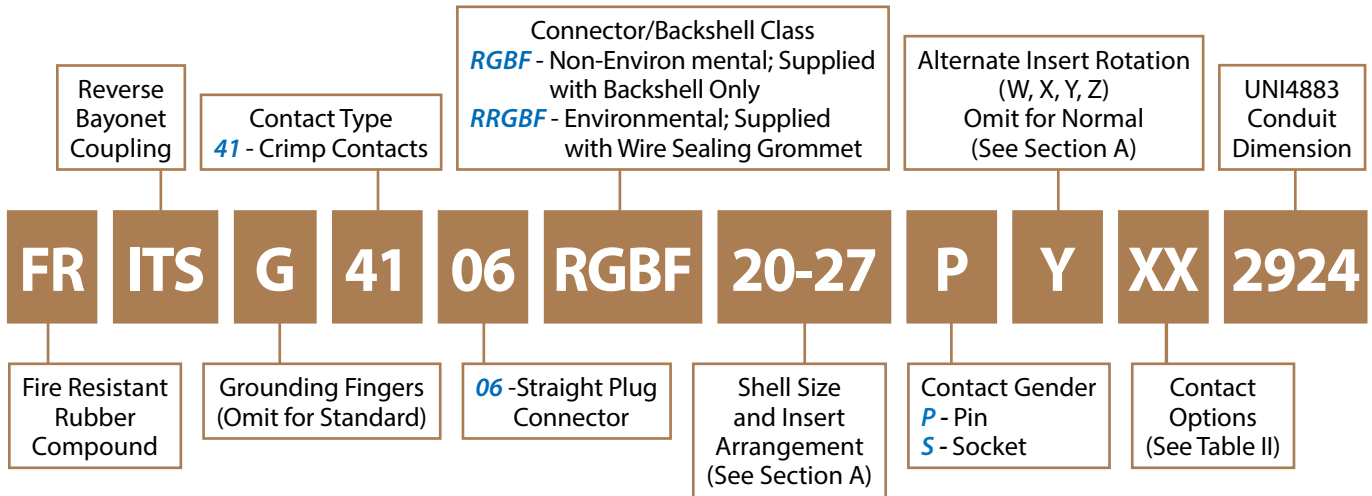

Application Notes

1. Straight plug connector with rubber-coated threaded adapter for termination of UNI4883 conduit.
2. RGBF - Non-Environmental; grommet not supplied.
RRGBF - Environmental; supplied with wire sealing grommet.
3. Standard materials configuration consists of aluminum alloy with plating RoHS compliant.
4. Standard contact material consists of copper alloy with silver plating or gold plating.

**ITS 4106 RGBF and ITS 4106 RRGBF
Straight Cylindrical Plug Connector
with Rubber-Coated Threaded Adapter
for Use with UNI4883 Conduit**



TABLE I: DIMENSIONS

Shell Size	L Max.	ØQ ±0.5	ØQ1 ±0.5	Rubber conduits UNI 4883
14 S	95	35.0	42.0	20X15 23X18 25X20 27X22 29X24 33X28 38X33 40X35 48X43 50X45
16 S	95	38.0	45.0	
16	105	38.0	45.0	
18	110	43.5	49.0	
20	115	46.5	52.0	
22	115	50.5	56.0	
24	145	54.0	60.0	
28	145	61.0	67.0	
32	150	68.0	76.0	
36	165	74.0	82.0	
40	170	80.0	88.0	

For correct shell size match, please consult the factory.

C

TABLE II: MODIFICATION CODES

CONTACT OPTIONS	
Sym	Description
B0	Connector without Contacts*
B1	Connector with Gold Plated Contacts
Omit for standard version (Silver plated)	

(*) Crimp Contacts Only