

BATTLE-TESTED

STAR-PAN™

Selection Guide

Hubs, cables, adapters, and accessories



STAR-PAN HUBS: SCALABLE MULTIPOINT POWER AND DATA HUBS


| Part No. | NATO Stock No. NSN | Description | Electrical Function | Weight | IP Rating | Protocol | ECCN / EAR | Page No. |
|----------------------------------|-------------------------|--|---------------------|-------------------|-----------|---------------------------------|------------|----------------|
| 808-054 808-058 | 5995-01-688-2439 | STAR-PAN Light bifurcated cable (battery plug / RADIO plug cable ends or battery plug / PAN receptacle cable ends) | Power + Data | 122g | IP67 | USB1.1 USB2.0 | 3A611.x | 14 |
| 808-057-1 | 6150-01-682-5677 | STAR-PAN II hub / cable assembly, optional MOLLE pouch and MOLLE clip | Power + Data | 245g | IP67 | USB1.1 USB2.0 SMBus | 3A611.a | 16 |
| 808-194-1 | 5935-01-691-2366 | STAR-PAN II connectorized hub, optional MOLLE pouch, clip, and expansion cable | Power + Data | 170g | IP67 | USB1.1 USB2.0 SMBus | 3A611.a | 16 |
| 808-273 | | STAR-PAN IV, optional MOLLE pouch, MOLLE clip, general-purpose cable | Power + Data | (consult factory) | IP67 | USB1.1 USB2.0 SMBus | 3A611.a | 22 |
| 808-037 | 6140-01-669-3584 | STAR-PAN VI, standard port configuration | Power + Data | 337g | IP67 | USB1.1 USB2.0 SMBus | 3A611.a | 28 |
| TS8-462 | | STAR-PAN X Base Station, with 10 PAN ports | Power + Data | 5 lbs. | IP67 | USB 3.0 HDMI 10G Ethernet | 3A611.a | 34 |
| TS3-001 | | STAR-PAN USB Flash drive (for all STAR-PAN hubs) | Data | (consult factory) | | | | 20, 26, 32, 35 |




STAR-PAN™ II
Hub / Cable Assembly and
Connectorized Hub



STAR-PAN™ IV

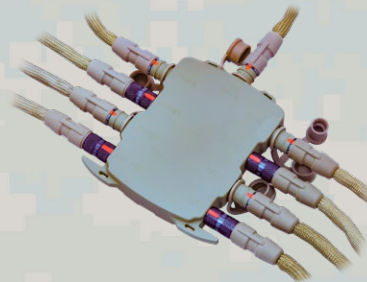

STAR-PAN™ VI

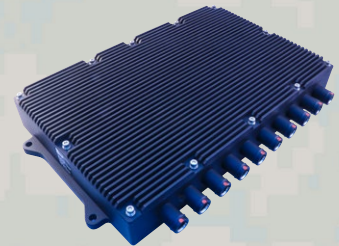

STAR-PAN™ X
Base Station

STAR-PAN MISSION MANAGER

| Part No. | NATO Stock No. NSN | Description | Electrical Function | Weight | IP Rating | Protocol | ECCN / EAR | Page No. |
|----------------|-------------------------|---|-----------------------|-------------------|-----------|--------------------------------------|------------|----------|
| TS2-002 | 7025-01-687-0223 | STAR-PAN MISSION MANAGER, standard | Host Datalink Manager | 90g | IP67 | USB1.1 / USB2.0 SMBus Ethernet | 99 | 36 |
| TS2-005 | | STAR-PAN MISSION MANAGER, WiFi version | Host Datalink Manager | (consult factory) | IP67 | USB1.1 / USB2.0 SMBus Ethernet | 99 | 36 |
| TS2-010 | | STAR-PAN MISSION MANAGER, WiFi version with wireless external antenna | Host Datalink Manager | (consult factory) | IP67 | USB1.1 / USB2.0 SMBus Ethernet | 99 | 36 |

BATTLE-TESTED

STAR-PAN™

Selection Guide

Hubs, cables, adapters, and accessories



GENERAL PURPOSE STAR-PAN CABLES

| Part No. | NATO Stock No. NSN | Description | Electrical Function | Weight | Standard Length | Cable Finish | ECCN / EAR | Page No. |
|-------------------------|----------------------------------|--|---------------------|-------------------|-----------------|---------------------|------------|----------|
| 808-047 | 5995-01-668-8636 | Mighty Mouse 807 universal adapter cable | Power + Data | 50g | 24" | Santoprene or Nomex | 3A611.x | 21, 39 |
| 808-081 | 5995-01-682-9386 | STAR-PAN II Expansion Cable | Power + Data | 56g | 8" | Black Santoprene | 3A611.x | 21 |
| 808-095 | | 90° Exit Cable (with 90° plug) | Power + Data | 20g | 6" | Nomex, O.D. | 3A611.x | 40 |
| 808-244 | | 90° Exit Cable (with 90° receptacle) | Power + Data | 20g | 6" | Nomex, O.D. | 3A611.x | 41 |
| 808-236 | | 6-6 Receptacle-to-Receptacle Cable | Power + Data | (consult factory) | 8" | Black Polyurethane | 3A611.x | 42 |
| TS8-452 | | Radio-to-PAN Adapter Cable | Power + Data | (consult factory) | 24" | Nomex, O.D. | 3A611.x | 43 |
| 808-129 | | Plug flying lead assembly | Power + Data | 65g | 24" | Black Santoprene | 99 | 45 |
| 808-130 | | Receptacle flying lead assembly | Power + Data | 65g | 24" | Black Santoprene | 99 | 45 |

STAR-PAN RADIO CABLES AND ADAPTERS

| Part No. | NATO Stock No. NSN | Description | Electrical Function | Weight | Standard Length | Cable / Device Finish | ECCN / EAR | Page No. |
|-------------------------|----------------------------------|--|---------------------|-------------------|-----------------|-----------------------|------------|----------|
| 808-087 | | AN/PRC-117F Radio Cable (PAN Port) | Data | (consult factory) | 36" | Santoprene, Black | 3A611.x | 49 |
| 808-035 | 5995-01-668-8687 | AN/PRC-117G Radio Cable | Power + Data | 90g | 32" | Nomex, O.D. | 3A611.x | 50 |
| 808-088 | 5995-01-692-0106 | AN/PRC-117G Radio Cable (PAN Port) | Data | 90g | 32" | Nomex, O.D. | 3A611.x | 51 |
| 808-039 | | AN/PRC-148 JEM Radio Adapter | Power + Data | 122g | 20" | Nomex, O.D. | 3A611.x | 52 |
| TS8-515 | | AN/PRC-148 Sync Serial Adapter | Power + Data | 91g | N/A | Black Zinc-Nickel | 3A611.x | 53 |
| TS8-431 | | AN/PRC-152A Radio Adapter | Power + Data | (consult factory) | N/A | Black Zinc-Nickel | 3A611.x | 54 |
| 808-032 | 5995-01-668-8863 | AN/PRC-152A Radio Adapter | Power + Data | 116g | 24" | Nomex, O.D. | 3A611.x | 55 |
| TS8-513 | | AN/PRC-152A Radio Side Connector | Power + Data | (consult factory) | N/A | Black Zinc-Nickel | 3A611.x | 56 |
| TS8-410 | | AN/PRC 152/152A Sync Serial Adapter | Power + Data | 91g | N/A | Black Zinc-Nickel | 3A611.x | 57 |
| TS8-508 | | AN/PRC-161 BATS-D Radio Adapter | Power + Data | (consult factory) | 20" | Black Santoprene / ZN | 3A611.x | 58 |
| TS8-509 | | AN/PRC-161 BATS-D Radio Adapter, PAN port | Power + Data | (consult factory) | 20" | Black Santoprene / ZN | 3A611.x | 59 |
| 808-166 | | AN/PRC-161 BATS-D Radio Adapter | Power + Data | 166g | 20" | Nomex, O.D. | 3A611.x | 60 |
| TS8-409 | | AN/PRC-161 Radio Ethernet Adapter | Power + Data | (consult factory) | 32" | Nomex, O.D. | 3A611.x | 61 |
| TS8-457 | | AN/PRC-163 Radio Battery Adapter, Red I/O | Power + Data | (consult factory) | N/A | Black Zinc-Nickel | 3A611.x | 62 |
| TS8-458 | | AN/PRC-163 Radio Battery Adapter, Black I/O | Power + Data | (consult factory) | N/A | Black Zinc-Nickel | 3A611.x | 63 |
| TS8-495 | | AN/PRC-163 Radio Adapter, Red/Black Switch | Power + Data | (consult factory) | N/A | Black Zinc-Nickel | 3A611.x | 64 |
| TS8-411 | | AN/PRC-167 Multi-Function I/O (MFI) Cable | Power + Data | (consult factory) | 18" | Santoprene, Black | 3A611.x | 65 |
| 808-132 | | Elbit PNR 1000 Radio Adapter | Data | 80g | 21" | Santoprene, Black | 3A611.x | 66 |
| TS8-470 | | Elbit PNR 1000 Radio Adapter | Power+Data | 42g | N/A | Black Zinc-Nickel | 3A611.x | 67 |
| TS8-446 | 5995-01-691-2527 | Harris RF-7850S-TR Radio Cable | Data | 75g | 18" | Santoprene, Black | 3A611.x | 68 |
| 808-257 | 5995-01-683-8677 | Harris RF-7800S Radio Cable | Data | (consult factory) | 32" | Nomex, O.D. | 3A611.x | 69 |
| 808-148 | | Harris RF-7800S Radio Cable (Radio Host) | Data | 74g | 32" | Nomex, O.D. | 3A611.x | 70 |
| TS8-466 | | Harris RF-7800S-TR Radio Cable, PAN Port | Data | (consult factory) | 32" | Nomex, O.D. | 3A611.x | 71 |
| TS8-426 | | Harris RF-7850M Sync Serial Adapter | Power + Data | 91g | N/A | Black Zinc-Nickel | 3A611.x | 72 |
| 808-044 | | Raytheon RT-1922 Microlight SADL Radio Cable | Power + Data | 60g | 24" | Nomex, O.D. | 3A611.x | 73 |
| TS3-009 | | Thales PR4G Radio Ethernet Cable | Power + Data | (consult factory) | 24" | Santoprene, Black | 3A611.x | 74 |
| TS3-016 | | TrellisWare TSM Shadow Radio Power Booster | Power + Data | 69g | N/A | Black Zinc-Nickel | 3A611.x | 75 |
| TS8-486 | | TS-950 Radio Power Booster | Power | (consult factory) | N/A | Black Zinc-Nickel | 3A611.x | 76 |
| TS1-094 | | Right-Angle Cable for use with TS8-486 | Power + Data | (consult factory) | N/A | Black Santoprene / ZN | EAR99 | 77 |
| TS1-003 | | Silvus SC4200 Radio Data Cable, AUX port | Data | (consult factory) | 24" | Santoprene, Black | EAR99 | 78 |
| TS8-539 | | MPU5 Ethernet Cable | Power + Data | (consult factory) | 90" | Black Santoprene / ZN | 3A611.x | 79 |
| TS8-544 | | MPU5 Ethernet Cable with RPB Option | Power + Data | (consult factory) | 30" | Black Santoprene / ZN | 3A611.x | 80 |

BATTLE-TESTED

STAR-PAN™

Selection Guide
Hubs, cables, adapters, and accessories



STAR-PAN POWER CABLES AND BATTERY ADAPTERS

| Part No. | NATO Stock No. NSN | Description | Electrical Function | Weight | Standard Length | Cable / Device Finish | ECCN / EAR | Page No. |
|-------------------------------------|--|--|---------------------|-------------------|-----------------|---------------------------------|------------|----------|
| 808-242 | | BB2590 Battery Adapter w/ Charging / SMBus | Power | 286g | N/A | Black, Green, Tan | 99 | 82 |
| TS2-026 (-1, -2, -3) | | BB2590 Adapters (Standard, EMI box, and 5V Out options) | Power | (consult factory) | N/A | Black Zinc-Nickel | 99 | 83 |
| TS1-027 | | Battery Connector for Bren-Tronics BTA-70838-8 | Power | (consult factory) | 21" | Black Zinc-Nickel | 99 | 84 |
| TS1-033 | | Battery Connector for Bren-Tronics BTA-70909-8 | Power | (consult factory) | 24" | Black Zinc-Nickel | 99 | 84 |
| 808-066 | 5935-01-683-1932 | Radio Battery Adapter for Harris and BT70716XX Handheld Radios | Power | 70g | N/A | Black Zinc-Nickel | 3A611.x | 85 |
| TS3-022 | | Universal Radio Power Booster (RPB) | Power | (consult factory) | N/A | Black Anodized | 3A611.x | 86 |
| 808-175 | | PRC-152A, -152, -148 Universal Battery Adapter / Charger | Power | (consult factory) | N/A | Santoprene / Zinc-Nickel, Black | 3A611.x | 87 |
| TS8-459 | | AN/PRC Radio Battery Adapter | Power | (consult factory) | N/A | Santoprene / Black Anodized | 3A611.x | 88 |
| TS8-473 | | AN/PRC-163 Dual Power Cable Battery Eliminator | Power | (consult factory) | N/A | Santoprene / Zinc-Nickel, Black | 3A611.x | 89 |
| 808-063 | | PRC-152A, -152, -148 Radio Power Booster | Power | 172g | N/A | Santoprene / Zinc-Nickel, Black | 3A611.x | 90 |
| TS1-067 | | Cable for use with Radio Battery Adapter | Power | (consult factory) | N/A | Santoprene / Zinc-Nickel, Black | 3A611.x | 91 |
| TS1-030 | | Cable for use with Radio Battery Adapter | Power | (consult factory) | 3.75" | Santoprene / Zinc-Nickel, Black | 99 | 92 |
| TS1-073 | | Cable for use with Radio Battery Adapter | Power | (consult factory) | 4" | Santoprene / Black Conductive | 99 | 93 |
| TS1-045 | | AN/PRC-163 Dual Charge/Battery Eliminator Cable | Power | (consult factory) | N/A | Santoprene / Black Conductive | 99 | 94 |
| TS2-003 | | Power Scavenger | Power | (consult factory) | N/A | Black Conductive | 3A611.x | 95 |
| TS2-009 | | Power Conditioner | Power | (consult factory) | N/A | Matte Tan | 3A611.x | 96 |
| TS2-093 | | STAR-PAN X Adapter Cable for TS2-009 Power Conditioner | Power | (consult factory) | 10" | Santoprene, Black | 99 | 97 |
| TS1-053 | | Automotive Aux Power / Cigarette Lighter Adapter Cable | Power | (consult factory) | 120" | Black Overmolded | 99 | 98 |
| TS1-054 | | Mighty Mouse to Battery Clamp Adapter Cable | Power | (consult factory) | 240" | Black Overmolded | 99 | 99 |
| TS1-055 | | Mighty Mouse to NATO Plug Adapter Cable | Power | (consult factory) | 120" | Black Overmolded | 99 | 100 |
| 808-059 | 6150-01-674-0055 | Cigarette Lighter Power Adapter Cable | Power | 84g | 72" | Santoprene, Black | 3A611.x | 101 |
| 808-064 808-064-EU | 5995-01-668-8659 5995-01-682-9273 | AC/DC Power Adapter Cable AC/DC Power Adapter Cable, European | Power | 590g | 110" | Santoprene, Black | 3A611.x | 102 |
| TS3-060 | | USB-C Power Delivery Downstream Charging Cable | Power | (consult factory) | 18" | Santoprene, Black | 3A611.x | 103 |



AN/PRC-152/ 152A Sync Serial Adapter



BB2590 Parallel Charging Battery Adapter with SMBus



Universal Battery Adapter / Charger For Harris PRC-152A, PRC-152, and PRC-148 Radios

BATTLE-TESTED

STAR-PAN™

Selection Guide

Hubs, cables, adapters, and accessories



STAR-PAN TARGETING CABLES AND ADAPTERS

| Part No. | NATO Stock No. NSN | Description | Electrical Function | Weight | Standard Cable Length | Cable Finish | ECCN / EAR | Page No. |
|----------------|-------------------------|---|---------------------|-------------------|-----------------------|-------------------|------------|----------|
| 808-041 | 5995-01-668-8804 | Vector 21 / 23B Cable | Data | 205g | 54" | Santoprene, Black | 3A611.x | 105 |
| TS8-494 | | Vektor 21 / Moskito / Multi-Use RS232 Cable | Data | 205g | 54" | Santoprene, Black | 3A611.x | 106 |
| 808-049 | 5995-01-693-5683 | PLRF 15C / 25C Cable | Data | 76g | 45" | Santoprene, Black | 3A611.x | 107 |
| 808-212 | | STERNA True North Finder (TNF) cable | Data + Power | 110g | 24" | Santoprene, Black | 3A611.x | 108 |
| 808-246 | 5995-01-684-4726 | JIM-LR Cable | Data + Power | 235g | 24" | Santoprene, Black | 3A611.x | 109 |
| 808-219 | | JIM Compact Cable | Data + Power | 115g | 40" | Santoprene, Black | 3A611.x | 110 |
| TS8-488 | | JIM Compact P2 Cable, 90° Overmold w/Switch | Data + Power | (consult factory) | 60" | Santoprene, Black | 3A611.x | 111 |
| 808-218 | | Moskito TI Cable | Data + Power | 150g | 24" | Santoprene, Black | 3A611.x | 112 |
| 808-251 | 6150-01-693-7011 | Moskito TI RS-232 to USB Converter Cable | Data + Power | 59g | 24" | Santoprene, Black | 3A611.x | 113 |
| TS8-427 | | Moskito TI-SI1 with STERNA Cable | Data + Power | (consult factory) | N/A | Santoprene, Black | 3A611.x | 114 |

VIDEO / GPS POWER AND DATA CABLES

| Part No. | NATO Stock No. NSN | Description | Electrical Function | Weight | Standard Cable Length | Cable Finish | ECCN / EAR | Page No. |
|-----------------|-------------------------|---|---------------------|-------------------|-----------------------|------------------------------|------------|----------|
| 808-040 | 5995-01-668-8854 | DAGR GPS Cable | Data + Power | 104g | 32" | O.D. Nomex / Blk. Santoprene | 3A611.x | 116 |
| 808-045 | | TacROVER-P SIR 2.0 Cable | Data + Power | 104g | 32" | O.D. Nomex / Blk. Santoprene | 3A611.x | 117 |
| 808-068 | | TacROVER-P SIR 2.5 Cable | Data | (consult factory) | 6" | O.D. Nomex | 3A611.x | 118 |
| 808-043 | 5995-01-693-7025 | TacROVER-P SIR 2.5 Video Cable | Data | 70g | 24" | O.D. Nomex | 3A611.x | 119 |
| 808-082 | 5995-01-693-6951 | TacROVER-E SIR 2.5 Cable | Data + Power | (consult factory) | 33" | O.D. Nomex / Blk. Santoprene | 3A611.x | 120 |
| 808-067 | 5995-01-693-7053 | TacROVER-P SIR 2.5 Cable | Data + Power | 106g | 33" | O.D. Nomex / Blk. Santoprene | 3A611.x | 121 |
| TS8-463U | | TacROVER-E SIR 2.5 Cable with "U" Bend | Data + Power | (consult factory) | 20" | Santoprene, Black | 3A611.x | 122 |
| 808-152 | | TacROVER-P SIR 2.5 with TAC-EYE Cable | Data + Power | 108g | 24" | O.D. Nomex / Blk. Santoprene | 3A611.x | 123 |
| 808-151 | | Tactical Net Rover Cable | Data + Power | 112g | 24" | O.D. Nomex / Blk. Santoprene | 3A611.x | 124 |
| TS8-404 | | Tactical Net Rover Cable with TAC-EYE Adapter | Data + Power | (consult factory) | 24" | Santoprene, Black | 3A611.x | 125 |
| 808-171 | | Tactical Net Rover Cable with Thru Power | Data + Power | 112g | 24" | O.D. Nomex / Blk. Santoprene | 3A611.x | 126 |
| TS1-037 | | Cable for 808-151 and TS8-404 TNR Cables | Data | (consult factory) | 5.50" | Santoprene, Black | 3A611.x | 127 |
| 808-224 | 5995-01-683-6023 | StrikeHawk Digital Cable | Data | 100g | 24" | Nomex, O.D. | 3A611.x | 128 |
| TS8-424 | | Remote Secure Receiver-to-PAN Port Cable | Data | (consult factory) | 30" | Santoprene, Black | 3A611.x | 129 |
| TS8-467 | | Teledyne FLIR BH3 Hangar Cable, Power / Data | Data + Power | (consult factory) | 34" | Santoprene, Black | 3A611.x | 130 |
| TS3-072 | | MOHOC IP Camera Cable | Data + Power | (consult factory) | 34" | Santoprene, Black | 3A611.x | 131 |



DAGR GPS Navigation Cable



StrikeHawk Digital Adapter Cable



BATTLE-TESTED

STAR-PAN™

Selection Guide
Hubs, cables, adapters, and accessories



STAR-PAN-TO-HOST/EUD CABLES, ADAPTERS, AND ACCESSORIES

| Part No. | NATO Stock No. NSN | Description | Electrical Function | Weight | Standard Length | Cable / Device Finish | ECCN / EAR | Page No. |
|----------------------------|-------------------------|--|---------------------|-------------------|-----------------|---------------------------------|------------|----------|
| 808-101 | 5995-01-683-8691 | Panasonic® Toughpad® FZ-M1/FZ-B2 Adapter | Data + Power | 62g | N/A | Black Zinc-Nickel | 3A611.x | 133 |
| 808-103 | 5935-01-683-8596 | Toughpad® FZ-M1/FZ-B2 Adapter with Cable | Data + Power | 92g | 12" | Santoprene / Zinc-Nickel, Black | 3A611.x | 134 |
| TS3-003 | | TS3-003 Panasonic® FZ-M1 Voltage-Regulated Adapter Cable | Data + Power | (consult factory) | 24" | Santoprene / Zinc-Nickel, Black | 3A611.x | 135 |
| 808-281 | 5995-01-683-1103 | Juggernaut QD USB-C Host Cable with Power Delivery | Data + Power | 72g | 24" | Santoprene, Black | 3A611.x | 136 |
| TS1-020 | | Juggernaut USB-C to Mighty Mouse Plug cable | Data | (consult factory) | 19" | Santoprene / Zinc-Nickel, Black | 99 | 137 |
| TS3-052 | | Juggernaut USB-C Charging Cable with Power Delivery | Data + Power | (consult factory) | 24" | Santoprene, Black | 3A611.x | 138 |
| TS1-095 | | 6P7 Receptacle-to-Receptacle Cable | Data + Power | (consult factory) | 24" | Santoprene / Zinc-Nickel, Black | 99 | 139 |
| TS1-096 | | 6P7 Plug-to-Plug Cable | Data + Power | (consult factory) | 24" | Santoprene / Zinc-Nickel, Black | 99 | 140 |
| TS1-081 | | Juggernaut S21 IMPCT USB-C to Mighty Mouse Plug cable | Data + Power | (consult factory) | 19" | Santoprene / Zinc-Nickel, Black | 99 | 141 |
| 808-135 | 5995-01-668-8832 | USB-C Cable | Data | 76g | 21" | Santoprene, Black | 3A611.x | 142 |
| 808-232 | 5995-01-688-2121 | USB-C Host Cable with Power Delivery | Data + Power | 68g | 24" | Santoprene, Black | 99 | 143 |
| 808-102 | | USB On-The-Go Cable | Data | 62g | 6" | Santoprene, Black | 3A611.x | 144 |
| 808-096, -160, -271 | | Host Mode OTG Adapters | Data + Power | 8g | N/A | Black Zinc-Nickel | 3A611.x | 145 |
| 8071-3628 | 5935-01-682-9578 | Host Mode OTG Adapter, USB Detect, Grounded ID Pin | Data + Power | 8g | N/A | Black Zinc-Nickel | 3A611.x | 146 |
| TS1-034 | | USB-C Host Mode Adapter | Data + Power | 8g | N/A | Black Zinc-Nickel | 3A611.x | 147 |
| TS1-009 | | USB-C Charge Adapter | Data + Power | 8g | N/A | Black Zinc-Nickel | 99 | 148 |
| 808-259 | | Gender Changer Adapter (plug connectors) | Data + Power | 11g | N/A | Black Zinc-Nickel | 99 | 149 |
| 808-260 | | Gender Changer Adapter (receptacle connectors) | Data + Power | (consult factory) | N/A | Black Zinc-Nickel | 99 | 150 |
| 808-080 | | STAR-PAN IV Radio Adapter | Data + Power | (consult factory) | 8" | Polyurethane, Black | 3A611.x | 151 |
| 808-274 | | 6-6 Plug-to-Plug cable | Data + Power | (consult factory) | 8" | Polyurethane, Black | 3A611.x | 152 |
| TS1-106 | | USB-C to Mighty Mouse-Interfaced Device Cable | | (consult factory) | 8" | TPE, Black | 99 | 153 |



Panasonic ToughPad® Adapter



Host Mode Adapters and Gender-Changers



USB-C EUD Charging Cable

BATTLE-TESTED

STAR-PAN™

Selection Guide

Hubs, cables, adapters, and accessories



COMMERCIAL PROTOCOL CABLES, ADAPTERS, AND ACCESSORIES

| Part No. | NATO Stock No. NSN | Description | Electrical Function | Weight | Standard Cable Length | Cable Finish | ECCN / EAR | Page No. |
|----------------|-------------------------|-----------------------------|---------------------|-------------------|--------------------------|---------------------|---------------|-------------|
| 808-079 | 5995-01-682-9409 | USB Type A Cable | Data | 26g | 18" | Santoprene, Black | 3A611.x | 157 |
| 808-145 | 5995-01-679-0913 | USB Type A EUD Cable | Data + 5V Power | 26g | 18" | Santoprene, Black | 3A611.x | 158 |
| 808-053 | 5995-01-674-0054 | PAN Port to USB-A Cable | Data + 5V Power | 18g | 5" | Santoprene, Black | 3A611.x | 159 |
| 808-111 | | On-The-Go USB Adapter Cable | Data + Power | (consult factory) | 5" | Santoprene, Black | 3A611.x | 160 |
| TS3-033 | | DB-9 RS-232 Cable | Data + Power | 88g | 24" | Polyurethane, Black | 3A611.x | 161 |
| 808-078 | 5995-01-682-9477 | RJ45 Plug Cable | Data | 80g | 24" | Santoprene, Black | 3A611.x | 162 |
| 808-084 | 5995-01-693-7143 | RJ45 Receptacle Cable | Data | 94g | 30" | Nomex, O.D. | 3A611.x | 163 |

SOFT GOODS: MISSION KIT BAG AND POUCHES

| Part No. | Description | Weight | Length | Material/Color | ECCN / EAR | Page No. |
|----------------|---|-------------------|---|-------------------------------------|------------|-------------|
| TS4-011 | Mission Kit Bag with Pouches - Complete Kit | 2.08 lbs. | L = 20" W = 14" D = 2.5" (outer Kit Bag) | Cordura/Black | 99 | 163 |
| TS4-001 | Mission Kit Bag | .9 lbs | L = 20" W = 14" D = 2.5" | Cordura/Black | 99 | 163 |
| TS4-002 | Large Pouch | .18 lbs. | W = 18" H = 4" | Cordura/Black | 99 | 164 |
| TS4-003 | Square Pouch | .9 lbs. | W = 10" H = 10" | Cordura/Black | 99 | 164 |
| TS4-004 | Medium Pouch | .1 lbs. | W = 9.5" H = 5" | Cordura/Black | 99 | 164 |
| TS4-017 | STAR-PAN II MOLLE Pouch | 1.1 oz. | L = 3.5" W = 2.5" H = 1" | Cordura/Desert Tan or Camouflage | 99 | 165 |
| TS4-018 | STAR-PAN IV MOLLE Pouch | (consult factory) | (consult factory) | Cordura/Desert Tan or Camouflage | 99 | 165 |
| TS4-009 | STAR-PAN VI MOLLE Pouch | 4 oz. | L = 5" W = 7" H = 1.5" | Cordura/Desert Tan or Camouflage | 99 | 165 |
| TS4-028 | MISSION MANAGER MOLLE Pouch | (consult factory) | L = 4" W = 2" | Cordura/Desert Tan or Camouflage | 99 | 165 |
| TS4-022 | Connector dust caps | (consult factory) | various | Tan or Black | 99 | 166 |
| TS4-024 | Dust Caps for in-line cable receptacles | (consult factory) | various | Tan or Black | 99 | 167 |
| TS4-025 | Dust Caps for in-line cable plugs | (consult factory) | various | Tan or Black | 99 | 167 |



Mission Kit Bag
(**TS4-011** complete kit shown)



Pouches



**STAR-PAN VI
MOLLE Pouch**