 


SERIES 802 2400M / 3500 PSI Ultraminiature Subsea Connectors


Contact arrangements




SUBSEA/SHALLOW WATER: AQUAMOUSE™




| Shell Size 5 | | Shell Size 6 | | | | Shell Size 7 | | |
|------------------------|------------------------|--------------------------|------------------------|------------------------|------------------------|-----------------------|--------------------------|-------------------------|
| 5-3 | 6-1 | 6-23 | 6-4 | 6-6 | 6-7 | 7-1 | 7-25 | 7-10 |
| 3 Size #23 Contacts | 1 Size #16 Contacts | 3 Size #20HD Contacts | 4 Size #23 Contacts | 6 Size #23 Contacts | 7 Size #23 Contacts | 1 Size #12 Contact | 5 Size #20HD Contacts | 10 Size #23 Contacts |

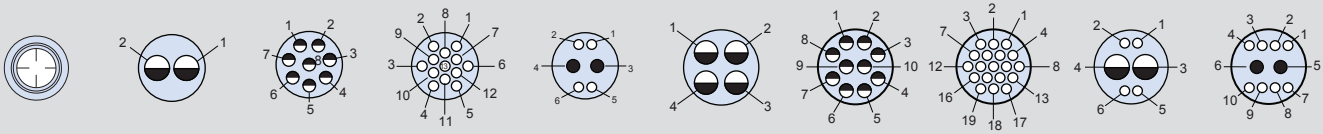

| Shell Size 8 | | | | | Shell Size 9 | | | | |
|----------------------|------------------------|--------------------------|-------------------------|--------------------------------------|------------------------|---------------------------|-------------------------|--------------------------------------|--------------------------------------|
| 8-1 | 8-2 | 8-28 | 8-13 | 8-200 | 9-4 | 9-210 | 9-19 | 9-200 | 9-201 |
| 1 Size #8 Contact | 2 Size #16 Contacts | 8 Size #20HD Contacts | 13 Size #23 Contacts | 4 Size #23 2 Size #20 Contacts | 4 Size #16 Contacts | 10 Size #20hd Contacts | 19 Size #23 Contacts | 4 Size #23 2 Size #16 Contacts | 8 Size #23 2 Size #20 Contacts |

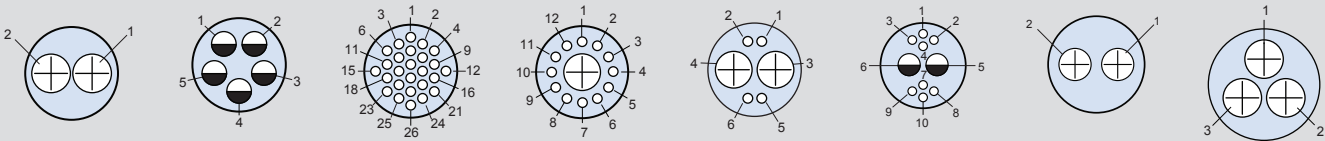

| Shell Size 10 | | | | | | Shell Size 12 | |
|------------------------|------------------------|-------------------------|---------------------------------------|--------------------------------------|--------------------------------------|------------------------|------------------------|
| 10-2 | 10-5 | 10-26 | 10-200 | 10-201 | 10-202 | 12-2 | 12-3 |
| 2 Size #12 Contacts | 5 Size #16 Contacts | 26 Size #23 Contacts | 12 Size #23 1 Size #12 Contacts | 4 Size #23 2 Size #12 Contacts | 8 Size #23 2 Size #16 Contacts | 2 Size #12 Contacts | 3 Size #12 Contacts |

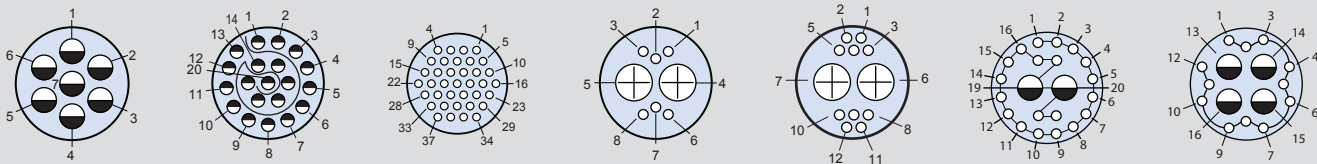


| Shell Size 12 | | | | | | |
|------------------------|---------------------------|-------------------------|--------------------------------------|---------------------------------------|---------------------------------------|---------------------------------------|
| 12-7 | 12-220 | 12-37 | 12-200 | 12-201 | 12-202 | 12-203 |
| 7 Size #16 Contacts | 20 Size #20HD Contacts | 37 Size #23 Contacts | 6 Size #23 2 Size #12 Contacts | 10 Size #23 2 Size #12 Contacts | 20 Size #23 2 Size #16 Contacts | 12 Size #23 4 Size #16 Contacts |

Standard PCB footprints begin on page 7
Hybrid PCB footprints begin on page 24


*All arrangements with #12 contacts available
with keyed Twinax contacts. Use mode code -688

Contact Legend


#23 ◦ #20HD ◐ #20 ● #16 ◑ #12 ⊕ #8 ⊕

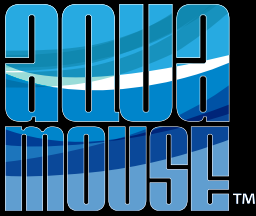


SERIES 802 2400M / 3500 PSI Ultraminiature Subsea Connectors Contact arrangements

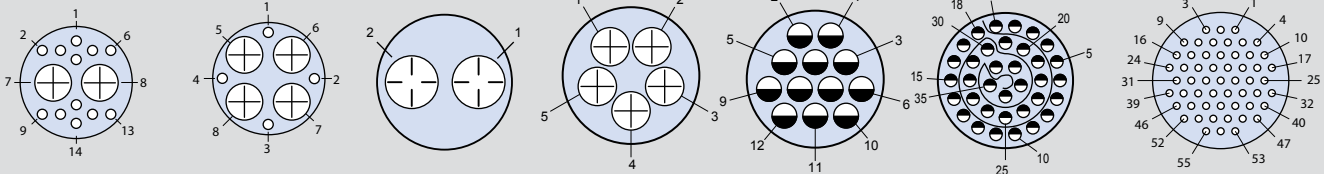

| Shell Size 14 | | | | | | |
|---------------------------------------|--------------------------------------|-----------------------|------------------------|-------------------------|-------------------------|-------------------------|
| 12-204 | 12-205 | 14-2 | 14-5 | 14-12 | 14-235 | 14-55 |
| 12 Size #23 2 Size #12 Contacts | 4 Size #23 4 Size #12 Contacts | 2 Size #8 Contacts | 5 Size #12 Contacts | 12 Size #16 Contacts | 35 Size #20 Contacts | 55 Size #23 Contacts |

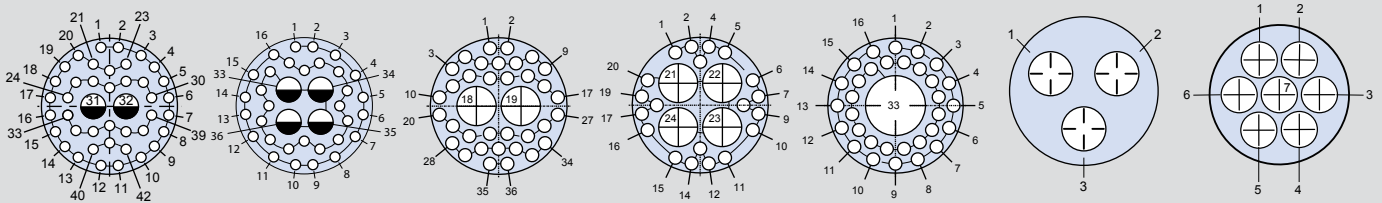

| Shell Size 14 | | | | | Shell Size 15 | |
|---------------------------------------|---------------------------------------|---------------------------------------|---------------------------------------|--------------------------------------|-----------------------|------------------------|
| 14-204 | 14-205 | 14-206 | 14-207 | 14-208 | 15-3 | 15-7 |
| 2 Size #16 40 Size #23 Contacts | 4 Size #16 32 Size #23 Contacts | 34 Size #23 2 Size #12 Contacts | 20 Size #23 4 Size #12 Contacts | 32 Size #23 1 Size #8 Contacts | 3 Size #8 Contacts | 7 Size #12 Contacts |

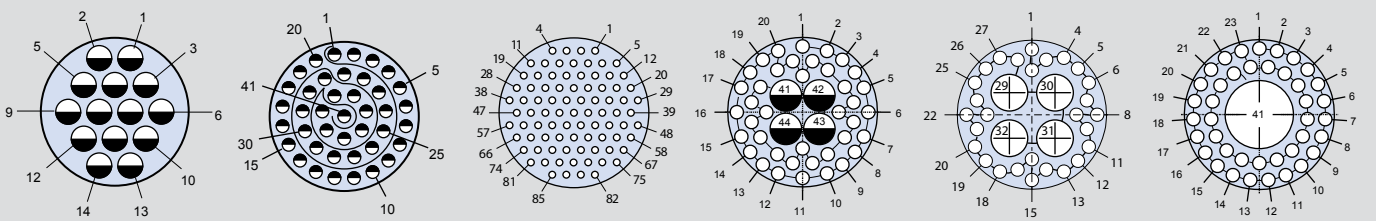

| | | | | | |
|-------------------------|---------------------------|-------------------------|---------------------------------------|---------------------------------------|--------------------------|
| 15-14 | 15-241 | 15-85 | 15-203 | 15-204 | 15-205 |
| 14 Size #16 Contacts | 41 Size #20HD Contacts | 85 Size #23 Contacts | 40 Size #23 4 Size #16 Contacts | 28 Size #23 4 Size #12 Contacts | 1 Size #8 40 Size #23 |

Standard PCB footprints begin on page 7
Hybrid PCB footprints begin on page 24





*All arrangements with #12 contacts available
with keyed Twinax contacts. Use mode code -688

Contact Legend

#23 ◯ #20HD ◯ #20 ● #16 ◐ #12 ⊕ #8 ⊕

SUBSEA SHALLOW WATER: AQUAMOUSE™



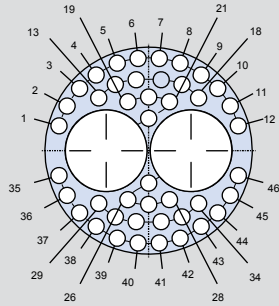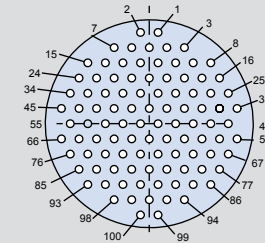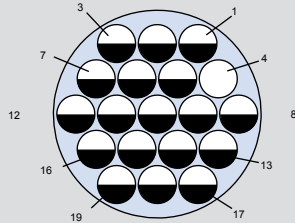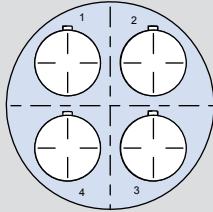

Shell Size 19

19-4

4 Size #8
Contacts

19-19





19 Size #16
Contacts

19-100

100 Size #23
Contacts

19-201

2 Size #8
44 Size #23
Contacts

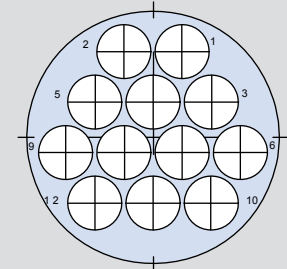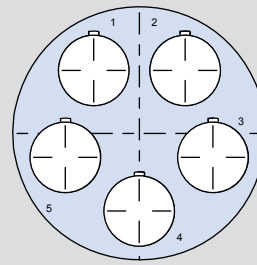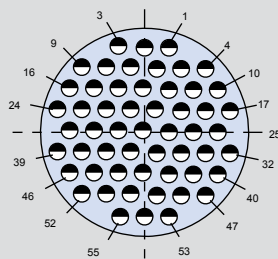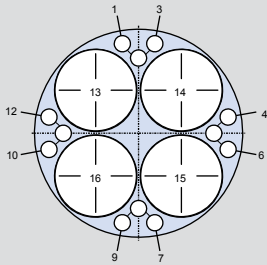

Shell Size 21

19-202

4 Size #8
12 Size #23
Contacts

19-255





55 Size #20HD
Contacts

21-5

5 Size #8
Contacts

21-12

12 Size #12
Contacts

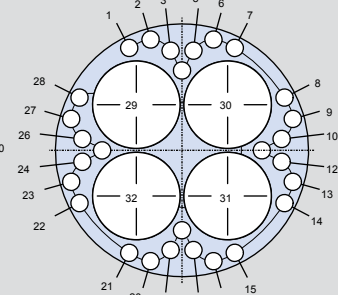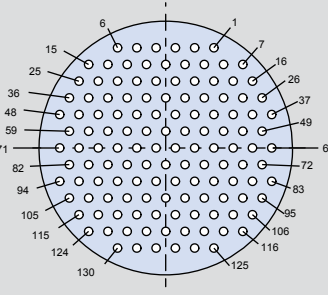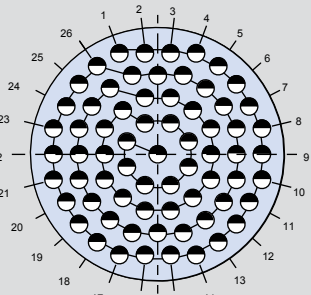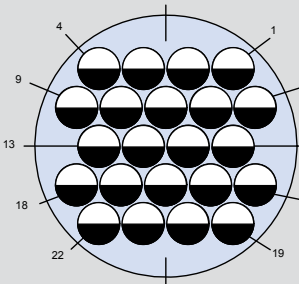

Shell Size 21

21-22

22 Size #16
Contacts

21-269

69 Size #20HD
Contacts

21-130

130 Size #23
Contacts

21-200

4 Size #8
28 Size #23
Contacts

Standard PCB footprints begin on page 7
 Hybrid PCB footprint layouts begin on page 24

*All arrangements with #12 contacts available
 with keyed Twinax contacts. Use mode code -688

Contact Legend
 #23 ◯ #20HD ◯ #20 ● #16 ◯ #12 ⊕ #8 ⊕