

121-191


Annular Polymer-Core Convulsed Tubing  
with External Braid and Jacket



Series 72  
Annular Tubing

Tubing with one EMI/RFI Braided shield plus jacket for use in environmental applications

How To Order

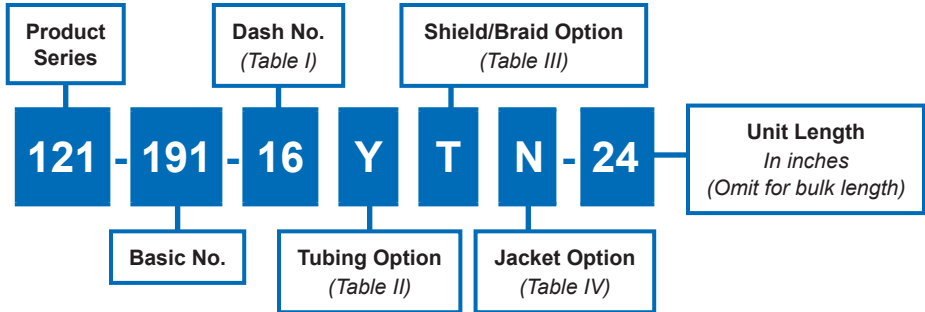


| Dash No | A Inside Dia |             | B Outside Dia |
|---------|--------------|-------------|---------------|
|         | Min          | Max         | Max           |
| 06      | .17 (4.3)    | .19 (4.8)   | .51 (12.9)    |
| 09      | .24 (6.1)    | .28 (7.1)   | .61 (15.5)    |
| 12      | .33 (8.4)    | .37 (9.4)   | .71 (18.0)    |
| 14      | .40 (10.1)   | .44 (11.2)  | .78 (19.8)    |
| 16      | .45 (11.4)   | .50 (12.7)  | .85 (21.6)    |
| 20      | .57 (14.5)   | .62 (15.7)  | .96 (24.4)    |
| 24      | .69 (17.5)   | .75 (19.1)  | 1.13 (28.7)   |
| 28      | .81 (20.6)   | .87 (22.1)  | 1.27 (32.2)   |
| 32      | .93 (23.6)   | 1.00 (25.4) | 1.39 (35.3)   |
| 40      | 1.18 (30.0)  | 1.25 (31.8) | 1.63 (41.4)   |
| 48      | 1.43 (36.3)  | 1.50 (38.1) | 1.90 (48.3)   |
| 52      | 1.56 (39.6)  | 1.63 (41.4) | 2.04 (51.8)   |

|   |  |
|---|--|
| Y | Kynar/Thermally stabilized                     |
| V | PVDF/Not thermally stabilized                  |
| S | G-FLEX Siltem/Medium duty - natural color only |

|   |                      |
|---|----------------------|
| T | Tin/Copper           |
| C | Stainless Steel      |
| N | Nickel Copper        |
| L | ArmorLite™           |
| D | Dacron               |
| M | Nomex                |
| E | AmberStrand® 100%    |
| F | AmberStrand® 75%/25% |
| - | No braid             |

|    |                         |
|----|-------------------------|
| N  | Neoprene                |
| H  | Hypalon                 |
| E  | EPDM                    |
| V  | Viton                   |
| B  | Duralectric, black      |
| G  | Bluejacket, Gray        |
| TN | Duralectric, Desert Tan |

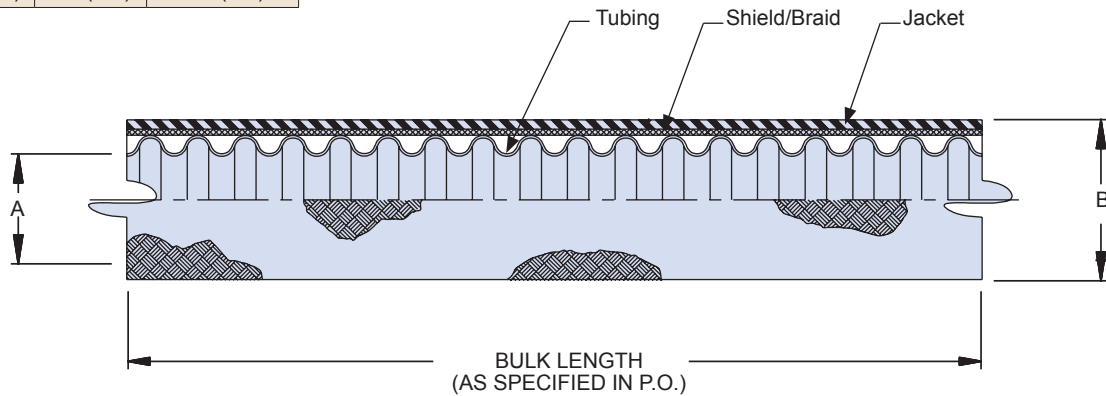

| Dash No. | Max Length Per Pkg. |
|----------|---------------------|
| 09& 12   | 200 ft (60m)        |
| 16 - 52  | 100 ft (30m)        |

Packaging

121-191 braided and jacketed conduit is typically supplied in 50 foot lengths. Longer lengths are available—consult factory for additional information. Unless otherwise specified, Glenair packages optimal lengths of product based on weight, size, and commercial carrier specifications. If necessary, consult factory for additional information on package weight restrictions.