


SERIES 86 SealTac Tactical Push-Pull Connectors

861-001 cable jumper receptacle-to-receptacle



How To Order	
Sample Part Number	861-001 ZR 08-19 A -36
Series	861-001 = spring contact push-pull receptacle-to-receptacle overmolded cable jumper
Material / Finish	ME = Aluminum Electroless Nickel ZR = Aluminum / Black Zinc Nickel Z1 = 316 Stainless Steel / Passivated
Shell Size - Insert Arrangement	06-7, 07-10, 08-19 (See Table)
Key Position	A = Normal B = Pos. B C = Pos. C D = Pos. D E = Pos. E F = Pos. F
Cable Length	Cable length, "L" in Inches, min.

MIGHTY MOUSE SEALTAC

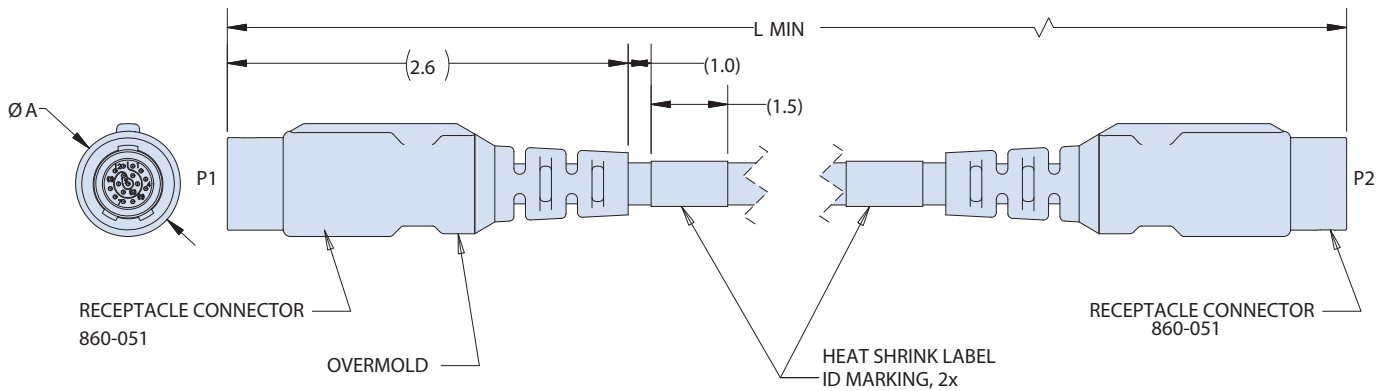

Dimensions	
Shell Size/ Ins. Arr.	ØA Max
06-7	.590 (15.0)
07-10	.630 (16.0)
08-19	.710 (18.0)

Shell Size / Contact Arrangements		
06-7 shell size 6, 7 contacts	07-10 shell size 7, 10 contacts	08-19 shell size 8, 19 contacts

MATERIAL / FINISH

- Receptacle connectors IAW 860-051
- Overmold: TPV elastomer, black
- Cable: TPV jacket, NiCu EMI braid, 26AWG stranded wire

TECHNICAL SPECIFICATIONS

- Temperature range -40°C to +75°C
- 100% electrical testing, pin-pin and pin-shell DWV: 500 VAC min, IR = 200 MΩ min at 500 VDC, and continuity check