




SERIES 86 SealTac Tactical Push-Pull Connectors

861-002 cable jumper plug-to-plug

MIGHTY MOUSE SEALTAC



How To Order					
Sample Part Number	861-002	ZR	08-19	A	-36
Series	861-002 = target contact push-pull plug-to-plug overmolded cable jumper				
Material / Finish	ME = Aluminum Electroless Nickel ZR = Aluminum / Black Zinc Nickel Z1 = 316 Stainless Steel / Passivated				
Shell Size - Insert Arrangement	06-7, 07-10, 08-19 (See Table)				
Key Position	A = Normal B = Pos. B C = Pos. C D = Pos. D E = Pos. E F = Pos. F				
Cable Length	Cable length, "L" in Inches, min.				

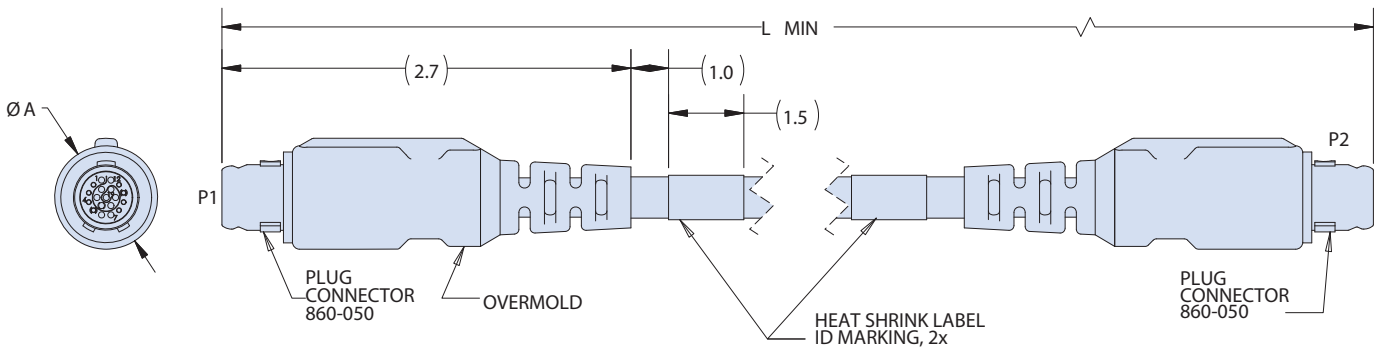

Dimensions	
Shell Size/ Ins. Arr.	ØA Max
06-7	.590 (15.0)
07-10	.630 (16.0)
08-19	.710 (18.0)

Shell Size / Contact Arrangements		
06-7 shell size 6, 7 contacts	07-10 shell size 7, 10 contacts	08-19 shell size 8, 19 contacts

MATERIAL / FINISH

- Plug connectors IAW 860-050
- Overmold: TPV elastomer, black
- Cable: TPV jacket, NiCu EMI braid, 26AWG stranded wire

TECHNICAL SPECIFICATIONS

- Temperature range -40°C to +75°C
- 100% electrical testing, pin-pin and pin-shell DWV: 500 VAC min, IR = 200 MΩ min at 500 VDC, and continuity check