

## BNC-SMA Adapters


RF CONNECTOR ADAPTERS

### 852-189 BNC MALE TO SMA FEMALE ADAPTER



**BNC Male / SMA Female.** 852-189 adapter connects female BNC to SMA male connector. Stainless steel SMA body, nickel-plated brass BNC body and coupling nut. Gold-plated BeCu contact, PTFE insulator, nickel-plated brass wave washer. Silicone gasket.

- Operating temperature: -40 °C to +120 °C
- Frequency range: DC - 4 GHz
- VSWR: 1.20 maximum
- Impedance: 50 ohm

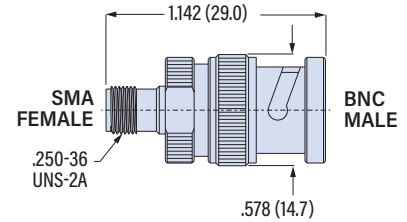

#### PART NUMBER

852-189