





# REVERSE-BAYONET QUICK-DISCONNECT ITS-NG™ Nuclear-Grade Containment Area Class 1E Connectors Cable Clamps and Backshells



## EXTEND ADAPTER FOR PLUG CONNECTORS for Use with Cable Clamp IT3057-XX A/B/C

How To Order			
Sample Part Number	NGIT	101393-323	FK1
Product Series	NGIT = Nuclear-grade Backshell		
Shell Size Designator	See Table below		
Material/Finish	FK1 = Material AISI 316L Stainless Steel, Passivated		

Part Numbers, Shell Size, Thread & Dimensions					
Part Number	Shell Size	A Thread	L Max.	ØQ ±0.2	V Thread
NGIT 101393-123	10 SL	0.6250 - 24UNEF	36.0 (1.42)	20.0 (0.79)	0.6250 - 24UNEF
NGIT 101393-143	14 S	0.7500 - 20UNEF	50.0 (1.97)	23.0 (0.91)	0.7500 - 20UNEF
NGIT 101393-163	16 S	0.8750 - 20UNEF	50.0 (1.97)	25.0 (0.98)	0.8750 - 20UNEF
NGIT 101393-173	16	0.8750 - 20UNEF	54.0 (2.13)	25.0 (0.98)	0.8750 - 20UNEF
NGIT 101393-183	18	1.0000 - 20UNEF	56.0 (2.20)	29.5 (1.16)	1.0000 - 20UNEF
NGIT 101393-203	20	1.1250 - 18UNEF	56.0 (2.20)	32.0 (1.26)	1.1875 - 18UNEF
NGIT 101393-223	22	1.2500 - 18UNEF	56.0 (2.20)	35.0 (1.38)	1.1875 - 18UNEF
NGIT 101393-243	24	1.3750 - 18UNEF	56.0 (2.20)	38.5 (1.52)	1.4375 - 18UNEF
NGIT 101393-283	28	1.6250 - 18UNEF	61.0 (2.40)	45.0 (1.77)	1.4375 - 18UNEF
NGIT 101393-323	32	1.8750 - 16UN	61.0 (2.40)	53.2 (2.09)	1.7500 - 18UNS
NGIT 101393-363	36	2.0625 - 16UN	61.0 (2.40)	57.4 (2.26)	2.0000 - 18UNS
NGIT 101393-403	40	2.3125 - 16UN	61.0 (2.40)	63.2 (2.49)	2.2500 - 16UN

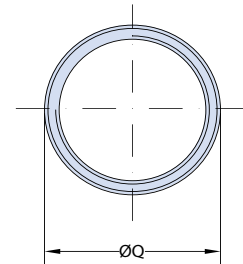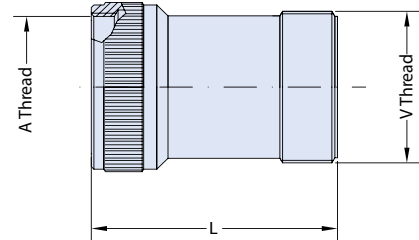


### NOTES

To make wiring easier an extender backshell is available for use with cable clamp.

## WATERPROOF CABLE CLAMP FOR JACKETED CABLE or Wires Protected by Tubing

How To Order			
Sample Part Number	NGIT	3057-20C	FK1
Product Series	NGIT = Nuclear-grade Backshell		
Shell Size Designator	See Table below		
Material/Finish	FK1 = Material AISI 316L Stainless Steel, Passivated		

Part Numbers, Shell Size, Sleeving, Dimensions & Thread					
Part Number	Shell Size	Sleeve to Use	ØB		F Thread
			Min.	Max.	
NGIT 3057- 4C	10 SL	IT 3420 - 4A	2.38 (0.09)	7.93 (0.31)	0.6250 - 24UNEF
NGIT 3057- 6C	14 S	IT 3420 - 4A / 6A	5.84 (0.23)	11.12 (0.44)	0.7500 - 20UNEF
NGIT 3057- 8C	16 S - 16	IT 3420 - 6A / 8A	8.00 (0.31)	13.48 (0.53)	0.8750 - 20UNEF
NGIT 3057-10C	18	IT 3420 - 6A / 10A	9.60 (0.38)	15.87 (0.62)	1.0000 - 20UNEF
NGIT 3057-12C	20 - 22	IT 3420 - 8A / 12A	11.30 (0.44)	19.00 (0.75)	1.1875 - 18UNEF
NGIT 3057-16C	24 - 28	IT 3420 - 8A / 12A / 16A	15.50 (0.61)	23.80 (0.94)	1.4375 - 18UNEF
NGIT 3057-20C	32	IT 3420 - 12A / 16A / 20A	23.40 (0.92)	31.75 (1.25)	1.7500 - 18UNS
NGIT 3057-24C	36	IT 3420 - 16A / 18A / 24A	23.40 (0.92)	35.00 (1.38)	2.0000 - 18UNS
NGIT 3057-28C	40	IT 3420 - 16A / 20A / 28A	29.90 (1.18)	41.25 (1.62)	2.2500 - 16UN

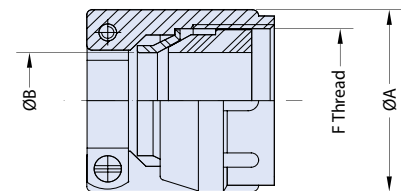

### NOTES

Gasket made of High Insulation Synthetic rubber.

SUPER ITS: HARSH ENVIRONMENT

A