

SERIES 77 Autoshrink™ T Cold-Action Shrink Boots and Tubing



777-030 Straight Wall Tubing




Straight wall tubing provides a quick, reliable method of repairing the outer jacket of Duraelectric™ cables while providing mechanical and environmental protection from damage and debris. High temperature tubing operates continuously from -65°C to 300°C. Material is water-tight when used in conjunction with 779-008 adhesive. Choose tubing based on cable diameter.

How to Order				
Sample Part Number	777	-030	-0500	-6
Product Series	777 = Autoshrink™			
Basic Part Number	-030 = Straight wall tubing, Autoshrink™ T			
Size Code	See dimensions table			
Length	Dimension in one inch increments; 8 inches maximum			

NOTES

1. High-temperature silicone adhesive 779-008 sold separately
2. Length in expanded form may be less than length after unrestricted shrinkage
3. Material:
 - Tubing: silicone, red

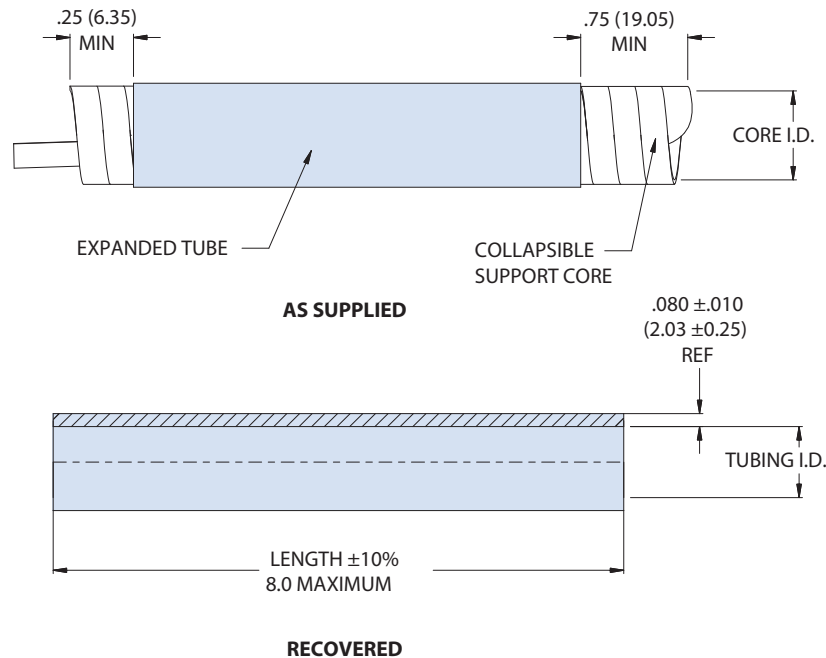

Dimensions				
Size Code	Tube I.D after unrestricted shrinkage (Ref)	As Supplied Core I.D. (Ref)	Reference Wire Bundle Range	
			Min	Max
0250	.250 (6.4)	.50 (12.9)	.30 (7.1)	.45 (11.4)
0500	.500 (12.7)	1.18 (30.0)	.60 (14.7)	1.05 (26.7)