

Four material types for high UV plus LSZH, advanced fluid resistance, extreme temperature tolerance, and subsea use



Autoshrink™ Performance Data


Autoshrink™ D Material Performance 2
 Autoshrink™ F Material Performance 3
 Autoshrink™ S Material Performance 4
 Autoshrink™ T Material Performance 5
 779-005 Autoshrink™ D and 779-006 Autoshrink™ F Adhesive 6
 779-007 Autoshrink™ S and 779-008 Autoshrink™ T Adhesive 7

Autoshrink™ D UV-Resistant / LSZH Shrink Boots and Tubing



777-005 Standard or 777-006 Short Straight Boot 8
 777-005 Right Angle, Lipped Boot 9
 777-005 45° Angle, Lipped Boot 10
 777-008 Straight, Lipped Long Tail Boot 11
 777-008 Right Angle, Lipped Long Tail Boot 12
 809-432 Straight, Lipped Boot for Mighty Mouse 13
 809-432 Right Angle, Lipped Boot for Mighty Mouse 14
 809-432 45° Angle, Lipped Boot for Mighty Mouse 15
 777-015 Straight, Lipless Boot 16
 777-015 Right Angle, Lipless Boot 17
 777-033 Straight, Lipless boot for SuperFly 18
 777-033 Right Angle, Lipless Boot for SuperFly 19
 777-004 Straight Wall Tubing 20
 777-035 Small Diameter, Straight Wall Tubing 21
 777-023 Shielded, Straight Wall Tubing 22
 777-024 Shielded, Straight Wall Tubing with Ground Strap 23

Autoshrink™ F Advanced Fluid Resistant Shrink Boots and Tubing

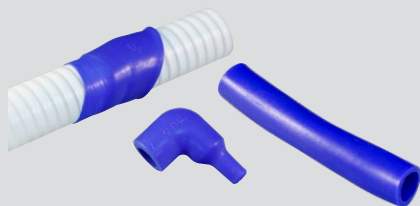

777-012 Standard or Short Straight Boot 24
 777-012 Right Angle, Lipped Boot 25
 777-012 45° Angle, Lipped Boot 26
 777-022 Straight Wall Tubing 27

Autoshrink™ T High-Temperature-Tolerant Shrink Boots and Tubing



777-025 Standard or Short Straight Boot 32
 777-025 Right Angle, Lipped Boot 33
 777-025 45° Angle, Lipped Boot 34
 777-030 Straight Wall Tubing 35