

# Miscellaneous Accessories


Jam Nuts, Splice Rings, Dummy Contacts, Grommet Nuts, Bushings

## M85049/139 Rubber Bushings for Cable Clamps





M85049/139 rubber bushings provide wire cushioning and protection. Install bushing under saddle bars of cable clamp. These bushings telescope into the next larger size. Use multiple bushings to reduce the inside diameter. Available with or without flange. These bushings are identical to the MS3420 specification. Black neoprene (-40 to +100 °C), red silicone (-70 to +200 °C) or blue fluorosilicone (-70 to +200 °C).

### WITH FLANGE

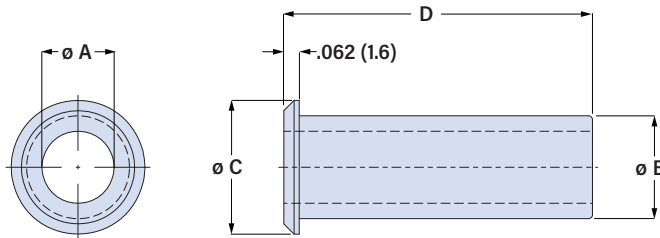

Size	Part No.			øA		øB		øC		D	
	Black Neoprene	Red Silicone	Blue Fluorosilicone	in	mm	in	mm	in	mm	in	mm
3	M85049/139-3	M85049/139-3C	M85049/139-3K	.130	3.3	.210	5.3	.379	9.6	2.875	73.0
4	M85049/139-4	M85049/139-4C	M85049/139-4K	.220	5.6	.302	7.7	.505	12.8	2.750	69.9
6	M85049/139-6	M85049/139-6C	M85049/139-6K	.312	7.9	.427	10.8	.619	15.7	2.625	66.7
8	M85049/139-8	M85049/139-8C	M85049/139-8K	.437	11.1	.552	14.0	.744	18.9	2.500	63.5
10	M85049/139-10	M85049/139-10C	M85049/139-10K	.562	14.3	.615	15.6	.889	22.6	2.375	60.3
12	M85049/139-12	M85049/139-12C	M85049/139-12K	.625	15.9	.740	18.8	1.084	27.5	2.250	57.2
16	M85049/139-16	M85049/139-16C	M85049/139-16K	.750	19.1	.927	23.5	1.314	33.4	2.125	54.0
20	M85049/139-20	M85049/139-20C	M85049/139-20K	.937	23.8	1.240	31.5	1.598	40.6	2.000	50.8
24	M85049/139-24	M85049/139-24C	M85049/139-24K	1.250	31.8	1.365	34.7	1.847	46.9	1.875	47.6
28	M85049/139-28	M85049/139-28C	M85049/139-28K	1.375	34.9	1.614	41.0	2.085	53.0	1.750	44.5
32	M85049/139-32	M85049/139-32C	M85049/139-32K	1.624	41.2	1.864	47.3	2.335	59.3	1.625	41.3
40	M85049/139-40	M85049/139-40C	M85049/139-40K	1.874	47.6	2.364	60.0	2.835	72.0	1.500	38.1

### NO FLANGE

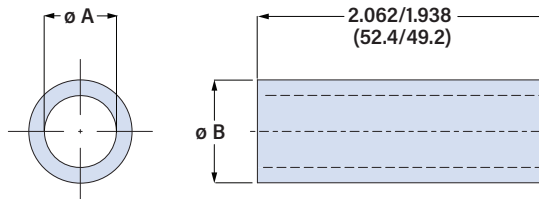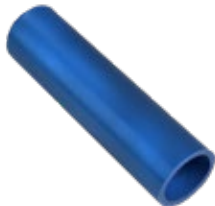

Size	Part No.			øA		øB	
	Black Neoprene	Red Silicone	Blue Fluorosilicone	in	mm	in	mm
3	M85049/139-3A	M85049/139-3D	M85049/139-3L	.125	3.2	.210	5.3
4	M85049/139-4A	M85049/139-4D	M85049/139-4L	.219	5.6	.302	7.7
6	M85049/139-6A	M85049/139-6D	M85049/139-6L	.312	7.9	.427	10.8
8	M85049/139-8A	M85049/139-8D	M85049/139-8L	.438	11.1	.531	13.5
10	M85049/139-10A	M85049/139-10D	M85049/139-10L	.438	11.1	.615	15.6
12	M85049/139-12A	M85049/139-12D	M85049/139-12L	.541	13.7	.740	18.8
16	M85049/139-16A	M85049/139-16D	M85049/139-16L	.750	19.1	.927	23.5
18	M85049/139-18A	M85049/139-18D	M85049/139-18L	.938	23.8	1.115	28.3
20	M85049/139-20A	M85049/139-20D	M85049/139-20L	.938	23.8	1.240	31.5
24	M85049/139-24A	M85049/139-24D	M85049/139-24L	1.125	28.6	1.365	34.7
28	M85049/139-28A	M85049/139-28D	M85049/139-28L	1.250	31.8	1.614	41.0
32	M85049/139-32A	M85049/139-32D	M85049/139-32L	1.625	41.3	1.865	47.4
40	M85049/139-40A	M85049/139-40D	M85049/139-40L	1.875	47.6	2.365	60.1