




SERIES 80
Mighty Mouse Connectors and Cables
Standard Contact Layouts and DWV



Contact Size and Quantity						Specifications			Contact Arrangement					
#23	20	#20HD	#16	#12	#8	Max Current Rating (Amps)	AWG Accepted	Vac DWV	Series 800	Series 801	Series 802	Series 803	Series 804	Series 805
3						3	#22-#28	750	5-3	5-3	5-3	5-3	5-3	N/A
4						3	#22-#28	750	6-4	6-4	6-4	6-4	6-4	8-4
6						3	#22-#28	750	6-6	6-6	6-6	6-6	6-6	8-6
7						3	#22-#28	750	6-7	6-7	6-7	6-7	6-7	8-7
10						3	#22-#28	750	7-10	7-10	7-10	7-10	7-10	9-10
13						3	#22-#28	750	8-13	8-13	8-13	8-13	8-13	10-13
19						3	#22-#28	750	9-19	9-19	9-19	9-19	9-19	11-19
26						3	#22-#28	750	10-26	10-26	10-26	10-26	10-26	12-26
31						3	#22-#28	750	N/A	11-31	N/A	11-31	11-31	13-31
37						3	#22-#28	750	12-37	13-37	12-37	12-37	12-37	15-37
55						3	#22-#28	750	N/A	16-55	14-55	14-55	14-55	18-55
85						3	#22-#28	750	N/A	17-85	15-85	N/A	N/A	19-85
100						3	#22-#28	750	N/A	19-100	19-100	N/A	N/A	21-100
130						3	#22-#28	750	N/A	21-130	21-130	N/A	N/A	23-130
		3				5	#20-#24	1000	6-23	6-23	6-23	6-23	6-23	8-23
		5				5	#20-#24	1000	7-25	7-25	7-25	7-25	7-25	9-25
		8				5	#20-#24	1000	8-28	8-28	8-28	8-28	8-28	10-28
		10				5	#20-#24	1000	9-210	9-210	9-210	9-210	9-210	11-210
		20				5	#20-#24	1000	12-220	13-220	12-220	12-220	12-220	15-220
		35				5	#20-#24	1000	N/A	16-235	14-235	14-235	14-235	18-235
		41				5	#20-#24	1000	N/A	17-241	15-241	N/A	N/A	19-241
		55				5	#20-#24	1000	N/A	19-255	19-255	N/A	N/A	21-255
		69				5	#20-#24	1000	N/A	21-269	21-269	N/A	N/A	23-269
			1			10	#16-#20	1800	6-1	6-1	6-1	6-1	6-1	8-1
			2			10	#16-#20	1800	8-2	8-2	8-2	8-2	8-2	10-2
			4			10	#16-#20	1800	9-4	9-4	9-4	9-4	9-4	11-4
			5			10	#16-#20	1800	10-5	10-5	10-5	10-5	10-5	12-5
			7			10	#16-#20	1800	12-7	13-7	12-7	12-7	12-7	15-7
			12			10	#16-#20	1800	N/A	16-12	14-12	14-12	14-12	18-12
			14			10	#16-#20	1800	N/A	17-14	15-14	N/A	N/A	19-14
			19			10	#16-#20	1800	N/A	19-19	19-19	N/A	N/A	21-19
			22			10	#16-#20	1800	N/A	21-22	21-22	N/A	N/A	23-22
				1		17	#12-#14	1800	7-1	7-1	7-1	7-1	7-1	9-1
				2		17	#12-#14	1800	10-2	10-2	10-2	10-2	10-2	12-2
				2		17	#12-#14	1800	12-2	13-2	12-2	12-2	12-2	15-2
				3		17	#12-#14	1800	12-3	13-3	12-3	12-3	12-3	15-3
				4		17	#12-#14	1800	N/A	16-4	14-4	14-4	14-4	18-4
				5		17	#12-#14	1800	N/A	16-5	14-5	14-5	14-5	18-5
				7		17	#12-#14	1800	N/A	17-7	15-7	N/A	N/A	19-7
				12		17	#12-#14	1800	N/A	21-12	21-12	N/A	N/A	23-12
					1	33	#8	1800	N/A	8-1	8-1	N/A	N/A	10-1
					2	33	#8	1800	N/A	16-2	14-2	N/A	N/A	18-2
					3	33	#8	1800	N/A	17-3	15-3	N/A	N/A	19-3
					4	33	#8	1800	N/A	19-4	19-4	N/A	N/A	21-4
					5	33	#8	1800	N/A	21-5	21-5	N/A	N/A	23-5

General Information and Reference

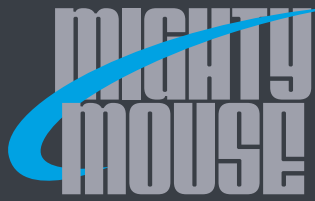

SERIES 80
Mighty Mouse Connectors and Cables
Combo Contact Layouts and DWV



Contact Size and Quantity						Specifications		Contact Arrangement					
#23	20	#20HD	#16	#12	#8	Vac Test Rating	AWG Accepted	Series 800	Series 801	Series 802	Series 803	Series 804	Series 805
12				1		750	#22-#28	10-200	10-200	10-200	10-200	10-200	12-200
4				2		750	#22-#28	10-201	10-201	10-201	10-201	10-201	12-201
6				2		750	#22-#28	12-200	13-200	12-200	12-200	12-200	15-200
10				2		750	#22-#28	12-201	13-201	12-201	12-201	12-201	15-201
4			2			750	#22-#28	9-200	9-200	9-200	9-200	9-200	11-200
8			2			750	#22-#28	10-202	10-202	10-202	10-202	10-202	12-202
4	2					750	#22-#28	8-200	8-200	8-200	8-200	8-200	10-200
8	2					750	#22-#28	9-201	9-201	9-201	9-201	9-201	11-201
20			2			1300	#22-#28	12-202	13-202	12-202	12-202	12-202	15-202
12			4			1300	#22-#28	12-203	13-203	12-203	12-203	12-203	15-203
40			2			1300	#22-#28	N/A	16-204	14-204	14-204	14-204	18-204
32			4			1300	#22-#28	N/A	16-205	14-205	14-205	14-205	18-205
40			4			1300	#22-#28	N/A	17-203	15-203	N/A	N/A	19-203
58			4			1300	#22-#28	N/A	17-206	15-206	N/A	N/A	19-206
12				2		1300	#22-#28	12-204	13-204	12-204	12-204	12-204	15-204
4				4		1300	#22-#28	12-205	13-205	12-205	12-205	12-205	15-205
34				2		1300	#22-#28	N/A	16-206	14-206	14-206	14-206	18-206
20				4		1300	#22-#28	N/A	16-207	14-207	14-207	14-207	18-207
28				4		1300	#22-#28	N/A	17-204	15-204	N/A	N/A	19-204
18					1	1300	#22-#28	N/A	11-201	11-201	N/A	11-201	13-201
32					1	1300	#22-#28	N/A	16-208	14-208	N/A	14-208	18-208
40					1	1300	#22-#28	N/A	17-205	15-205	N/A	N/A	19-205
44					2	1300	#22-#28	N/A	19-201	19-201	N/A	N/A	21-201
12					4	1300	#22-#28	N/A	19-202	19-202	N/A	N/A	21-202
28					4	1300	#22-#28	N/A	21-200	21-200	N/A	N/A	23-200