
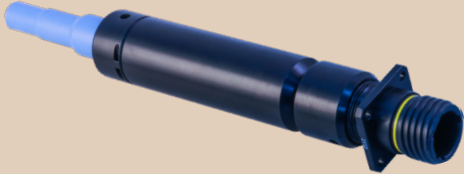


MIL-PRF-28876 Fiber Optic Connectors Selection Guide



Wall Mount Receptacles		
	MIL-PRF-28876 M28876/1 Wall Mount Receptacle without Backshell	M28876/2 Wall Mount Receptacle with Straight Backshell M28876/3 Wall Mount Receptacle with 45° Backshell (not shown) M28876/4 Wall Mount Receptacle with 90° Backshell (not shown)

Jam Nut Mount Receptacles		
	MIL-PRF-28876 M28876/11 Jam Nut Mount Receptacle without Backshell	M28876/12 Jam Nut Mount Receptacle with Straight Backshell M28876/13 Jam Nut Mount Receptacle with 45° Backshell (not shown) M28876/14 Jam Nut Mount Receptacle with 90° Backshell (not shown)

Plug Connectors		
	MIL-PRF-28876 M28876/6 Plug without Backshell	M28876/7 Plug with Straight Backshell M28876/8 Plug with 45° Backshell (not shown) M28876/9 Plug with 90° Backshell (not shown)

In-Line Receptacles	Wall Mount Receptacle Mounting Gaskets	Dust Covers
MIL-PRF-28876 M28876/5 In-Line Receptacle with Straight Backshell	M28840 and Commercial M28840/24 Mounting Gasket (Mil-Spec) 930-006 Mounting Gasket (commercial)	MIL-PRF-28876 M28876/10 Plug Cover M28876/15 Receptacle Cover

Dimensions in Inches (millimeters) are subject to change without notice.