

# SPACE-GRADE MIL-DTL-24308 D-SUB BACKSHELLS


## Lightweight, Low-Profile EMI/RFI Backshell with Qwik-Ty option



Solid shell, long side cable entry - 557-108



How To Order					
<b>Sample Part Number</b>	<b>557-108</b>	<b>M</b>	<b>2</b>	<b>04</b>	<b>C S</b>
<b>Series</b>	Side Entry backshell				
<b>Finish Symbol</b>	<b>M</b> = Electroless Nickel <b>Z2</b> = Gold Plate				
<b>Shell Size</b>	<b>1, 2, 3, 4, 5</b> (Table I)				
<b>Entry Size</b>	<b>01, 02, 03, 04, 05, 06, 07, 08, 09</b> (Table II)				
<b>Jackscrew Option</b>	<b>A</b> = Hex Socket Head and Clip <b>C</b> = Fillister Head and Clip <b>CR</b> = Phillips Head and Clip <b>Omit</b> for none				
<b>Qwik-Ty Option</b>	<b>S</b> = With Qwik-Ty strain relief arm <b>Omit</b> for none				

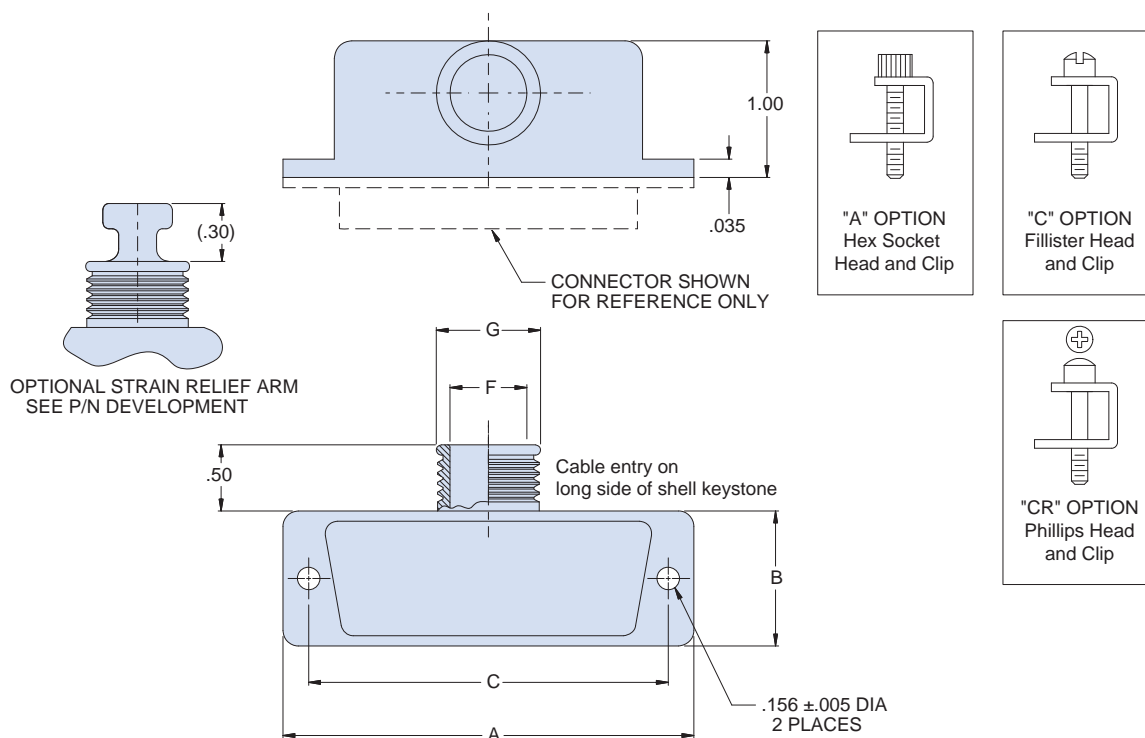

Entry Size	F Dia.	G Dia.
01	.125 (3.18)	.205 (5.21)
02	.187 (4.75)	.267 (6.78)
03	.270 (6.86)	.350 (8.89)
04	.290 (7.37)	.370 (9.40)
05	.312 (7.92)	.392 (9.96)
06	.395 (10.03)	.475 (12.07)
07	.420 (10.67)	.500 (12.70)
08	.500 (12.70)	.580 (14.73)
09	.529 (13.44)	.609 (15.47)

Shell Size	A	B	C ±.005 (0.1)
1	1.203 (30.6)	.500 (12.7)	.984 (25.0)
2	1.531 (38.9)	.500 (12.7)	1.312 (33.3)
3	2.078 (52.8)	.500 (12.7)	1.852 (47.0)
4	2.718 (69.0)	.500 (12.7)	2.500 (63.5)
5	2.625 (66.7)	.609 (15.5)	2.406 (61.1)

### MATERIAL/FINISH

Backshell: Aluminum alloy  
Hardware: CRES / passivated