



 
MICRO USB 2.0 Series 801 Mighty Mouse



801-089 and 801-090 Receptacle Adapter with USB Micro "AB" Female-to-Female Interface



Receptacle with Micro "AB" Front and Rear Female Interface



Receptacle and Rear View of Micro "AB" Female Interface


How To Order				
Sample Part Number	801-089	-02 MUSB	-M	A
Series	801-089 = Shield Termination Porch 801-090 = Accessory Threads			
Shell Style*	01 = In Line Receptacle 07 = Jam Nut Rear Mount Receptacle 02 = Square Flange Front or Rear Mount Receptacle			
Shell Material and Finish*	NF = AL/Cadmium, Olive Drab MT = AL/Nickel PTFE		M = AL/Electroless Nickel ZNU = AL/Black Zinc Nickel	
Shell Key Positions*	A, B, C, D, E, F			

*See Section A for recommended panel cutout, alternate keyway positions, and additional finishes. Mates with Glenair plugs 801-082, 801-083, 801-087, and 801-088

801-089-01 AND 801-090-01 INLINE RECEPTACLE ADAPTER, SHELL SIZE 8

805-089-01 Receptacle with Shield Termination Porch


801-090-01 Receptacle with Accessory Thread

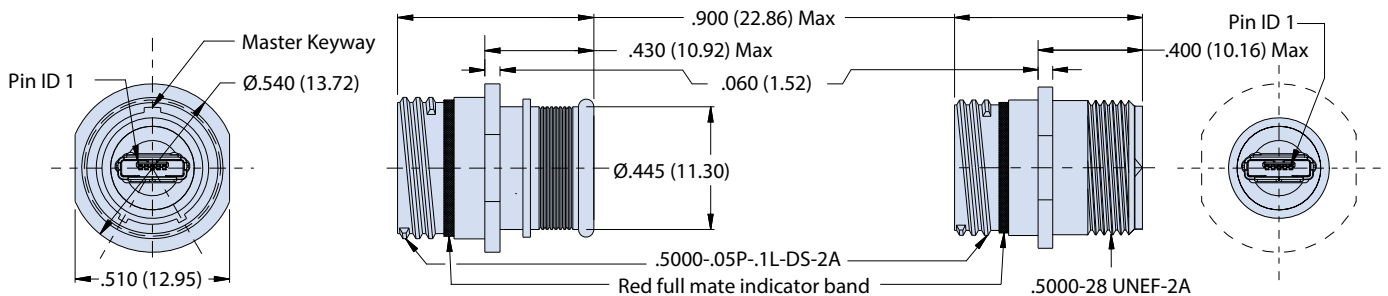

801-089-02 AND 801-090-02 SQ FLANGE RECEPTACLE ADAPTER, SHELL SIZE 8

805-089-02 Receptacle with Shield Termination Porch

801-090-02 Receptacle with Accessory Thread

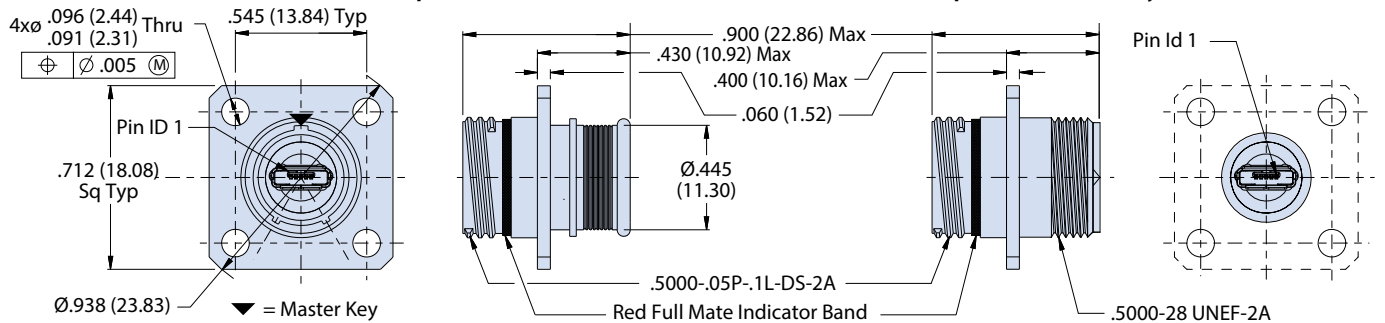

801-089-07 AND 801-090-07 JAM NUT RECEPTACLE WITH, SHELL SIZE 8

805-089-07 Receptacle with Shield Termination Porch

801-090-07 Receptacle with Accessory Thread

