



RJ45 AND USB 2.0 Contacts, Tools, and Accessories




Series IPT Protective Covers for Wall Mount and Jam Nut Receptacle Connectors


Series IPT (26482 Type)

How To Order				
Sample Part Number	IPT3181	-18	CF	F6
Series/Basic Part No.	IPT3181 = Receptacle Cover (See Note 1)			
Connector Size	16 = Shell Size 16	18 = Shell Size 18		
Lanyard Style	Wall Mount C = Sash Chain CF = Nylon Cord Z1C = Nylon Cord with Loose Terminal and Sleeve		Jam Nut Mount N = Sash Chain NF = Nylon Cord	
Finish Options	F6 = Aluminum/Black Polymer Electrocoat F11 = Aluminum/Electroless Nickel		F7 = Aluminum/Conductive Black Zinc Nickel Omit for Aluminum/Cadmium, Olive Drab	


IPT WALL MOUNT RECEPTACLE COVER

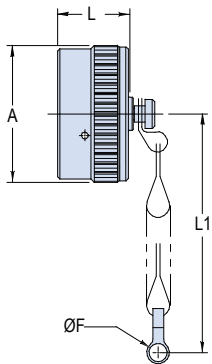


Example: IPT3181-18C
(Stainless Steel Sash Chain)

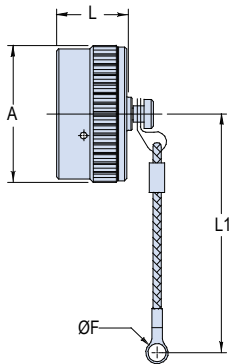


Example: IPT3181-18CF
(Nylon Cord)

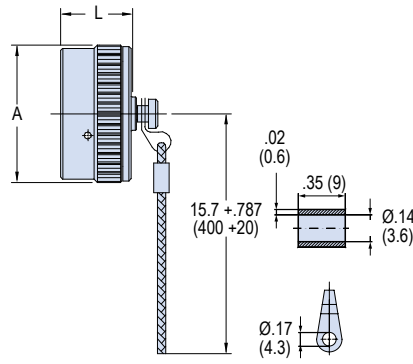


Example: IPT3181-18Z1C
(Nylon Cord with loose terminal and sleeve)

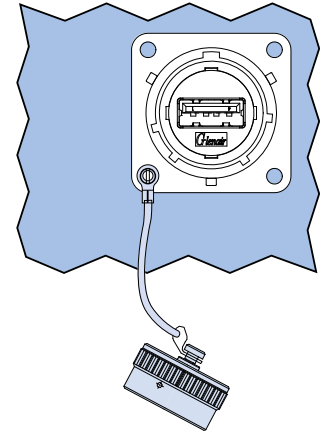


IPT JAM NUT MOUNT RECEPTACLE COVER

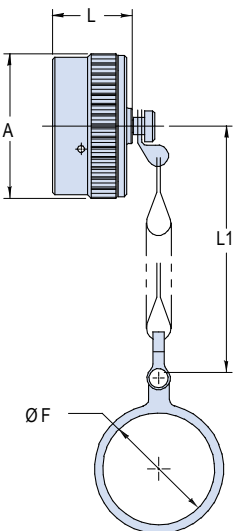

Example: IPT3181-18N
(Stainless Steel Sash Chain)

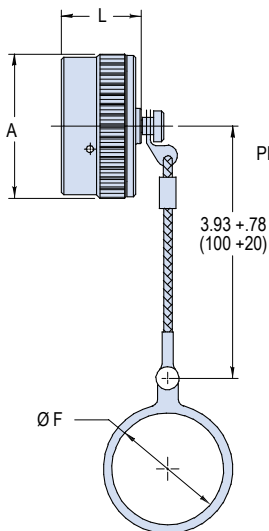

Example: IPT3181-18NF
(Nylon Cord)

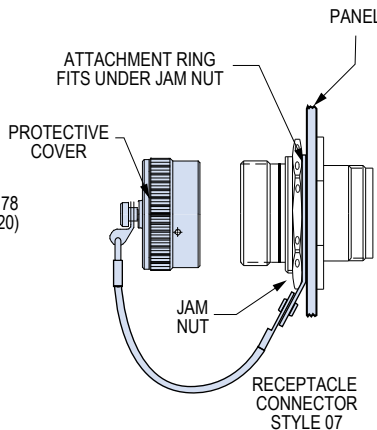

Dimensions for Wall Mount and Jam Nut Covers				
Shell Size	A Max.	ØF +.874 (+0.2) -.004 (-0.1)	L +.197 (+0.5) -0 (-0)	L1 Min.
16	1.256 (31.90)	.169 (4.3)	.563 (14.30)	3.5 (88.9)
18	1.378 (35.00)	.169 (4.3)	.563 (14.30)	3.5 (88.9)

NOTES

1. For plug covers contact factory