



DOWNHOLE HTHP High Pressure/High Temperature Connectors

707-0030 glass sealed receptacle

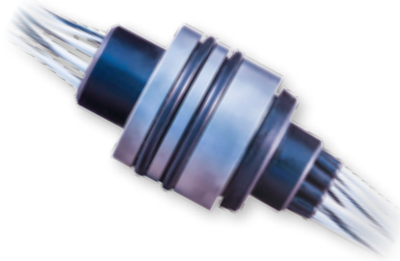

How To Order				
Sample Part Number	707-0030	-M	37	P
Series	707-0030			
Shell Size	G = Shell Size G M = Shell Size M See dimensions table			
Insert Arrangement	See page 20 and 21			
Pin Termination	P = Pin S = Solder Cup			

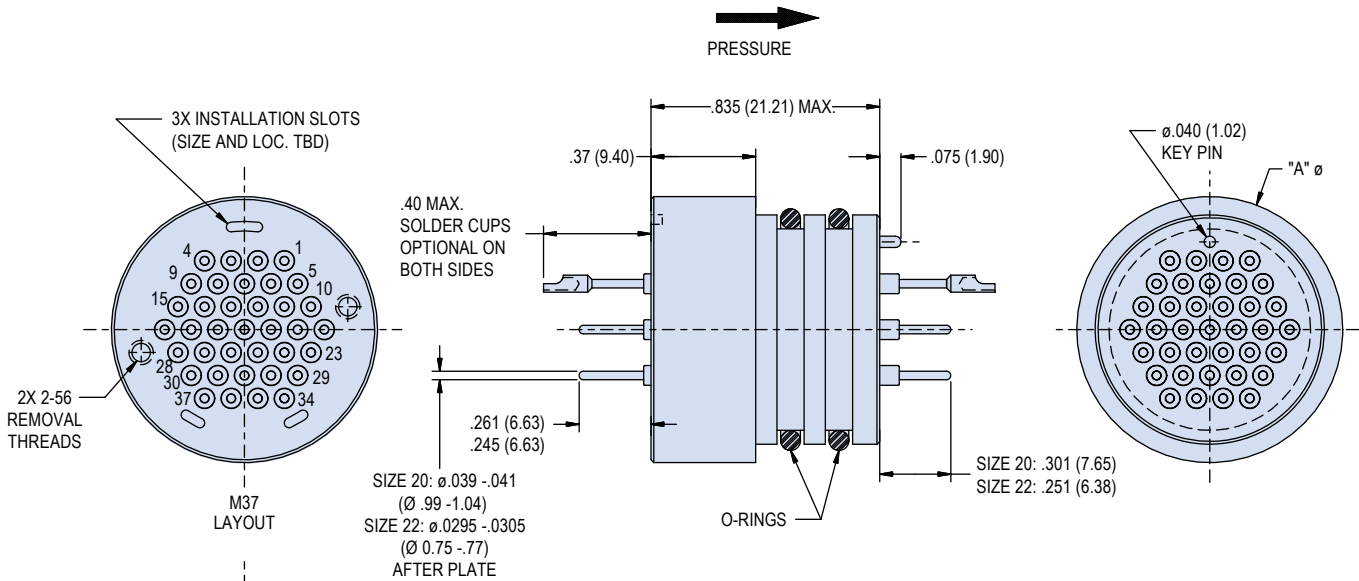

Dimensions			
Part No.	Contacts	"A" Ø	O-Ring
707-0030-G8*	8#20	.635 (16.13)	2-012
707-0030-M37*	37#22	.940 (23.88)	2-017

NOTES

- Dielectric withstand voltage: 1200VAC at sea level
- Insulation resistance: 5,000 megohms min @ 500 Vdc
- Operating temperature: -60°C to +260°C
- Hermeticity - $< 1 \times 10^{-7}$ sccHe/sec @ 1 atmosphere differential
- Pressure: 0 to 12,000 PSI

