

Specifications, contact arrangements and accessories



Male Bulkhead Connector

| Specifications | |
|-------------------------|--|
| Contacts | Copper Alloy, Gold-Plated |
| O-Rings | Nitrile |
| Nut, Washer | Stainless Steel |
| Cable | Neoprene insulation, Stranded Copper Conductor |
| Bulkhead Connector Body | Glass-Filled Epoxy |
| Voltage Rating | 600 VDC |
| Current Rating | See Contact Arrangements |
| Temperature Rating | -55°C to +105°C |

| Contact Arrangements and Current Rating | | |
|---|---|---|
| <p>2 contacts</p> <p>1 #10 Contact 1 #12 Contact 10 Amps G2</p> | <p>3 contacts</p> <p>1 #10 Contact 2 #12 Contact 10 Amps G3</p> | <p>4 contacts</p> <p>1 #12 Contact 3 #16 Contacts 7.5 Amps G4</p> |
| <p>5 contacts</p> <p>1 #10 Contact 4 #16 Contacts 7.5 Amps K5</p> | <p>6 contacts</p> <p>1 #10 Contact 5 #16 Contacts 7.5 Amps K5</p> | <p>8 contacts</p> <p>1 #10 Contact 7 #16 Contacts 6 Amps K8</p> |

ACCESSORIES

Locking Sleeves


Locking Sleeves enable a mated pair of cable assemblies to be locked together, preventing accidental unmating. Material: Delrin.



| Cable Part No. | Type | Sleeve Part No. |
|----------------|--------|-----------------|
| GL20G*P | Male | GL20G401 |
| GL20K*P | Male | GL20K403 |
| GL20G*S | Female | GL20G402 |
| GL20K*S | Female | GL20K404 |

O-Rings

Replacement O-Rings for bulkhead connectors. Material: Nitrile

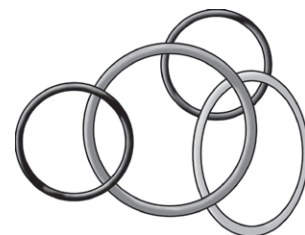

| Cable Part No. | O-Ring |
|----------------|--------|
| GL30G | 2-213 |
| GL30K | 2-217 |