





Style 1/Style 2 Backshells General Information and Direct Coupling "Y" Diameters

Maximum Cable/Wire Bundle Y Diameter for For Style 1 Backshells With Direct Coupling

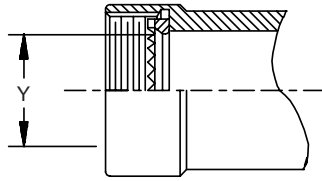

STYLE 1

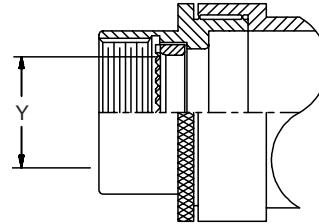

STYLE 2

SHELL SIZE	Y DIAMETER CONNECTOR DESIGNATOR				
	A	C	D	E	F
03	.43 (10.9)				
08	.36 (9.1)		.30 (7.6)	.34 (8.6)	.30 (7.6)
10	.49 (12.4)		.42 (10.7)	.43 (10.9)	.43 (10.9)
12	.61 (15.5)	.610 (15.44)	.55 (14.0)	.59 (15.0)	.55 (14.0)
14	.74 (18.8)	.736 (18.69)	.68 (17.3)	.68 (17.3)	.68 (17.3)
16	.86 (21.8)	.855 (21.71)	.80 (20.3)	.78 (19.8)	.80 (20.3)
18	.93 (23.6)	.980 (24.89)	.93 (23.1)	.91 (23.6)	.93 (23.6)
20	1.05 (26.7)	1.105 (28.06)	1.05 (26.7)	1.04 (26.4)	1.05 (26.7)
22	1.18 (30.0)	1.230 (31.24)	1.18 (30.0)	1.17 (29.7)	1.18 (30.0)
24	1.30 (33.0)	1.480 (37.59)	1.30 (33.0)	1.29 (32.8)	1.30 (33.0)
28	1.61 (40.9)	1.723 (43.76)			
32	1.86 (47.2)	1.910 (48.51)			
36	2.11 (53.6)	2.160 (54.86)			
40	2.36 (59.9)	2.470 (62.74)			
44	2.61 (66.3)	2.780 (70.61)			
48	2.86 (72.6)	2.870 (72.89)			
61	1.30 (33.0)				

DASH NO.	Y DIAMETER CONN. DESIGN. B	
01	.32 (8.1)	
02	.32 (8.1)	
03	.27 (6.9)	
04	.32 (8.1)	
05	.40 (10.2)	
06	.40 (10.2)	
07	.44 (11.2)	
08	.44 (11.2)	
09	.44 (11.2)	
10	.49 (12.4)	
11	.49 (12.4)	
12	.49 (12.4)	
13	.49 (12.4)	
14	.62 (15.7)	
15	.74 (18.8)	
16	.87 (22.1)	
17	.99 (25.1)	
18	.99 (25.1)	
20	1.12 (28.4)	
21	1.28 (32.5)	
22	1.49 (37.8)	
23	1.74 (44.2)	
24	1.74 (44.2)	
25	1.74 (44.2)	
26	1.86 (47.2)	
27	1.86 (47.2)	
28	1.93 (49.0)	
30	1.93 (49.0)	
31	2.18 (55.4)	
32	2.18 (55.4)	
33	2.18 (55.4)	
34	2.49 (63.2)	
35	2.74 (69.6)	
36	2.74 (69.6)	
37	2.62 (66.5)	

SHELL SIZE	Y DIAMETER CONNECTOR DESIGNATOR				
	H	J	K	L	S
08		.46 (11.7)	.24 (6.1)	.30 (7.6)	.30 (7.6)
09	.30 (7.6)				
10		.59 (15.0)	.30 (7.6)	.43 (10.9)	.43 (10.9)
11	.43 (10.9)		.39 (9.9)		
12			.40 (10.2)	.55 (14.0)	.55 (14.0)
13	.55 (14.0)		.40 (10.2)		
14		.84 (21.3)	.48 (12.2)	.68 (17.3)	.68 (17.3)
15	.68 (17.3)		.48 (12.2)		
16		.96 (24.4)	.60 (15.2)	.80 (20.3)	.80 (20.3)
17	.80 (20.3)		.60 (15.2)		
18		1.09 (27.7)	.72 (18.3)	.93 (23.6)	.93 (23.6)
19	.93 (23.6)				
20		1.21 (30.7)	.86 (21.8)	1.05 (26.7)	1.05 (26.7)
21	1.05 (26.7)				
22		1.34 (34.0)	.97 (24.6)	1.18 (30.0)	1.18 (30.0)
23	1.18 (30.0)				
24		1.46 (37.1)	1.08 (27.4)	1.30 (33.0)	1.30 (33.0)
25	1.30 (33.0)				
28			1.24 (31.5)		
32			1.51 (38.4)		
36			1.75 (44.5)		
40			1.86 (47.2)		

Metric dimensions (mm) are indicated in parentheses