
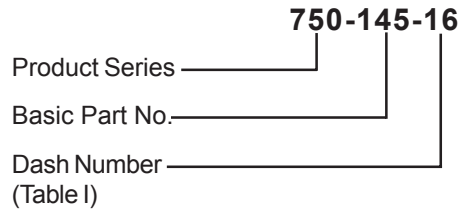


750-145
Series 75 EMI/RFI Shielded Metal-Core Conduit
Black Neoprene Jacketed for FIRST Adapters and Fittings

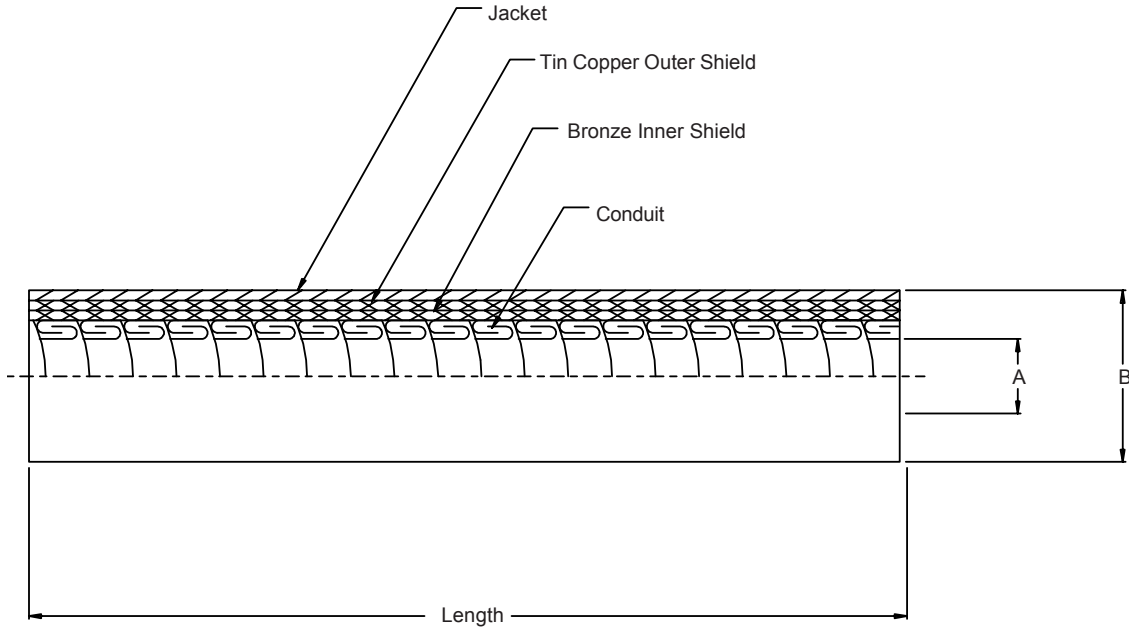

| TABLE I | | | |
|-------------|--------------|--------------|-----------------|
| Dash Number | A Dia Min | B Dia Min | Min Bend Radius |
| 16 | .485 (12.3) | .867 (22.0) | 2.250 (57.2) |
| 24 | .735 (18.7) | 1.100 (27.9) | 2.250 (57.2) |
| 32 | .985 (25.0) | 1.450 (36.8) | 3.750 (95.3) |
| 40 | 1.235 (31.4) | 1.677 (42.6) | 4.750 (120.7) |
| 48 | 1.485 (37.7) | 1.960 (49.8) | 5.500 (139.7) |

Sizes from .250 (6.4) to 3.00 (76.2) are available upon request

Metric Dimensions (mm) are indicated in parentheses.