




The Glenair Mighty Mouse

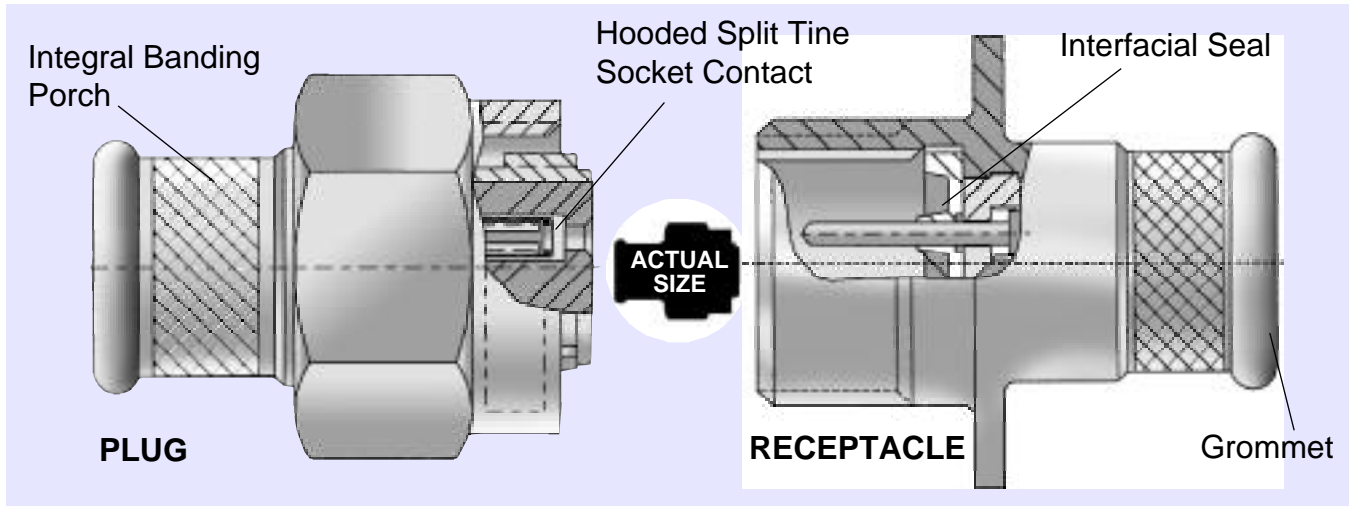

The Industry's Smallest Crimp and Poke Environmentally Sealed Connector

PRODUCT FACTS

- .076" Inch Contact Spacing
- Up to 85 Contacts
- Stainless Steel Retention Tines
- Integral Shield Banding
- Aluminum Shells
- Threaded Coupling
- #22 through #26 AWG Wire
- Crimp Termination
- Optional Stainless Steel Shell
- High Temperature

SPECIFICATIONS

- Voltage:** 500 VAC Sea Level
- Insulation Resistance:** 5,000 Megohms min.
- Current Rating:** 3.5 AMPS
- Durability:** 2,000 Cycles
- Operating Temperature:** -55°C. to +200° C.

APPLICATIONS

- Missile Systems
- Satellites
- Man-Portable Battlefield Gear
- Light Armored Vehicles
- Geophysical Exploration



Glenair, Inc.

1211 Air Way · Glendale, California 91201-2497

Telephone: 818-247-6000 · Facsimile: 818-500-9912 · EMail: sales@glenair.com

United Kingdom · Germany · Nordic · Italy · France

Revised 11-01-2000

www.glenair.com