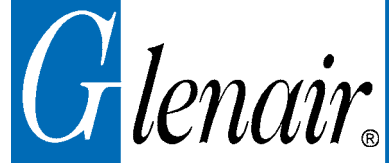


### Application Notes:

1. Dummy receptacle stowage fitting protects the plug connector when not in use.
2. Standard materials configuration consists of aluminum alloy. For platings, see TABLE II finish options.
3. A broad range of other front and rear connector accessories are available.  
See our website and/or contact the factory for complete information.

**ITS 05-XX  
Dummy Plug Stowage Receptacle**



**TABLE I: DUMMY PLUG RECEPTACLE SHELL SIZE & DIMENSIONS**

Shell Size	ØA +0 -0.1	K ±0.2	M +0.2 -0	R ±0.1	S +0.2	ØT +0.1 -0
<b>10 SL</b>	18.2	2.8	14.3	18.25	25.4	3.2
<b>14 S</b>	24.5	3.3	14.5	23.00	30.4	3.2
<b>16 S</b>	27.2	3.3	14.5	24.60	32.5	3.2
<b>16</b>	27.2	3.3	19.1	24.60	32.5	3.2
<b>18</b>	30.7	4.0	19.1	27.00	35.0	3.2
<b>20</b>	34.0	4.0	19.1	29.40	38.0	3.2
<b>22</b>	37.3	4.0	19.6	31.75	41.0	3.2
<b>24</b>	40.9	4.0	20.6	34.90	44.5	3.7
<b>28</b>	46.7	4.0	20.7	39.70	50.9	3.7
<b>32</b>	53.4	4.0	22.3	44.45	57.0	4.3
<b>36</b>	59.6	4.0	22.3	49.20	63.5	4.3
<b>40</b>	65.5	4.0	22.3	55.55	69.9	4.3

**TABLE II**

<b>FINISH OPTIONS</b>	
<b>Sym</b>	<b>Description and RoHS compliant (*)</b>
F2	Bright Nickel Plating (*)
F6	Black Electrodeposited Paint (*)
F7	Black Zn-Co Plating (*)
F8	Olive Drab Zn-Co Plating
F11	Electroless Nickel (*)
	<b>Omit for standard version (Cadmium Olive Drab Finish)</b>

