
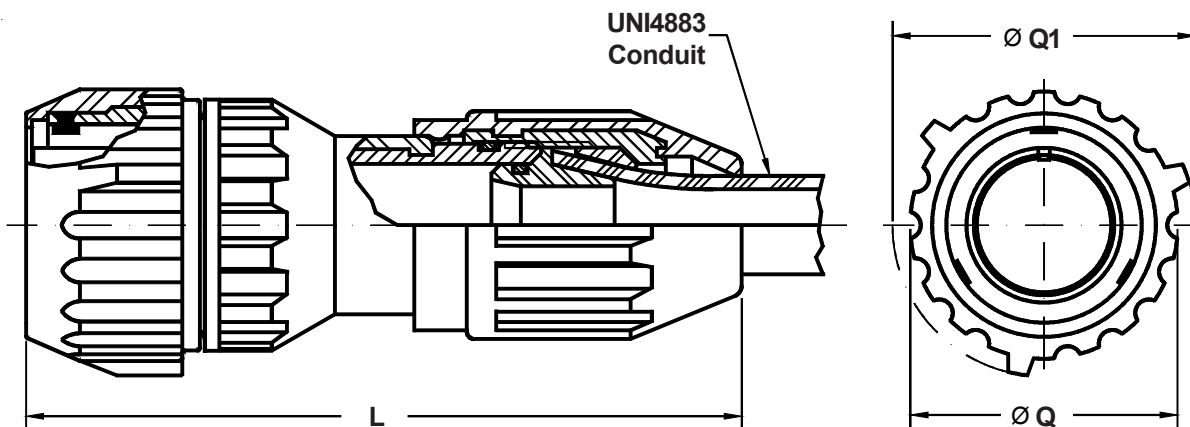


ITS 4106 (RGBF) and ITS 4106 (RRGBF) Straight Cylindrical Plug Connector with Rubber-Coated Threaded Adapter for Use with UNI4883 Conduit

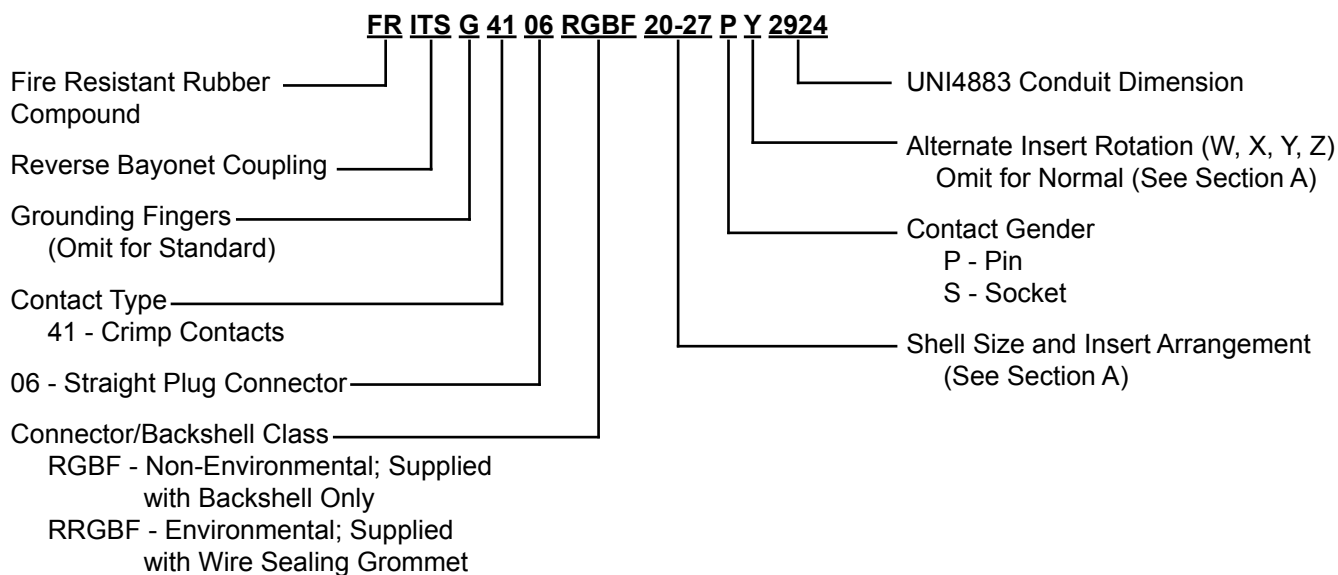

Application Notes:

1. Straight plug connector with rubber-coated threaded adapter for termination of UNI4883 conduit.
2. RGBF - Non-Environmental. Supplied with backshell only;
RRGBF - Environmental. Supplied with wire sealing grommet.
3. Standard materials configuration consists of aluminum alloy with plating ROHS compliant.
4. Standard contact material consists of copper alloy with silver plating or gold plating.
5. A broad range of additional connector accessories are available.
See our website and/or contact the factory for complete information.

**ITS 4106 (RGBF) and ITS 4106 (RRGBF)
Straight Cylindrical Plug Connector
with Rubber-Coated Threaded Adapter
for Use with UNI4883 Conduit**



TABLE I: DIMENSIONS

<i>Shell size</i>	L Max.	ØQ ±0.5	ØQ1 ±0.5	<i>Rubber conduits UNI 4883</i>
14 S	92	35.0	42.0	20x15 23x18 27x22 29x24 33x28 38x33 40x35 48x43 50x45
16 S	92	38.0	45.0	
16	98	38.0	45.0	
18	101	43.5	49.0	
20	119	46.0	51.5	
22	119	50.5	56.0	
24	143	54.0	60.0	
28	143	61.0	67.0	
32	145	68.0	76.0	
36	155	74.0	82.0	
40	157	80.0	88.0	

TABLE II: MODIFICATION CODES

CONTACT OPTIONS	
Sym	Description
B0	Connector less contacts
B1	Connector with gold plated contacts
Omit for version Silver plated	

