



800-013
Series 800 Mighty Mouse Hermetic Receptacles
with UN Mating Thread



Series 800 Hermetic Receptacles feature 304L stainless steel shells, fused vitreous glass insulators and Alloy 52 iron alloy contacts.

1 X 10⁻⁷ cc/second maximum helium leak rate.

Three Shell Styles: solder mount, jam nut or square flange.

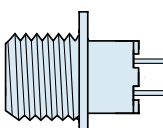
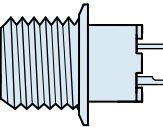
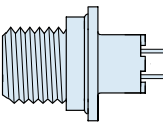
Solder Cup Contacts for wire attachment, or **PC Tail Contacts** for attachment to flexible or rigid circuits.

Series 800 Hermetic

C

HOW TO ORDER

Sample Part Number

800-013	-07	Z1	7-10	P	Z
Series	Shell Style	Shell Material / Finish	Shell Size- Insert Arrangement	Contact Type	Shell Key Position
800-013 Hermetic Receptacle	 -02 Square Flange	Z1 Stainless Steel / Passivated ZL Stainless Steel / Nickel Plated	See C-23 for Contact Arrangements	P Pin, Solder Cup	N Normal
	 -03 Solder Mount	*Titanium and Inconel® shell materials are available. Consult factory for ordering information.		C Pin, PC Tail	X Pos. X
	 -07 Jam Nut			S Socket, Solder Cup	Y Pos. Y
				D Sockets, PC Tail	Z Pos. Z