

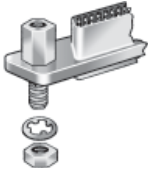
 
 
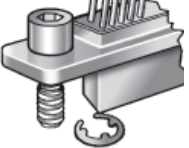
 
 
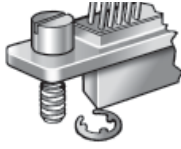
 
 
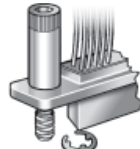
 
 
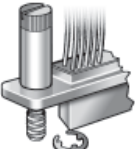
 
 
# MIL-DTL-83513/05 Micro-D Hardware Jackscrews and Jackposts



**Order One Kit Per Connector.** Jackpost kits contain two posts, two hex nuts and 2 lockwashers. Jackscrew kits contain 2 screws and 2 e-rings. Packaged one kit (two screws or posts) per bag.

**Mil Spec Hardware Kits** feature 300 series stainless steel.

## MIL SPEC JACKSCREW KITS

Configuration	Connector Size, Thread Size	Mil Spec Part Number	Glenair Part Number	Dimensions
 <b>Jackpost</b>	Sizes 9 to 69 Contacts. Mil Spec Size A to G #2-56 UNC	M83513/05-07	080-00-00-100	 <p>.190 / .185 (4.8 / 4.7)                  .125 (3.2) HEX                  .086 (2.2)-56 UNC-2B                  .490 / .460 (12.4 / 11.7)                  .086 (2.2)-56 UNC-2A</p>
	Size 100 Only Mil Spec Size H #4-40 UNC	M83513/05-17	080-00-00-101	 <p>.185 / .175 (4.7 / 4.4)                  .187 (4.7) HEX                  .112 (2.8)-40 UNC-2B                  .490 / .460 (12.4 / 11.7)                  .112 (2.8)-40 UNC-2A</p>
 <b>Hex Head Jackscrew Low Profile</b>	Sizes 9 to 69 Contacts. Mil Spec Size A to G #2-56 UNC-2A	M83513/05-02	080-00-00-502	 <p>.062 (1.57) HEX                  .125 (3.18) DIA                  .103 (2.62) MAX                  .083 (2.11) DIA                  #2-56 UNC 2A                  .090 (2.29) MIN PERFECT THD                  .258 (6.55) MAX</p>
	Size 100 Only Mil Spec Size H #4-40 UNC-2A	M83513/05-12	080-00-00-512	 <p>.062 (1.57) HEX                  .187 (4.75) DIA                  .098 (2.49)                  .140 (3.56) DIA                  #4-40 UNC 2A                  .110 (2.79) MIN PERFECT THD                  .292 (7.41) MAX</p>
 <b>Slot Head Jackscrew Low Profile</b>	Sizes 9 to 69 Contacts. Mil Spec Size A to G #2-56 UNC-2A	M83513/05-05	080-00-00-505	 <p>.083 (2.11) DIA                  .125 (3.18) DIA                  .103 (2.62) MAX                  #2-56 UNC 2A                  .090 (2.29) MIN PERFECT THD                  .258 (6.55) MAX</p>
	Size 100 Only Mil Spec Size H #4-40 UNC-2A	M83513/05-15	080-00-00-515	 <p>.140 (3.56) DIA                  .187 (4.75) DIA                  .098 (2.49)                  #4-40 UNC 2A                  .110 (2.79) MIN PERFECT THD                  .292 (7.41) MAX</p>
 <b>Hex Head Jackscrew Extended</b>	Sizes 9 to 69 Contacts. Mil Spec Size A to G #2-56 UNC-2A	M83513/05-03	080-00-00-503	 <p>.156 (3.96) DIA MAX                  .062 (1.57) HEX                  .610 (15.49) MAX                  .083 (2.11) DIA                  #2-56 UNC 2A                  .090 (2.29) MIN PERFECT THD                  .258 (6.55) MAX</p>
	Size 100 Only Mil Spec Size H #4-40 UNC-2A	M83513/05-13	080-00-00-513	 <p>.200 (5.08) DIA MAX                  .062 (1.57) HEX                  .610 (15.49) MAX                  .140 (3.56) DIA                  #4-40 UNC 2A                  .110 (2.79) MIN PERFECT THD                  .292 (7.41) MAX</p>
 <b>Slot Head Jackscrew Extended</b>	Sizes 9 to 69 Contacts. Mil Spec Size A to G #2-56 UNC-2A	M83513/05-06	080-00-00-506	 <p>.156 (3.96) DIA MAX                  .610 (15.49) MAX                  .083 (2.11) DIA                  #2-56 UNC 2A                  .090 (2.29) MIN PERFECT THD                  .258 (6.55) MAX</p>
	Size 100 Only Mil Spec Size H #4-40 UNC-2A	M83513/05-16	080-00-00-516	 <p>.200 (5.08) DIA MAX                  .610 (15.49) MAX                  .140 (3.56) DIA                  #4-40 UNC 2A                  .110 (2.79) MIN PERFECT THD                  .292 (7.41) MAX</p>