


## Size #12 Pneumatic Contacts



Contact Type	For Use With	Tube I.D.	Part Number
Socket	D38999 Series II, Series 80	.094 (2.38)	<b>830-004</b>
Socket	D38999 Series I, III, IV	.094 (2.38)	<b>830-005</b>

830-005

830-004

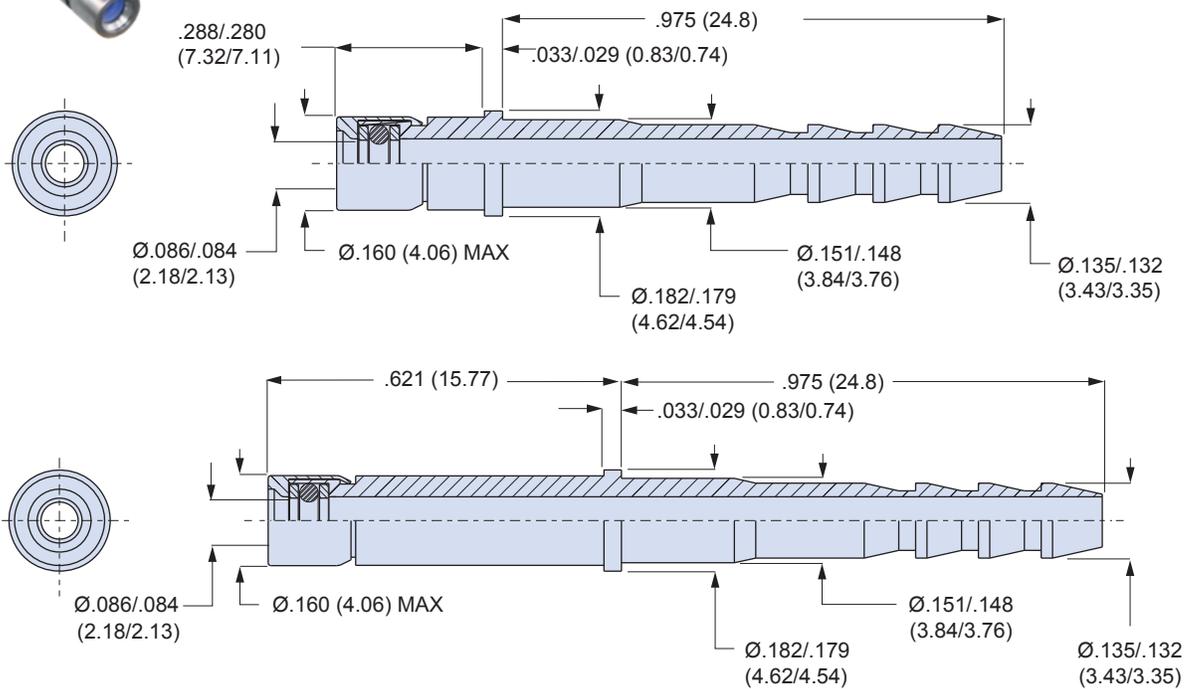

D

830-005

Stainless steel pneumatic contacts attach to 3/32 inch (2.38) diameter tubing. Socket contact has o-ring and PTFE backup washers. Contacts snap into size #12 connector cavities. These pneumatic contacts are rated for 100 PSI maximum air pressure. No installation tool is required. Remove contacts with plastic extraction tool 809-132.

### Material and Finish

Body and Cap: stainless steel, passivated  
 O-ring: fluorosilicone  
 Washers: PTFE

### Specifications

Contact may be used for air pressures up to 100±10% PSIG  
 Fits #12 socket contact cavities (see description for details)

### Notes

High pressure pneumatic contacts available. Consult factory for more information.  
 For Series 79, use 857-010 and 857-011.