

## SPECIAL PURPOSE Pin Contacts



857-217-22-30


**M39029/58-360 Type Size 22 Pin Contact with size 30 crimp barrel accommodation**

## SPECIAL PURPOSE



| HOW TO ORDER    |                             |     |     |
|-----------------|-----------------------------|-----|-----|
| Sample Part No. | 857-217                     | -22 | -30 |
| Product         | 857-217-22-30 = Pin Contact |     |     |
| Contact Size    | 22                          |     |     |
| Wire Size, AWG  | 30                          |     |     |

## 857-217-22-30 - DIMENSIONS

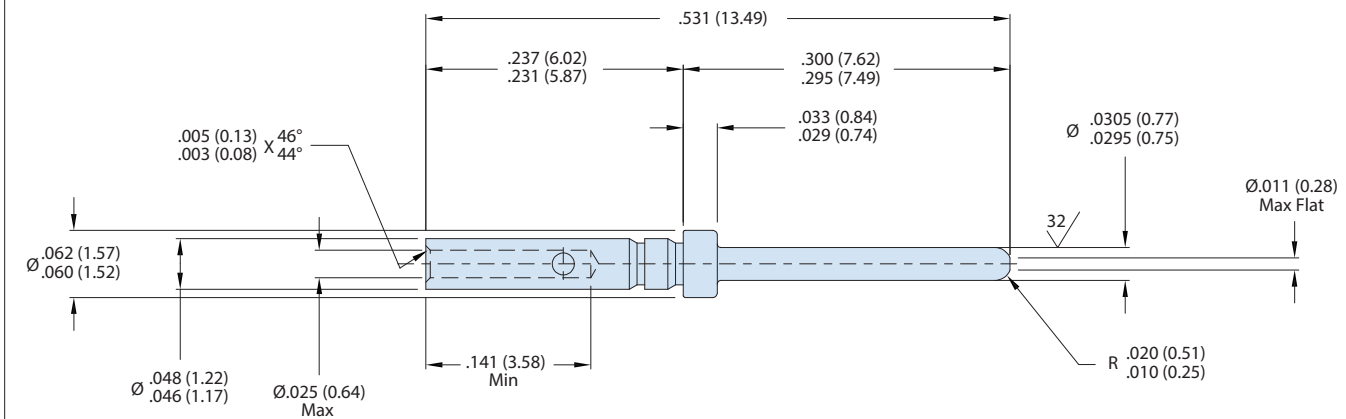

### TABLE I - CRIMP TOOL SELECTOR

|          |    |    |    |
|----------|----|----|----|
| Wire     | 26 | 28 | 30 |
| Selector | 5  | 4  | 3  |

## MATERIAL / FINISH

- Copper alloy / gold plated per ASTM B 488, Type II, Code C, .000050 min thick over nickel per SAE AMS-QQ-N-290, Class 2, .000030 to .000150 thick.

## NOTES

- Crimp tool data:
  - A) Crimp Frame - M22520/2-01 (Glenair p/n 809-015)
  - B) Positioner - M22520/2-09 (Glenair p/n 859-018)
  - C) Crimp tool selector: See Table I
  - D) Insertion/extraction tool - M81969/14-01 (Glenair p/n 859-020)
- Contact barrel accommodates 26 to 30 AWG