

CONNECTOR ACCESSORIES

Split-Back Backshells



440-236

Stainless Steel, Low-Profile 90° with Qwik-Ty



HOW TO ORDER										
Sample Part Number			440	H	E	236	Z1	15	D	S L
Product Series	440									
Connector Designator	A, F or H Table I									
Angular Function	E = 90° (Low Profile, Split)									
Basic Number	236									
Finish Symbol	Z1 = 300 SST, Passivate ZM = 300 SST, Electroless Nickel									
Shell Size	See Table I									
Drain Hole Option	Omit Letter "D" if Drain Holes Are Not Required									
Shield Termination Slot	Omit for None									
Qwik-Ty Option	Omit for None									

NOTES

- Assembly identified with manufacturer's name and p/n, space permitting.
- For effective grounding, connector with conductive finish should be used.
- Glenair 601-701 or 601-703 Micro-Max band supplied. Use with micro-max banding tool 601-129.
- Material/finish:
 - Adapter and cover - see How to Order Table
 - Coupling nut and anti-decoupling device - CRES/passivated

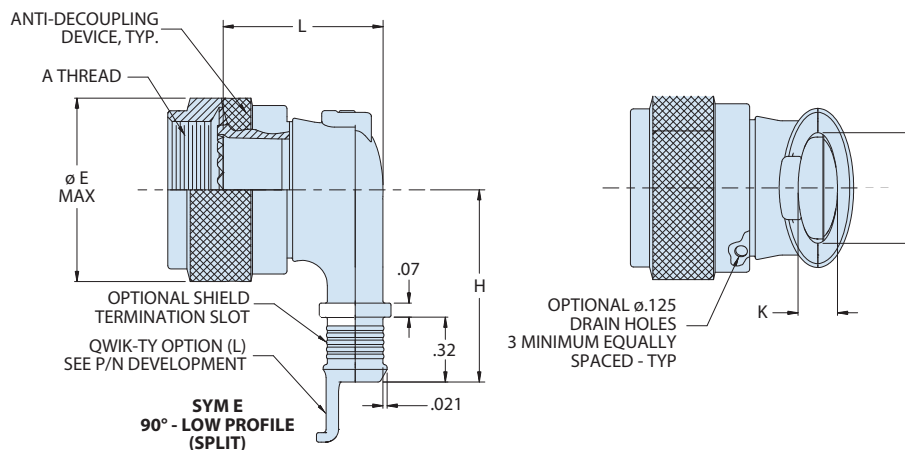


TABLE I						
Shell Size		H ±.03	J Dim	K Dim	L Max	Micro-Max P/N
A & F	H					
08	09	.828 (21.03)	.304 (7.72)	.160 (4.06)	.81 (20.57)	601-701
10	11	.888 (22.56)	.432 (10.97)	.174 (4.42)	.81 (20.57)	
12	13	.949 (24.10)	.546 (13.87)	.195 (4.95)	.82 (20.83)	
14	15	1.013 (25.73)	.670 (17.02)	.315 (8.00)	.88 (22.35)	
16	17	1.077 (27.36)	.796 (20.22)	.385 (9.78)	.93 (23.62)	
18	19	1.105 (28.07)	.902 (22.91)	.445 (11.30)	.99 (25.15)	601-703
20	21	1.169 (29.69)	1.027 (26.09)	.525 (13.34)	1.06 (26.92)	
22	23	1.236 (31.39)	1.152 (29.26)	.595 (15.11)	1.13 (28.70)	
24	25	1.294 (32.87)	1.448 (36.78)	.530 (13.46)	1.05 (26.67)	