



Qwik-Ty® Strain Reliefs

for MIL-DTL-26482 Series I Connectors

450D*001 Qwik-Ty Strain Relief




Lightweight, rugged, economical, fast-to-install. 450D*001 Qwik-Ty® strain relief fits Mil-DTL-26482 Series I connectors. Straight, 45° and 90° profiles. Straight profile is direct coupling, 45° and 90° are spin coupling. Secure with plastic strap or lacing tape (not included). Aluminum alloy.

Adapter Code D

This accessory fits MIL-DTL-26482 Series I connectors

PART NUMBER

	450DS001	C	10
Base P/N	450DS001 Straight 450DA001 90° 450DB001 45°		
Finish	C Black Anodize M Electroless Nickel NF Olive Drab Cadmium MT Nickel-PTFE ZR Black Zinc-Nickel TZ Tin-Zinc		
Shell Size	08 10 12 14 16 18 20 22 24		

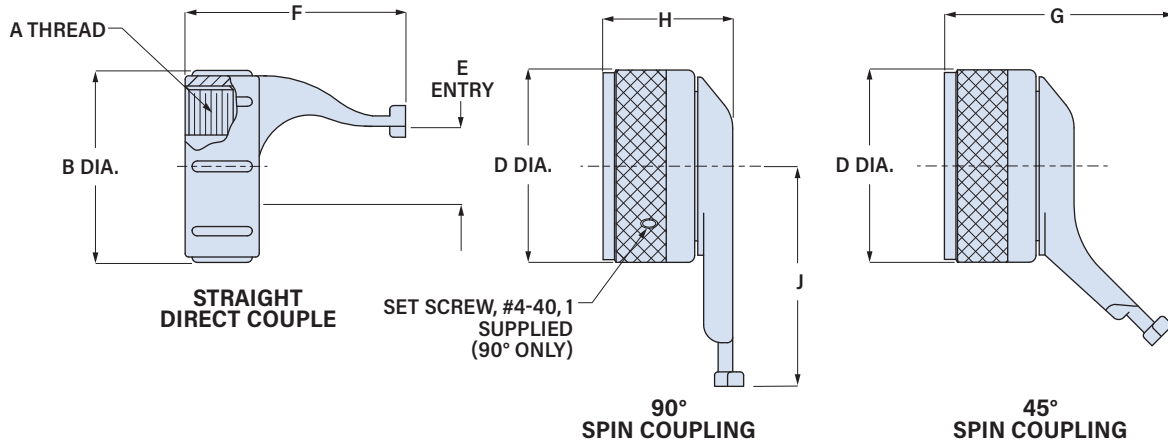

Shell Size	A Thread UNEF-2B	øB Max.		øD Max.		± .015 (0.4) E		F Max.		G Max.		H Max.		J Max.	
		In.	mm.	In.	mm.	In.	mm.	In.	mm.	In.	mm.	In.	mm.		
08	0.4375-28	.59	15.0	.77	19.6	.275	7.0	1.40	35.6	1.85	47.0	1.24	31.5	.88	22.4
10	0.5625-24	.72	18.3	.89	22.6	.402	10.2	1.40	35.6	1.85	47.0	1.24	31.5	.94	23.9
12	0.6875-24	.84	21.3	1.02	25.9	.516	13.1	1.40	35.6	1.85	47.0	1.24	31.5	1.00	25.4
14	0.8125-20	.97	24.6	1.15	29.2	.651	16.5	1.61	40.9	2.35	59.7	1.23	31.2	1.32	33.5
16	0.9375-20	1.09	27.7	1.26	32.0	.766	19.5	1.61	40.9	2.35	59.7	1.23	31.2	1.38	35.1
18	1.0625-18	1.22	31.0	1.40	35.6	.872	22.1	1.61	40.9	2.44	62.0	1.26	32.0	1.46	37.1
20	1.1875-18	1.34	34.0	1.53	38.9	.997	25.3	1.68	42.7	2.51	63.8	1.26	32.0	1.51	38.4
22	1.3125-18	1.47	37.3	1.60	40.6	1.125	28.6	1.68	42.7	2.51	63.8	1.26	32.0	1.56	39.6
24	1.4375-18	1.59	40.4	1.94	49.3	1.247	31.7	1.77	45.0	2.65	67.3	1.26	32.0	1.63	41.4