

Series 65 Dummy Receptacles

for MIL-DTL-28840 Connectors and Series 801 Mighty Mouse

650GS001, 657-072

650GS001 DUMMY RECEPTACLE FOR MIL-DTL-28840 AND MIL-PRF-28876 CONNECTORS



Use dummy storage receptacle to secure and protect unused plugs. 650GS001 receptacle accommodates MIL-DTL-28840 and MIL-PRF-28876 threaded plug connectors.

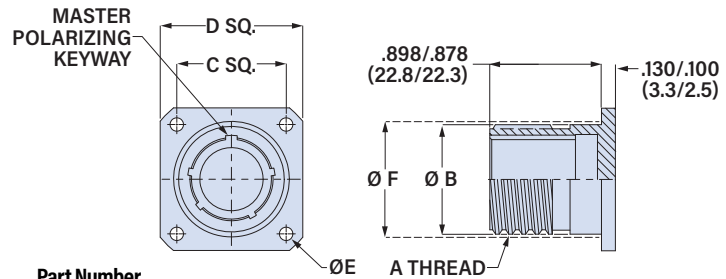


TABLE 1 FINISH CODES

| Aluminum | | Stainless Steel | |
|-----------|--------------------|-----------------|---------------|
| C | Black Anodize | Z1 | Passivate |
| M | Electroless Nickel | ZU | Black Cadmium |
| NF | Olive Drab Cadmium | | |
| MT | Nickel-PTFE | | |
| ZR | Black Zinc-Nickel | | |
| TZ | Tin-Zinc | | |

| Shell Size | Part Number * = Finish Code ♦ = Key Position 1-6 | A Thread. | øB Max. | | C Square | | D Max. | | øE | | F Ref. | |
|------------|--|------------------|---------|------|----------|------|--------|------|------|-----|--------|------|
| | | | In. | mm. | In. | mm. | In. | mm. | In. | mm. | In. | mm. |
| 11 (A) | 650GS001*11-♦ | .750-1P-2L-D.S. | .750 | 19.1 | .750 | 19.1 | 1.043 | 26.5 | .125 | 3.2 | .812 | 20.6 |
| 13 (B) | 650GS001*13-♦ | .875-1P-2L-D.S. | .875 | 22.2 | .843 | 21.4 | 1.158 | 29.4 | .125 | 3.2 | .937 | 23.8 |
| 15 (C) | 650GS001*15-♦ | 1.062-1P-2L-D.S. | 1.062 | 27.0 | .968 | 24.6 | 1.278 | 32.5 | .125 | 3.2 | 1.124 | 28.6 |
| 17 (D) | 650GS001*17-♦ | 1.125-1P-2L-D.S. | 1.125 | 28.6 | 1.015 | 25.8 | 1.403 | 35.6 | .125 | 3.2 | 1.187 | 30.2 |
| 19 (E) | 650GS001*19-♦ | 1.312-1P-2L-D.S. | 1.312 | 33.3 | 1.140 | 29.0 | 1.528 | 38.8 | .125 | 3.2 | 1.375 | 34.9 |
| 23 (F) | 650GS001*23-♦ | 1.500-1P-2L-D.S. | 1.500 | 38.1 | 1.281 | 32.5 | 1.738 | 44.1 | .125 | 3.2 | 1.562 | 40.0 |
| 25 (G) | 650GS001*25-♦ | 1.625-1P-2L-D.S. | 1.625 | 41.3 | 1.392 | 35.4 | 1.838 | 46.7 | .150 | 3.8 | 1.687 | 42.9 |
| 29 (H) | 650GS001*29-♦ | 1.812-1P-2L-D.S. | 1.812 | 46.0 | 1.568 | 39.8 | 2.158 | 54.8 | .150 | 3.8 | 1.874 | 47.6 |
| 33 (J) | 650GS001*33-♦ | 2.000-1P-2L-D.S. | 2.000 | 50.8 | 1.734 | 44.0 | 2.348 | 59.6 | .177 | 4.5 | 2.062 | 52.4 |

657-072 DUMMY RECEPTACLE FOR SERIES 801 CONNECTORS



Use dummy storage receptacle to secure and protect unused plugs. 657-072 receptacle accommodates Glenair Series 801 threaded plug connectors. Fluorosilicone gasket.

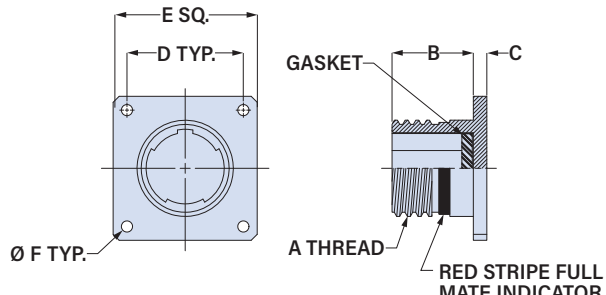


TABLE 1 FINISH CODES

| Aluminum | | Stainless Steel | |
|-----------|--------------------|-----------------|-----------|
| C | Black Anodize | Z1 | Passivate |
| M | Electroless Nickel | | |
| NF | Olive Drab Cadmium | | |
| MT | Nickel-PTFE | | |
| ZR | Black Zinc-Nickel | | |
| TZ | Tin-Zinc | | |

| Shell Size | Part Number * = Finish Code ♦ = Key Position 1-6 | A Thread. | B | | C | | D | | E | | ø F | |
|------------|--|---------------------|------|------|------|-----|-------|------|-------|------|------|-----|
| | | | In. | mm. | In. | mm. | In. | mm. | In. | mm. | In. | mm. |
| 5 | 657-072*5 | .3125-.05P-1L-DS-2A | .370 | 9.4 | .060 | 1.5 | .363 | 9.2 | .530 | 13.5 | .093 | 2.4 |
| 6 | 657-072*6 | .375-.05P-1L-DS-2A | .370 | 9.4 | .060 | 1.5 | .423 | 10.7 | .590 | 15.0 | .093 | 2.4 |
| 7 | 657-072*7 | .4375-.05P-1L-DS-2A | .370 | 9.4 | .060 | 1.5 | .483 | 12.3 | .650 | 16.5 | .093 | 2.4 |
| 8 | 657-072*8 | .5000-.05P-1L-DS-2A | .370 | 9.4 | .060 | 1.5 | .545 | 13.8 | .712 | 18.1 | .093 | 2.4 |
| 9 | 657-072*9 | .5625-.05P-1L-DS-2A | .370 | 9.4 | .060 | 1.5 | .607 | 15.4 | .850 | 21.6 | .128 | 3.3 |
| 10 | 657-072*10 | .6250-.05P-1L-DS-2A | .370 | 9.4 | .060 | 1.5 | .670 | 17.0 | .890 | 22.6 | .128 | 3.3 |
| 11 | 657-072*11 | .6875-1P-1L-DS-2A | .370 | 9.4 | .060 | 1.5 | .715 | 18.2 | .935 | 23.7 | .128 | 3.3 |
| 13 | 657-072*13 | .8125-1P-2L-DS-2A | .480 | 12.2 | .090 | 2.3 | .812 | 20.6 | 1.030 | 26.2 | .128 | 3.3 |
| 16 | 657-072*16 | 1.000-1P-2L-DS-2A | .480 | 12.2 | .090 | 2.3 | .981 | 24.9 | 1.219 | 31.0 | .128 | 3.3 |
| 17 | 657-072*17 | 1.0625-1P-2L-DS-2A | .480 | 12.2 | .090 | 2.3 | 1.060 | 26.9 | 1.280 | 32.5 | .128 | 3.3 |
| 19 | 657-072*19 | 1.1875-1P-2L-DS-2A | .480 | 12.2 | .090 | 2.3 | 1.191 | 30.3 | 1.432 | 36.4 | .128 | 3.3 |
| 21 | 657-072*21 | 1.3125-1P-2L-DS-2A | .480 | 12.2 | .090 | 2.3 | 1.322 | 33.6 | 1.565 | 39.8 | .128 | 3.3 |