

SERIES 79 MICRO-CRIMP RECTANGULAR CONNECTORS


Backshells and Accessories



799-119

Jackpost, Female, Rear Panel Mount

- ◆ Fits Series 790 PCB connectors
- ◆ Slot drive

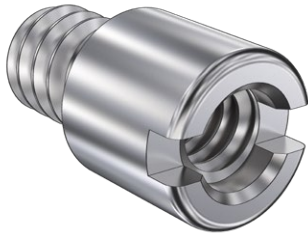


799-119



This jackpost fits Series 790 PCB connectors:
790-041, 790-042, 790-043, 790-044

Rear panel mount jackpost installs into Series 790 PCB connectors. Supplied as kit consisting of two jackposts. For panel thickness 0 (no panel), .032 (0.8), .05 (1.3) and .062 (1.6). Panel thickness greater than .062 requires counterboring. Passivated 300 series stainless steel.

⚠ Install jackpost with threadlocking compound.

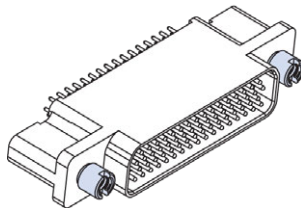


REAR PANEL MOUNT FEMALE JACKPOST KIT										
Kit contains (2) posts										
X Thread Size	Shell Size	Panel Thickness in mm	Part Number	A ± .003 (0.08) in mm		ø B in mm		ø C in mm		Y Thread Size
2-56	A-G, J, K	No Panel	799-119-A	N/A	N/A	N/A	N/A	.156	3.96	4-40
		.032 0.8	799-119-A1	.029	.74	.125	3.18	.156	3.96	
		.050 1.3	799-119-A2	.047	1.19	.125	3.18	.156	3.96	
		.062 1.6	799-119-A3	.060	1.52	.125	3.18	.156	3.96	
4-40	H, L	No Panel	799-119-B	N/A	N/A	N/A	N/A	.225	5.72	6-32
		.032 0.8	799-119-B1	.029	.74	.160	4.06	.225	5.72	
		.050 1.3	799-119-B2	.047	1.19	.160	4.06	.225	5.72	
		.062 1.6	799-119-B3	.060	1.52	.160	4.06	.225	5.72	
6-32	M	No Panel	799-119-C	N/A	N/A	N/A	N/A	.250	6.35	8-32
		.032 0.8	799-119-C1	.029	.74	.186	4.72	.250	6.35	
		.050 1.3	799-119-C2	.047	1.19	.186	4.72	.250	6.35	
		.062 1.6	799-119-C3	.060	1.52	.186	4.72	.250	6.35	

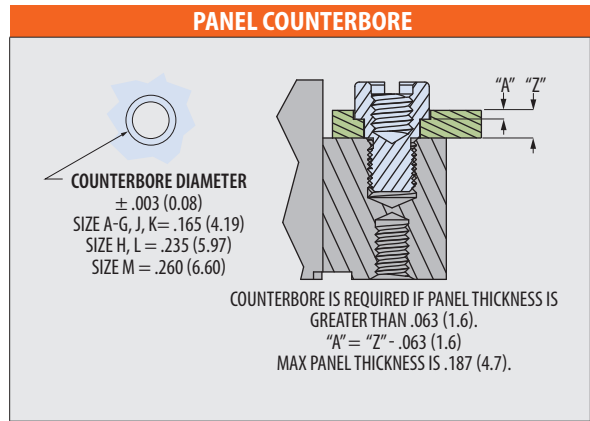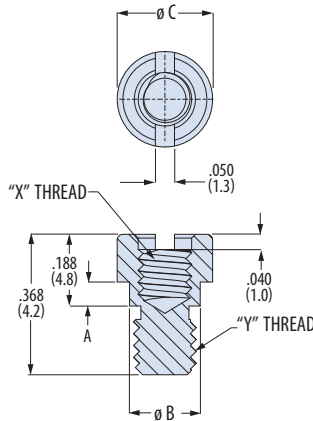


SERIES 790 PANEL CUTOUT FOR JACKPOST 799-119

Shell Size	A ± .002 (0.05)		B ± .002 (0.05)		C	
	in	mm	in	mm	in	mm
A	.406	10.31	.306	7.77	.565	14.35
B	.556	14.12	.306	7.77	.715	18.16
C	.706	17.93	.306	7.77	.865	21.97
D	.806	20.47	.306	7.77	.965	24.51
E	.956	24.28	.306	7.77	1.115	28.32
F	1.106	28.09	.306	7.77	1.265	32.13
G	1.084	27.53	.399	10.13	1.215	30.86
H	1.455	36.96	.419	10.64	1.800	45.72
J	1.461	37.11	.306	7.77	1.615	41.02
K	1.864	47.35	.306	7.77	2.015	51.18
L	1.691	42.95	.419	10.64	2.036	51.71
M	1.755	44.58	.479	12.17	2.200	55.88

PANEL CUTOUT FOR SERIES 790 SHELL SIZES A-G, J, K

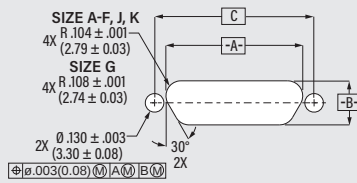

PANEL CUTOUT FOR SERIES 790 SHELL SIZES H AND L

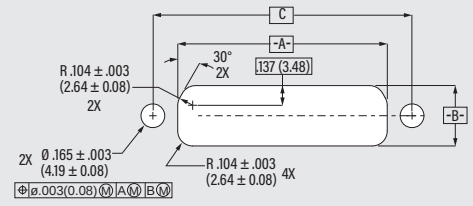

PANEL CUTOUT FOR SERIES 790 SHELL SIZE M

