

SERIES 79 MICRO-CRIMP RECTANGULAR CONNECTORS

Backshells and Accessories





799-164

Piggyback EMI Banding Backshell, Series 792

- ◆ for Series 792 connectors
- ◆ Internal grommet fits high speed data cables



799-164 INTERNAL VIEW

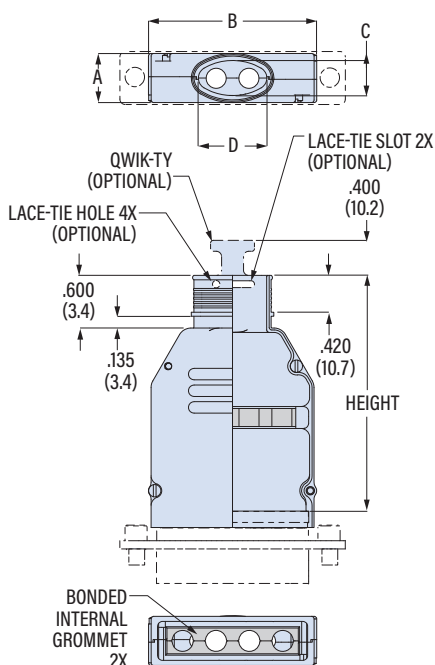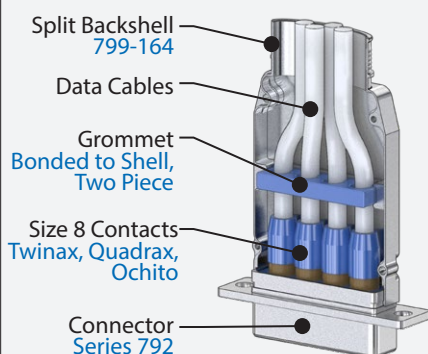

EMI, piggyback, split. 799-164 piggyback backshell fits Series 792 connectors with rear groove on shell. Internal fluorosilicone wire strain relief grommet accommodates high speed cables. Available with Qwik-Ty strain relief arm or slots/holes for lacing tape. Terminate cable shield to backshell with BandMaster ATS band strap. Aluminum with stainless steel screws.

799-164

This accessory fits Series 792 cable connectors with #8 insert arrangements.

792-001, 792-002

Not for use with insert arrangements with #23 contacts.

HOW TO ORDER

Sample Part Number	799-164	M	D	B	T	N	2
Basic Part Number	799-164						
Finish	M Electroless Nickel MT Nickel / PTFE NF Olive Drab Cadmium TZ Tin-Zinc ZR Black Zinc-Nickel						
Shell Size	A B C D E F						
Band	B Standard Band Included S Slim Standard Band Included M Micro Band Included J Micro Slim Band Included L Micro-Max Band Included						
Qwik-Ty	T Qwik-Ty Strain Relief Arm N No Qwik-Ty						
Lace-Tie Option	H Holes for Lace-Tie S Slots for Lace-Tie N No Lace-Tie Provision						
Cable Size	1 .188 (4.8) Max Individual Cable Diameter 2 .250 (6.4) Max Individual Cable Diameter 3 .313 (8.0) Max Individual Cable Diameter						

Shell Size	Cable Size 1		Cable Size 2		Cable Size 3	
	A Max	B Max	C	D	C	D
A	.575	.810	.200	.300	.260	.320
B	.575	1.185	.250	.390	.340	.380
C	.575	1.560	.400	.440	.400	.400
D	.575	1.935	.400	.520	.400	.400
E	.575	2.310	.400	.690	.400	.400
F	.950	2.310	.700	.700	.775	.775

BAND OPTIONS

Stainless steel band strap provides fast, cost-effective and highly reliable termination of braided metallic shielding. *Slim Standard* and *Micro Slim* bands have reduced thickness for weight reduction. High tension *Micro-Max* bands reduce braid-to-shell electrical resistance.



Band Type	Band Width	Band P/N 14" Length Pre-Coiled	Hand Tool	Pneumatic Tool
Standard	.24 (6.1)	601-041	601-100	601-106
Slim Standard	.24 (6.1)	601-573	601-109	601-110
Micro	.12 (3.0)	601-065	601-101	601-107
Micro Slim	.12 (3.0)	601-603	601-122	601-123
Micro-Max	.12 (3.0)	601-703	601-129	601-130