

SERIES 79 MICRO-CRIMP RECTANGULAR CONNECTORS

Backshells and Accessories

SERIES
79

799-257

Piggyback EMI Banding Backshell, Series 792


- ◆ Fits Series 792 connectors
- ◆ Band-Master® shield termination
- ◆ Variable entry size



799-257

This accessory fits Series 792 connectors
792-001, 792-002

799-257 piggyback backshell fits Series 792 connectors with rear groove on shell. Terminate cable shield to backshell with BandMaster ATS band strap. Aluminum with stainless steel screws.

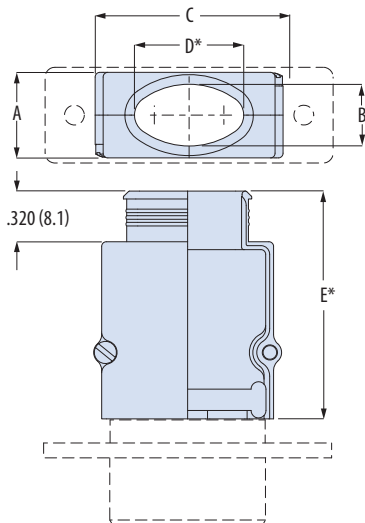


*SEE HOW TO ORDER TABLES FOR D AND E DIMS

Shell Size	A Max in mm	B Max in mm	C Max in mm	Available Entries
A	.555 14.1	.390 9.9	.825 21.0	03
B	.555 14.1	.390 9.9	1.200 30.5	03 thru 06
C	.555 14.1	.390 9.9	1.575 40.0	03 thru 08
D	.555 14.1	.390 9.9	1.950 49.5	03 thru 12
E	.555 14.1	.390 9.9	2.325 59.1	03 thru 15
F	.930 23.6	.765 19.4	2.325 59.1	06 thru 15


HOW TO ORDER

Sample Part Number		799-257	M	D	09	N	06
Basic Part Number		799-257					
Finish	M	Electroless Nickel					
	MT	Nickel / PTFE					
	NF	Olive Drab Cadmium					
	TZ	Tin-Zinc					
	ZR	Black Zinc-Nickel					
Shell Size		A B C D E F					
Entry Size	Entry Size	D	Shell Size				
	03	.440 (11.2)	A thru E				
	04	.540 (13.7)	B thru E				
	05	.690 (17.5)	B thru E				
	06	.810 (20.6)	B thru F				
	07	1.000 (25.4)	C thru F				
	08	1.190 (30.2)	C thru F				
	09	1.305 (33.1)	D thru F				
	10	1.420 (36.1)	D thru F				
	11	1.500 (38.1)	D thru F				
	12	1.600 (40.6)	D thru F				
	13	1.750 (44.5)	E thru F				
	14	1.875 (47.6)	E thru F				
	15	2.000 (50.8)	E thru F				
	Band	M	Micro Band Included				
J		Micro Slim Band Included					
L		Micro-Max Band Included					
Height Code	Height Code	E					
	05	1.310 (33.3)					
	06	1.440 (36.6)					
	07	1.560 (39.6)					
	08	1.690 (42.9)					
	09	1.810 (46.0)					
	10	1.940 (49.3)					
	11	2.060 (52.3)					
	12	2.190 (55.6)					
	13	2.310 (58.7)					
	14	2.440 (62.0)					
	15	2.560 (65.0)					

 


ENTRY




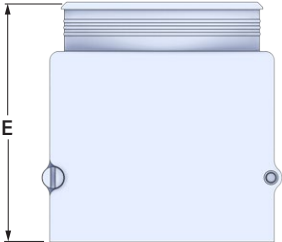

HEIGHT

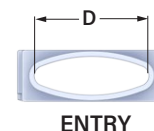

ENTRY

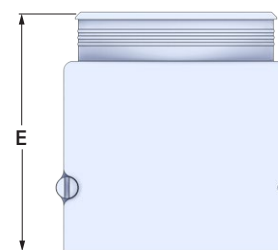

HEIGHT

BAND OPTIONS

Stainless steel band strap provides fast, cost-effective and highly reliable termination of braided metallic shielding. *Micro Slim* bands have reduced thickness for weight reduction. High tension *Micro-Max* bands reduce braid-to-shell electrical resistance.



Band Type	Band Width	Band P/N 14" Length Pre-Coiled	Hand Tool	Pneumatic Tool
Micro	.12 (3.0)	601-065	601-101	601-107
Micro Slim	.12 (3.0)	601-603	601-122	601-123
Micro-Max	.12 (3.0)	601-703	601-129	601-130