


SERIES 79 MICRO-CRIMP RECTANGULAR CONNECTORS

Contacts and Tools




Dummy Contact Sealing Plugs

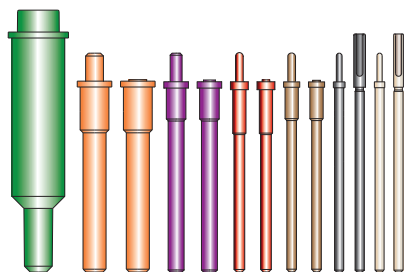

Weight-saving, high temperature. Glenair Super DCSP Dummy Contact Sealing Plugs maintain environmental sealing in unused connector cavities. Compatible with MIL-DTL-38999 connectors along with Glenair Series 80 Mighty Mouse, Series 806, and Series 79 connectors. Made of chemical-resistant thermoplastic, these dummy contacts are available in sizes 8, 12, 16, 20, 20HD, 22, 22HD, and 23. Sealing plug tail protrudes from grommet to facilitate removal with standard extraction tools. Rated for +200 °C continuous operating temperature, these sealing plugs save weight compared to installing an unused electrical contact plus a grommet sealing plug.


Size 8 dummy contacts require 680-180-02 sealing boot for environmental sealing.

Material: +200 °C thermoplastic

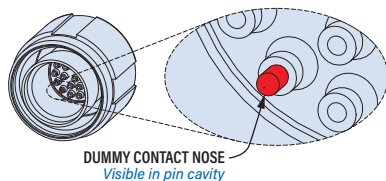

INSTALLATION TIPS

Insert dummy contact into unused contact cavity. Lubricate front nose of dummy contact with isopropyl alcohol. Install by hand. Use needle-nose pliers or contact insertion tool if space is limited. Push dummy contact into cavity until flange locks into contact retention clip. Pull on the tail to verify dummy contact is locked in place. Dummy contact is removable with standard contact removal tool.

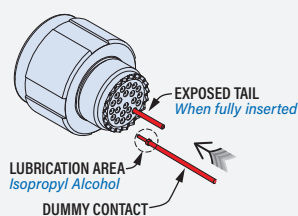

DUMMY CONTACT SEALING PLUGS

Contact Size	Pin Part Number	Socket Part Number	Series
#12	 680-116-12	 680-116-12S	D38999 Mighty Mouse Series 806 Series 79
#16	 680-116-16	 680-116-16S	D38999 Mighty Mouse Series 806 Series 79
#20	 680-116-20	 680-116-20S	D38999 Mighty Mouse
#20HD	 680-116-20HD	 680-116-20HDS	Mighty Mouse Series 806
#22	 680-116-22	 680-116-22S	D38999 Mighty Mouse
#22HD	 680-116-22HD	 680-116-22HDS	Series 806
#23	 680-116-23	 680-116-23S	D38999 Mighty Mouse Series 79

SIZE 8 DUMMY CONTACT SEALING PLUGS

Contact Size	Part Number for D38999, Mighty Mouse, Series 790/ 791/ 793/ 795	Part Number for Series 806, Series 792
#8 Sealing Boot Not Included	 680-116-8	 680-116-80
#8 Sealing Boot Included		
	680-116-8B	680-116-80B