


Pneumatic Contacts

CONTACTS AND TOOLS

SIZE 12 PNEUMATIC CONTACTS

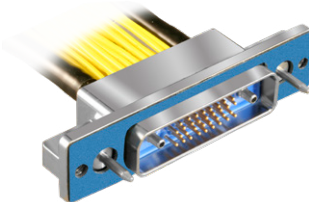

PART NUMBER		
Contact Type	Tube I.D.	Part Number
Pin	.094 (2.38)	857-011
Socket	.094 (2.38)	857-010

Ideal for pitot tube connections, these pneumatic contacts are rated for 100 PSI maximum air pressure. Stainless steel contacts attach to $\frac{3}{32}$ inch (2.38) diameter tubing. Contacts snap into size #12 connector cavities. No installation tool is required. Remove contacts with plastic extraction tool 809-132. Socket contact has O-ring and PTFE backup washers.

! Install tubing onto contact before installing contact into connector


COMPATIBILITY

- Series 790, 791 and 793 connectors with size #12 contact cavities

CONSTRUCTION

- Pin contact: Stainless steel, passivated
- Socket contact: Passivated stainless steel body and cap, fluorosilicone O-ring, PTFE washers

857-010 PNEUMATIC SOCKET CONTACT SIZE #12

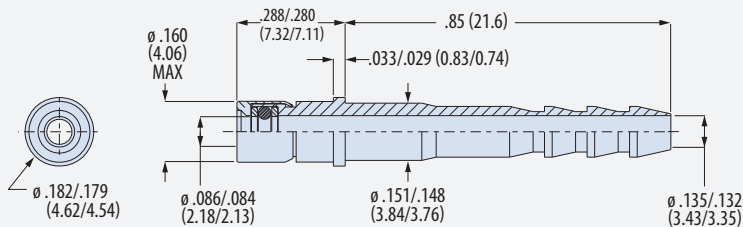

857-011 PNEUMATIC PIN CONTACT SIZE #12

