

## Pneumatic Contacts

### CONTACTS AND TOOLS



#### SIZE 12 PNEUMATIC CONTACTS



PART NUMBER		
Contact Type	Tube I.D.	Part Number
Pin	.094 (2.38)	<b>857-011</b>
Socket	.094 (2.38)	<b>857-010</b>

Ideal for pitot tube connections, these pneumatic contacts are rated for 100 PSI maximum air pressure. Stainless steel contacts attach to  $\frac{3}{32}$  inch (2.38) diameter tubing. Contacts snap into size #12 connector cavities. No installation tool is required. Remove contacts with plastic extraction tool 809-132. Socket contact has O-ring and PTFE backup washers.

**⚠** Install tubing onto contact before installing contact into connector


#### COMPATIBILITY

- Series 790, 791 and 793 connectors with size #12 contact cavities

#### CONSTRUCTION

- Pin contact: Stainless steel, passivated
- Socket contact: Passivated stainless steel body and cap, fluorosilicone O-ring, PTFE washers

#### 857-010 PNEUMATIC SOCKET CONTACT SIZE #12

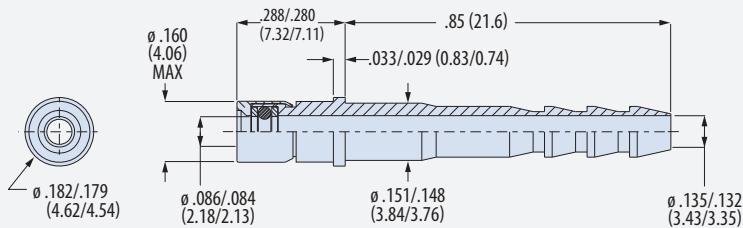

#### 857-011 PNEUMATIC PIN CONTACT SIZE #12

