

MICRO-CRIMP RECTANGULAR CONNECTORS

Series 792 High-Speed



Series 792 Insert Arrangements

 
SERIES 792 INSERT ARRANGEMENTS

Thermoplastic Insert	Grounded All-Aluminum	No. of Contacts	
		#8	#23
A-1W1	A-1G1	1	—
A-3W1		1	2
B-23W1		1	22
B-2W2	B-2G2	2	—
B-6W2		2	4
C-24W2		2	22
C-3W3	3G3	3	—
C-9W3		3	6
D-27W3		3	24
D-4W4	D-4G4	4	—
D-12W4		4	8
E-5W5	E-5G5	5	—
E-15W5		5	10
E-45W3		3	42
F-9W9	F-9G9	9	—
F-31W9		9	22

Grounded Insert Arrangements

Series 792 connectors are available with thermoplastic inserts ("A-1W1" for example), or with all-aluminum construction for grounding datalink contacts together with the connector shell ("A-1G1").


⚠ Cavity Numbers
Cavity numbers shown are for mating face of plug (socket) connector. Receptacle (pin) numbers are reversed.



1 #8


A-1W1

 A-1G1 Grounded



1 #8, 2 #23

 
A-3W1



2 #8


B-2W2

 B-2G2 Grounded




2 #8, 4 #23

 B-6W2



1 #8, 22 #23

 
B-23W1



3 #8


C-3W3

 C-3G3 Grounded




3 #8, 6 #23

 C-9W3



2 #8, 22 #23

 
C-24W2



4 #8


D-4W4

 D-4G4 Grounded




4 #8, 8 #23

 D-12W4



3 #8, 24 #23

 
D-27W3



5 #8


E-5W5

 E-5G5 Grounded




5 #8, 10 #23

 E-15W5



3 #8, 42 #23


E-45W3

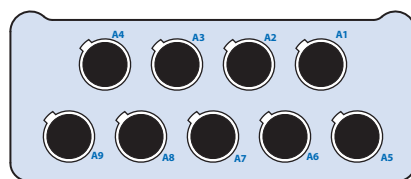

9 #8

F-9W9

F-9G9 Grounded

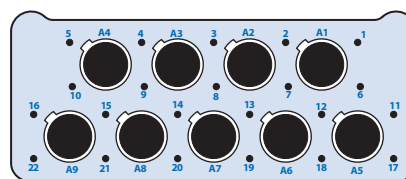

9 #8, 22 #23

F-31W9