

Series 792 Polarization Keying Option

OPTIONAL POLARIZATION KEYS



To prevent mis-mating of identical shell size and insert arrangement connectors


Series 792 connectors are available with an integral polarizing key. Keyed plug connectors have a raised boss on the shell. Receptacles have corresponding keyway. Ordering is simple—just add the keying position letter designator to the end of the part number.

Note: keyed receptacles will mate with unkeyed plugs.


HOW TO ORDER

Step 1	Create a Series 792 connector part number:	792-001SD-4G4MS
Step 2	Add the keying position letter designator A, B, C, D, E, F, G, H, J, or K to the part number.	792-001SD-4G4MS B

MOD-1104 POLARIZING KEY LOCATIONS
PLUG CONNECTOR MATING FACE

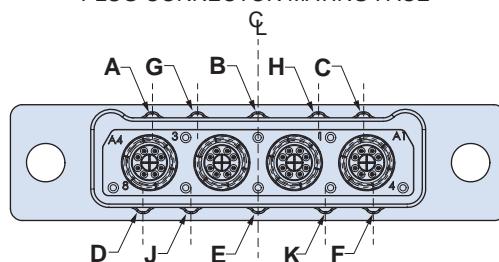

MOD-1104 POLARIZING KEY LOCATIONS
RECEPTACLE CONNECTOR MATING FACE

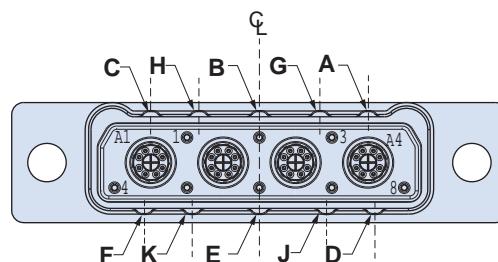

KEY LOCATIONS

Key Position Offset From Vertical Centerline

Shell Size	Position A		Position B		Position C		Position D		Position E		Position F		Position G		Position H		Position J		Position K	
	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm
A	.025	0.64	.000	.00	.025	0.64	.100	2.54	.000	.00	.100	2.54	POSITIONS G, H, J AND K ARE NOT AVAILABLE FOR SHELL SIZES A, B AND C							
B	.200	2.29	.000	.00	.200	2.29	.325	8.26	.000	.00	.325	8.26								
C	.375	9.53	.000	.00	.375	9.53	.500	12.70	.000	.00	.500	12.70	.315	8.00	.315	8.00	.350	8.89	.350	8.89
D	.550	13.97	.000	.00	.550	13.97	.600	15.24	.000	.00	.600	15.24	.315	8.00	.315	8.00	.350	8.89	.350	8.89
E	.700	17.78	.000	.00	.700	17.78	.750	19.05	.000	.00	.750	19.05	.315	8.00	.315	8.00	.350	8.89	.350	8.89
F	.700	17.78	.000	.00	.700	17.78	.750	19.05	.000	.00	.750	19.05	.315	8.00	.315	8.00	.350	8.89	.350	8.89