

OPTIMIZED  
FOR USE WITH  
**MILSTAR**<sup>TM</sup>  
HIGH-PERFORMANCE HOOKUP WIRE AND CABLE




**MIL-DTL-28840 qualified  
connectors and accessories:  
every slash sheet, no gaps**



- All sizes and platings in-stock and ready for immediate shipment
- High density, scoop proof contact arrangements
- Flange mount, box mount, jam-nut and in-line receptacles
- Straight, 45°, and 90° strain reliefs and backshell assemblies
- Sav-Con® connector savers and bulkhead feedthrus
- Contact and connector assembly tools

MIL-DTL-28840 qualified connectors and accessories. Splined connector-to-backshell interface is ideally suited for heavy backshells and cables.

**QUALIFIED CADMIUM-FREE AND COMPATIBLE TIN-ZINC (TZ) PLATING FOR CLASS CODE L AND M (CLASS T AND TJ) NAVY LAND AND MARITIME APPLICATIONS.**

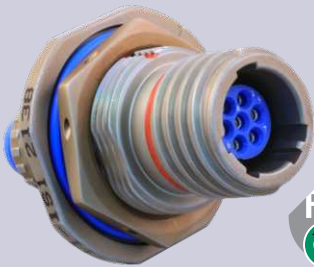

L - Class T: Aluminum, Tin-Zinc Plate over Electroless Nickel, Non-Reflective

- New DLA-qualified replacement for cadmium
- High conductivity and shielding performance in harsh maritime conditions
- High corrosion resistance
- Compatibility with legacy cadmium-plated connectors and environmental shrink boots
- RoHS-compliant material
- Test reports available upon request

# SHIPBOARD MIL-DTL-28840 Connectors and Accessories



With in-stock same-day availability

**MIL-DTL-28840 • FULLY-QUALIFIED • EVERY SLASH SHEET • NO GAPS • IN-STOCK AVAILABILITY**

 <p><b>Contacts</b> M39029/83 pin and /84 socket</p>	 <p><b>Clamps</b> M28840/1 straight M28840/2 90° M28840/3 45°</p>	 <p><b>Conduit</b> M28840/4 Metal-Core</p>
 <p><b>Conduit Fittings</b> M28840/5 Backshell for Metal Core Conduit M28840/6 EMI/RFI Environmental Backshell M28840/25 90° EMI Conduit Adapter M28840/27 45° EMI Conduit Adapter M28840/30 Metal Conduit Coupler, Styles A and B M28840/22 Metal Conduit Bushing M28840/23 "E Nut"</p>	 <p><b>Backshells</b> M28840/8 90° EMI/RFI Environmental M28840/4 45° EMI/RFI Environmental Backshell</p>	 <p><b>Connectors</b> M28840/10 Wall Mount Receptacle Connector M28840/11 In-Line Receptacle Connector M28840/12 Box Mount Receptacle Connector M28840/14 Jam Nut Mount Receptacle Connector M28840/16 Plug Connector</p>
 <p><b>Connector / Backshell Assemblies</b> M28840/17 Plug Connector / Straight Strain Relief M28840/18 Plug Connector with 90° Strain Relief M28840/19 Plug Connector with 45° Strain Relief M28840/20 Recept., Straight EMI/RFI Backshell M28840/21 In-Line Recept., St. EMI/RFI Backshell M28840/26 Plug, with Straight EMI/RFI Backshell M28840/28 90° Adapter Assembly Plug M28840/29 Plug with 45° EMI/RFI Backshell</p>	 <p><b>Protective Covers</b> M28840/13 Protective Receptacle Cover M28840/15 Protective Plug Cover</p>	 <p><b>Tools and Accessories</b> M28840/7 Dummy Stowage Receptacle M28840/24 Mounting Gasket</p>

M  
N  
O  
P  
Q  
R  
S  
T  
U  
V  
W  
X  
Y  
Z