

OPTIMIZED
FOR USE WITH




SeaKing
PRESSURE-RATED CABLES




**SeaKing™ PBOF 10K psi
Pressure-Balanced
Oil-Filled connectorized
assemblies**


**10K psi open-face
SeaKing PBOF wired
and connectorized
assemblies, fittings, and
accessories with Glenair
signature swivel hose
attachment accessories**

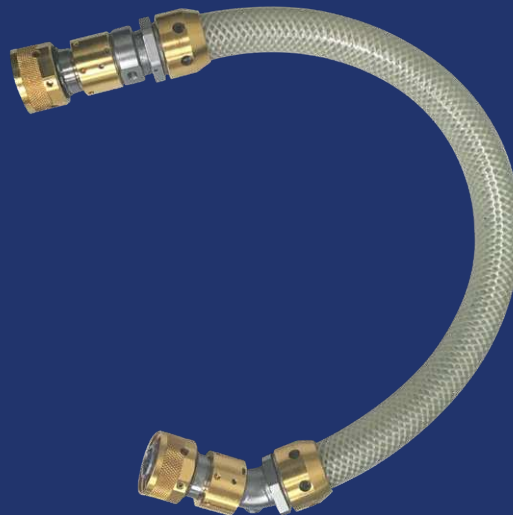


WIRED / CONNECTORIZED PBOF CONDUIT ASSEMBLIES

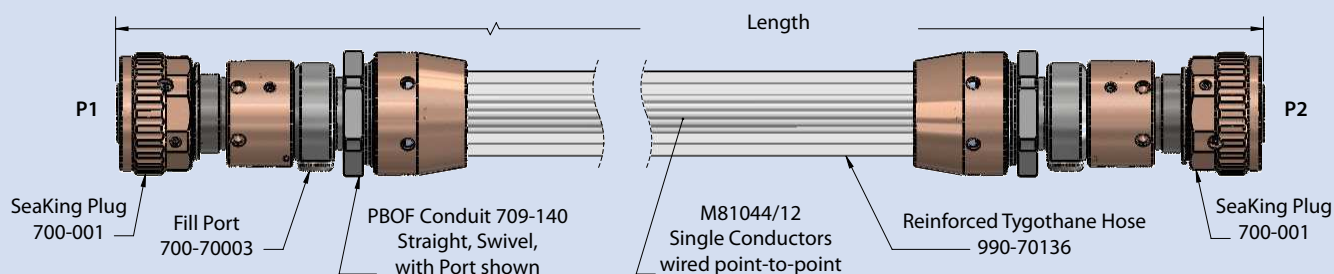

CONNECTOR / BACKSHELL / BOOT SEAL ASSEMBLY

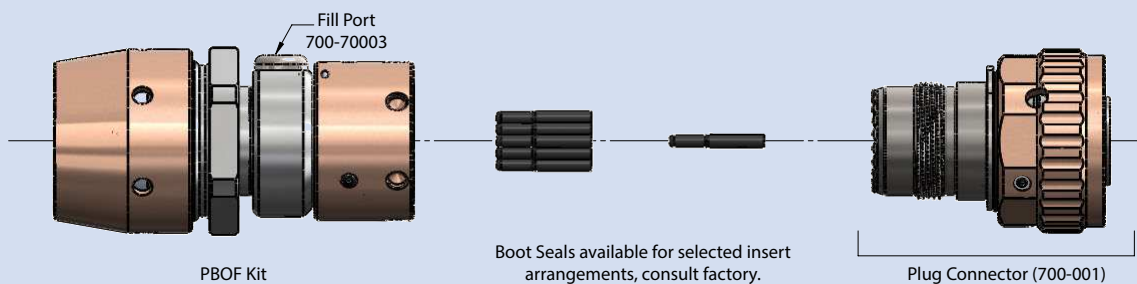

UNWIRED PBOF CONDUIT ASSEMBLIES

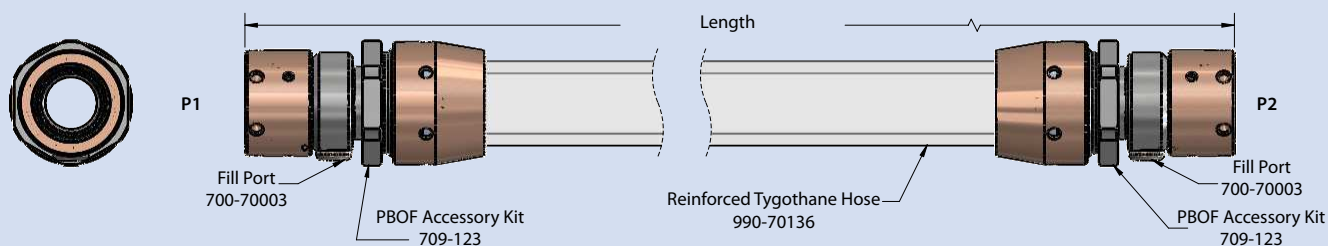

10K PSI / 700 BAR SeaKing™ PBOF Assemblies




Wired and connectorized turnkey assemblies

REVOLUTIONARY PBOF SWIVEL HOSE ATTACHMENT ACCESSORIES



Hose barb fittings for PBOF assemblies are the perennial weak link in subsea oil & gas applications. Kinked and twisted hoses, leaky fittings, corroded hose clamps, and other performance problems characterize most existing solutions. The Glenair PBOF swivel hose attachment for SeaKing™ 700 series connectors solves these problems and more. Designed from the sea floor up to perform flawlessly and reliably, this revolutionary attachment puts an end to the long list of field maintenance problems associated with oil-filled cable applications.

- Straight, 45°, and 90° “full radius” profile hose routing
- Hose angle adjustment feature reduces risk of oil leakage
- Corrosion-resistant materials used throughout
- Threaded couplers with safety set-screws for fail-safe leak and decoupling protection—no special tools required for assembly
- Compact PBOF compression fitting with optional 340° swivel-action hose for an extra degree freedom of routing in compact situations
- Support for the broad range of hose diameters and wall thicknesses
- Collet-type hose-clamp securely and uniformly grips the hose with 360° of uniform pressure

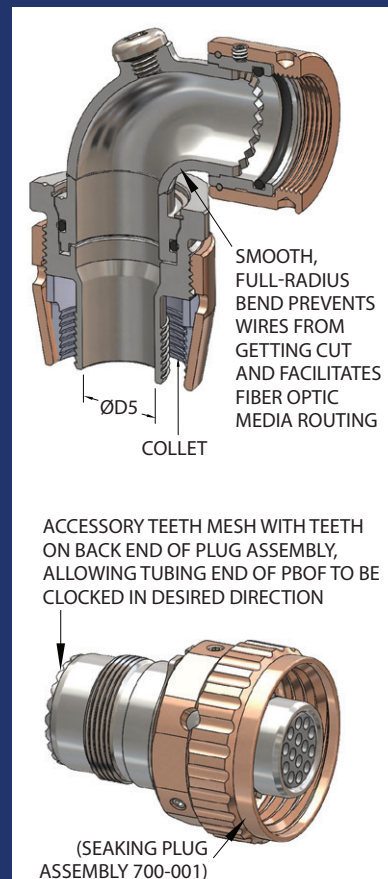

The complete range of SeaKing PBOF hose compression fittings includes straight, 45°, and 90° full radius profile versions; with and without integrated oil fill ports

