

## 660-072 and 660-073 • M28876/10 and M28876/15 Protective Covers for MIL-PRF-28876 connectors



LANYARD/ATTACHMENT (MIL-SPEC)	
Symbol	Description
A	Chain with Fastener (Eyelet) Attachment
B	Chain with Ring Attachment
C	Wire Rope with Fastener (Eyelet) Attachment
D	Wire Rope with Ring Attachment
E	Without Chain or Wire Rope


LANYARD/ATTACHMENT (COMMERCIAL)	
Symbol	Description
H	Wire Rope, Coated
S	Sash Chain, Passivated
N	No Lanyard

SHELL SIZE		
Shell Size (Mil-Spec)	Shell Size (Ref)	A Thread
A	11	.750-0.1P-0.2L-D.S.
B	13	.875-0.1P-0.2L-D.S.
C	15	1.062-0.1P-0.2L-D.S.
F	23	1.500-0.1P-0.2L-D.S.

MATERIAL AND FINISHES (COMMERCIAL 660 SERIES)		
Code	Material	Finish Description
GB4	Aluminum Alloy	Hard Anodize, Black with PTFE
ME		Electroless Nickel
MT		Nickel-PTFE, Grey
NF		Cadmium, Olive Drab
TZ		Tin-Zinc, Bronze-Gold
ZR		Zinc-Nickel, Black

HOW TO ORDER GLENAIR COMMERCIAL PROTECTIVE COVERS						
Sample Part Number	660-072	M	C	R	9	-01
Basic Number	660-072 Plug Cover 660-073 Receptacle cover					
Material/ Finish Code	See Material and Finish table					
Shell Size	A, B, C, F; See Shell Size table					
Attachment Type	See Lanyard/Attachment (Commercial) table					
Attachment Length	In inches 9" standard					
Ring Style Option	See Attachment Type (Commercial) table					

HOW TO ORDER				
Sample Part Number	M28876/10	C	C	T
Basic Number	M28876/10 Plug Cover M28876/15 Receptacle cover			
Shell Size	A, B, C, F; See Shell Size table			
Lanyard/Attachment Type	See Lanyard/Attachment (MIL-Spec) table			
Materials and Finishes	T = Tin-Zinc, Bronze-Gold over Aluminum Alloy Omit = Hard Anodize, Black with PTFE over Aluminum Alloy.			

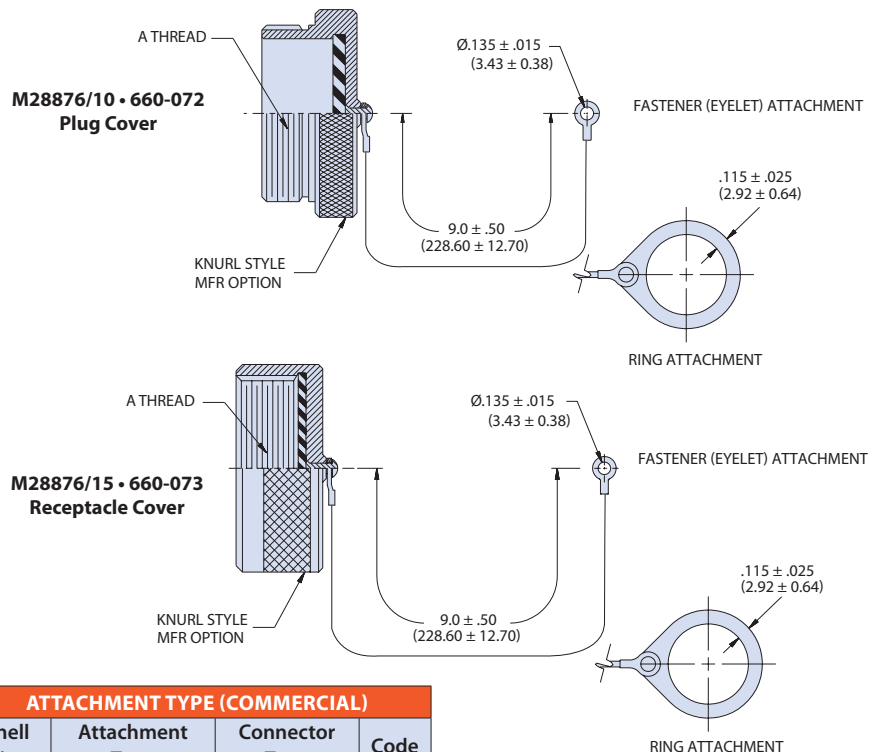

ATTACHMENT TYPE (COMMERCIAL)			
Shell Size	Attachment Type	Connector Type	Code
A	Ring	Plug	13
		Recp	15
B	Ring	Plug	15
		Recp	17
C	Ring	Plug	17
		Recp	20
F	Ring	Plug	23
		Recp	27
All	Fastener (Eyelet)	All	01